
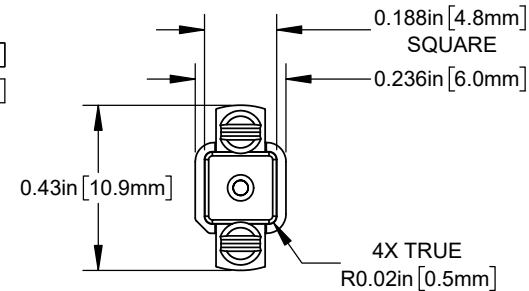



NOTES:

1. ALLOWABLE FLEXIBLE LIGHT PIPE CUT LENGTH AVAILABLE IN INCREMENTS OF 0.05".
2. MINIMUM BEND RADIUS OF FLEXIBLE LIGHT PIPE: 0.87" [22mm].
3. COMPONENTS SHIPPED NON-ASSEMBLED.
4. SEE SHEET 2 FOR DETAILED ASSEMBLY INSTRUCTIONS TO ACHIEVE OPTIMUM FUNCTION OF SPLASH GUARD


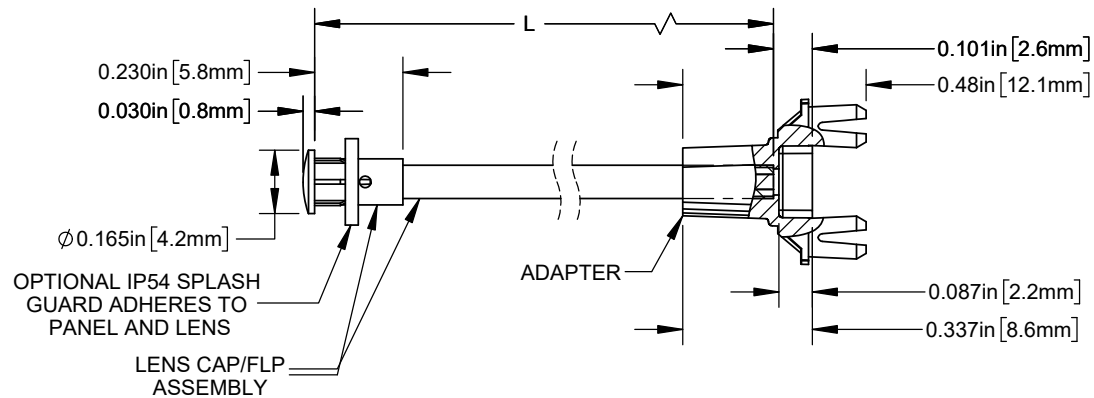


PART NUMBER CONFIGURATOR

SEE SHEET 2 FOR ORDERING INFORMATION

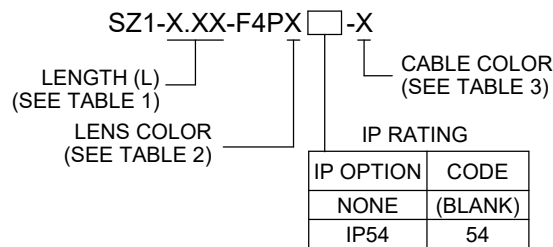

RECOMMENDED LENS MOUNTING HOLE

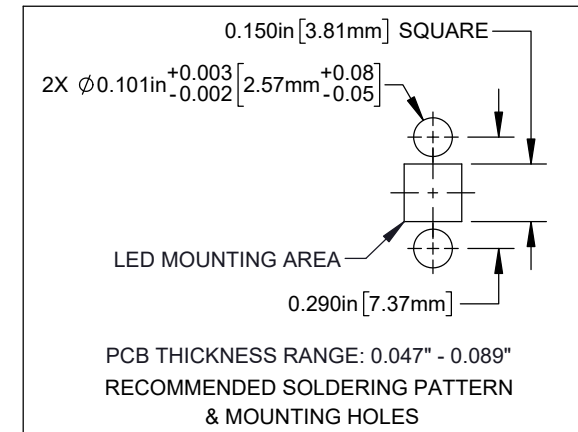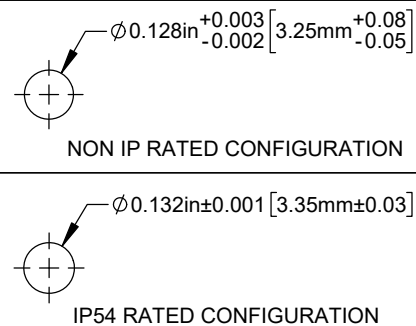

CUSTOMER USE DRAWING

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
DECIMALS	ANGULAR		
.X ± .1	X° ± 1°	TITLE:	

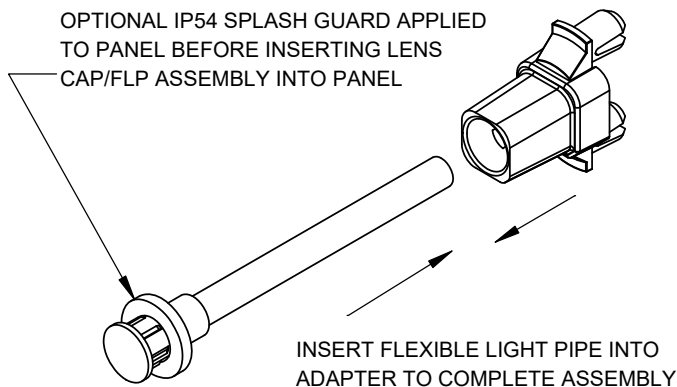


TABLE 1 - LENGTH	
LENGTH (L)*	TOLERANCE
1.00" - 16.00"	±0.05"
16.05" - 40.00"	±0.15"
40.05" - 80.00"	±0.30"
80.05" - 3,940.00"	±0.5%

*AVAILABLE IN 0.05" INCREMENTS

TABLE 2 - LENS	
ORDER CODE	LENS APPEARANCE
(BLANK)	CLEAR
D	DIFFUSED
S	SMOKED
BE	TINTED BLUE
GN	TINTED GREEN
RD	TINTED RED
YW	TINTED YELLOW

TABLE 3 - CABLE	
ORDER CODE	CABLE COLOR
(BLANK)	BLACK
2	RED
4	YELLOW
5	GREEN
6	BLUE
9	WHITE

SAMPLE PART NUMBER:

SZ1-11.20-F4PD54-5

11.20" LENGTH

DIFFUSED LENS

GREEN CABLE

IP54 RATED SPLASH
GUARD INCLUDED

ASSEMBLY INSTRUCTIONS TO ACHIEVE OPTIMUM FUNCTION OF SPLASH GUARD:

- CLEAN PANEL SURFACE AROUND MOUNTING HOLE WITH ALCOHOL
- PEEL LINER OFF TOP OF THE SPLASH GUARD WHILE KEEPING SPLASH GUARD ON PLASTIC ROLL
- APPLY SPLASH GUARD TO PANEL HOLE AS CENTERED AS POSSIBLE AND PEEL PLASTIC LINER SLOWLY AWAY
- INSERT LIGHT PIPE INTO PANEL UNTIL SPLASH GUARD MATERIAL IS COMPRESSED BETWEEN LENS AND PANEL
- HOLD FOR A FEW SECONDS TO ENSURE ENTIRE SPLASH GUARD ADHERES TO PANEL AND LENS FLANGE SURFACE

CUSTOMER USE DRAWING

		BIVAR[®]	
CAGE CODE:	32559	DRAWING NO: SZ1-X.XX-F4PX-X	REVISION: A
SHEET SIZE:	A	SCALE: 2:1	SHEET # 2 OF 2
CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

BIVAR:

[SZ1-6.00-F4PS54-5](#) [SZ1-6.00-F4PS54-6](#) [SZ1-6.00-F4PS54-9](#) [SZ1-6.00-F4PS-6](#) [SZ1-6.00-F4PS-9](#) [SZ1-6.00-F4PYW](#) [SZ1-6.00-F4PYW-2](#) [SZ1-6.00-F4PGN54-4](#) [SZ1-6.00-F4PGN54-5](#) [SZ1-6.00-F4PGN54-6](#) [SZ1-6.00-F4PGN54-9](#) [SZ1-6.00-F4P](#) [SZ1-6.00-F4P-2](#) [SZ1-6.00-F4P-4](#) [SZ1-6.00-F4P-5](#) [SZ1-6.00-F4PBE54-4](#) [SZ1-6.00-F4PBE54-5](#) [SZ1-6.00-F4PBE54-6](#) [SZ1-6.00-F4PBE54-9](#) [SZ1-6.00-F4PBE-6](#) [SZ1-6.00-F4PBE-9](#) [SZ1-6.00-F4PD](#) [SZ1-6.00-F4PD-2](#) [SZ1-6.00-F4PD-4](#) [SZ1-6.00-F4PD-5](#) [SZ1-6.00-F4PD54](#) [SZ1-6.00-F4PD54-2](#) [SZ1-6.00-F4PD54-4](#) [SZ1-6.00-F4PD54-5](#) [SZ1-6.00-F4PD54-6](#) [SZ1-6.00-F4PD54-9](#) [SZ1-6.00-F4PD-6](#) [SZ1-6.00-F4PD-9](#) [SZ1-6.00-F4PGN](#) [SZ1-6.00-F4PGN-2](#) [SZ1-6.00-F4PGN-4](#) [SZ1-6.00-F4PGN-5](#) [SZ1-6.00-F4PGN54](#) [SZ1-6.00-F4PGN54-2](#) [SZ1-6.00-F4PGN-6](#) [SZ1-6.00-F4PGN-9](#) [SZ1-6.00-F4PRD](#) [SZ1-6.00-F4PRD-2](#) [SZ1-6.00-F4PRD-4](#) [SZ1-6.00-F4PRD-5](#) [SZ1-6.00-F4PRD54](#) [SZ1-6.00-F4PRD54-2](#) [SZ1-6.00-F4PRD54-4](#) [SZ1-6.00-F4PRD54-5](#) [SZ1-6.00-F4PYW-4](#) [SZ1-6.00-F4PYW-5](#) [SZ1-6.00-F4PYW54](#) [SZ1-6.00-F4PYW54-2](#) [SZ1-6.00-F4PYW54-4](#) [SZ1-6.00-F4PYW54-5](#) [SZ1-6.00-F4PYW54-6](#) [SZ1-6.00-F4PYW54-9](#) [SZ1-6.00-F4PYW-6](#) [SZ1-6.00-F4PYW-9](#) [SZ1-6.00-F4PRD54-6](#) [SZ1-6.00-F4PRD54-9](#) [SZ1-6.00-F4PRD-6](#) [SZ1-6.00-F4PRD-9](#) [SZ1-6.00-F4PS](#) [SZ1-6.00-F4PS-2](#) [SZ1-6.00-F4PS-4](#) [SZ1-6.00-F4PS-5](#) [SZ1-6.00-F4PS54](#) [SZ1-6.00-F4PS54-2](#) [SZ1-6.00-F4PS54-4](#) [SZ1-10.00-F4P-5](#) [SZ1-10.00-F4P54](#) [SZ1-10.00-F4P54-2](#) [SZ1-10.00-F4P54-4](#) [SZ1-10.00-F4P54-5](#) [SZ1-10.00-F4P54-6](#) [SZ1-10.00-F4P54-9](#) [SZ1-10.00-F4P-6](#) [SZ1-10.00-F4P-9](#) [SZ1-10.00-F4PBE](#) [SZ1-10.00-F4PBE-2](#) [SZ1-10.00-F4PBE-4](#) [SZ1-10.00-F4PBE-5](#) [SZ1-10.00-F4PS54-5](#) [SZ1-10.00-F4PS54-6](#) [SZ1-10.00-F4PS54-9](#) [SZ1-10.00-F4PS-6](#) [SZ1-10.00-F4PS-9](#) [SZ1-6.00-F4P54](#) [SZ1-6.00-F4P54-2](#) [SZ1-6.00-F4P54-4](#) [SZ1-6.00-F4P54-5](#) [SZ1-6.00-F4P54-6](#) [SZ1-6.00-F4P54-9](#) [SZ1-6.00-F4P-6](#) [SZ1-6.00-F4P-9](#) [SZ1-6.00-F4PBE](#) [SZ1-6.00-F4PBE-2](#) [SZ1-6.00-F4PBE-4](#) [SZ1-6.00-F4PBE-5](#)