
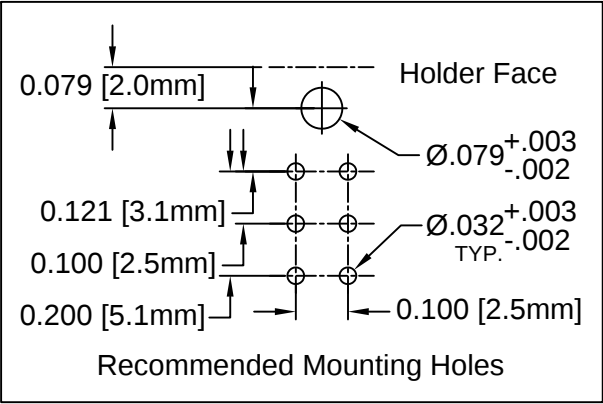


ITEM	Q'TY	PART NUMBER	PART DESCRIPTION
1	1	H-320C-LP	T-1 (3mm) Tri-Level LED Holder, 90° Mount
2	3	3XX-S	T-1 (3mm) N-Flange LED, See Page 2

REV.	DESCRIPTION	DATE	APPROVED
A	Engineering Update w/o Changes	03/08/04	M. C.
B	Updated LEDs to Shouldered	02/28/08	M. C.
C	Added P/N Designation	04/03/12	T. Y.
D	Engineering Update w/o Changes	06/24/16	J. C.

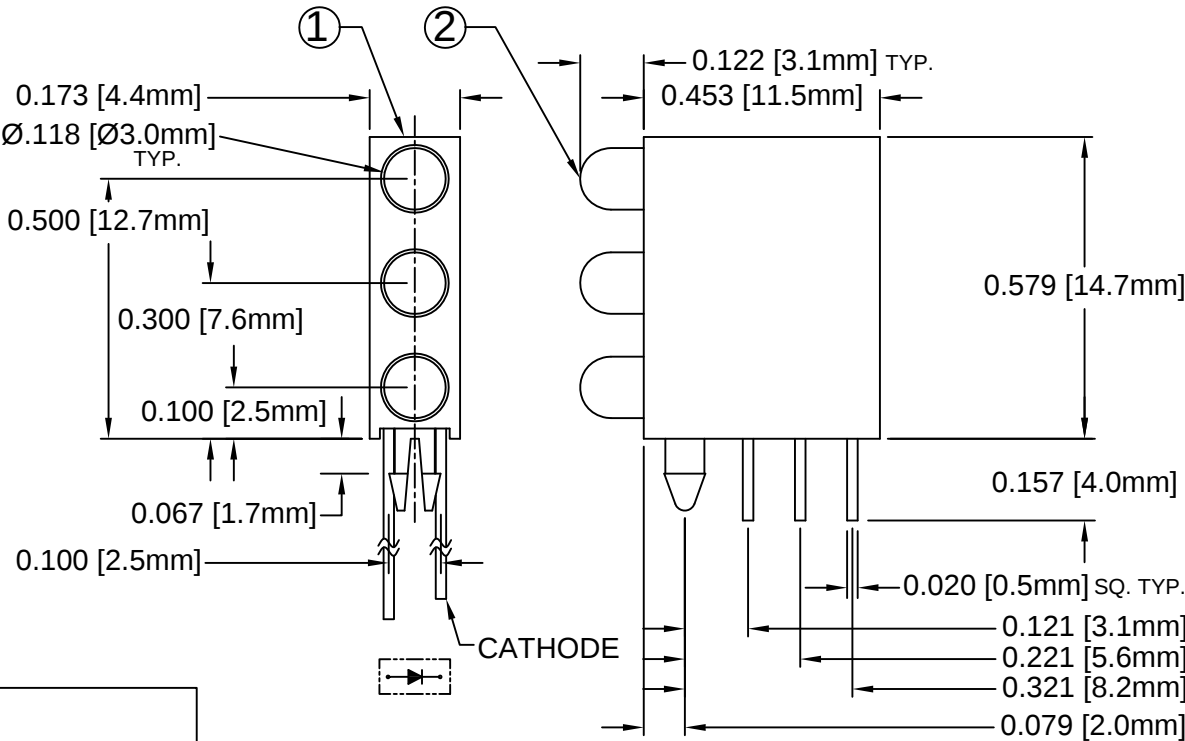

NOTE: P/N DESIGNATION

H320CXXXDX-LP

H-400 Holder Series
 Color of top LED - Use "X" if blank
 Color of Second from top LED - Use "X" if blank
 Color of Bottom LED - Use "X" if blank
 - " " Standard LED
 - "L" Low Current LED
 - "5V" 5V LED
 Lens Appearance
 -If LEDs are the same, use e.g. H200CGD
 All Green Diffused LEDs

ABSOLUTE MAXIMUM RATINGS (Ta=25° C)

REVERSE VOLTAGE _____ 5V
 REVERSE CURRENT _____ 100uA
 OPERATING TEMPERATURE RANGE _____ -25° C - 85° C
 STORAGE TEMPERATURE _____ -30° C - 100° C
 LEAD SOLDERING TEMPERATURE(1/16" FROM BODY) _____ 260° C FOR 5 SECONDS

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
DECIMALS	ANGULAR		
.X ± .1	X° ± 1°		
.XX ± .02			
.XXX ± .010			
DESIGNED: T. Yin	DATE: 03/08/04	TITLE: T-1 (3MM) 90° TRI-LEVEL LED LOCATOR PIN LED ASSY PART NO: H320CXX-LP REVISION: D	
CHECKED: D. Green	DATE: 03/08/04	CAGE CODE : 32559 SHEET # 1 OF 2 CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING.	

REV.	DESCRIPTION	DATE	APPROVED
	SEE SHEET #1		

LED Assy. No.	Peak Wave Length λp(nm)	Emitted Color	Lens Appearance	Electro-Optical Data				Viewing Angle 2 θ ½ (Deg)	LED P/N
				If (mA)	Vf (V)		Iv (mcd)		
				TYP	TYP	MAX	TYP		
STANDARD				Data @ 20mA					
H320CBWD-LP	430	BLUE	DIFFUSED	20	4.0	4.5	20	45	3BWD-S
H320CGD-LP	565	GREEN	DIFFUSED	20	2.2	2.6	30	45	3GD-S
H320CYD-LP	585	YELLOW	DIFFUSED	20	2.1	2.6	20	45	3YD-S
H320CHD-LP	635	HE RED	DIFFUSED	20	2.0	2.6	30	45	3HD-S
H320CRD-LP	655	RED	DIFFUSED	20	1.7	2.0	6	45	3RD-S
H320CSRDL-LP	660	SUPER RED	DIFFUSED	20	1.7	2.6	90	45	3SRD-S
LOW CURRENT				Data @ 2mA					
H320CGDL-LP	565	GREEN	DIFFUSED	2	1.9	2.2	6	45	3GDL-S
H320CYDL-LP	585	YELLOW	DIFFUSED	2	1.9	2.2	4	45	3YDL-S
H320CHDL-LP	635	HE RED	DIFFUSED	2	1.8	2.2	6	45	3HDL-S
5 VOLT				Data @ 5V					
H320CGD5V-LP	565	GREEN	DIFFUSED	10	-	5.0	30	45	3GD5V-S
H320CYD5V-LP	585	YELLOW	DIFFUSED	10	-	5.0	20	45	3YD5V-S
H320CHD5V-LP	635	HE RED	DIFFUSED	10	-	5.0	30	45	3HD5V-S

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED) $\pm 10\%$ ALL VALUES ANGULAR		 4 THOMAS, IRVINE, CA. 92618 TEL.: (949) 951-8808 FAX: (949) 951-3974	
DESIGNED: T. Yin		 DATE: 03/08/04	
CHECKED: D. Green		DATE: 03/08/04 PART NO: H320CXX-LP REVISION: D CAGE CODE : 32559 SHEET # 2 OF 2 CAD GENERATED DOCUMENT. DO NOT MEASURE DRAWING.	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[BIVAR:](#)

[H320CYD-LP](#) [H320CSRDL-LP](#) [H320CYDL-LP](#) [H320CBWD-LP](#) [H320CGDL-LP](#) [H320CGD-LP](#) [H320CHDL-LP](#)
[H320CHD-LP](#) [H320CRD-LP](#)