


ADAPTOR FEMALE BNC - FEMALE N
FLANGE TYPE

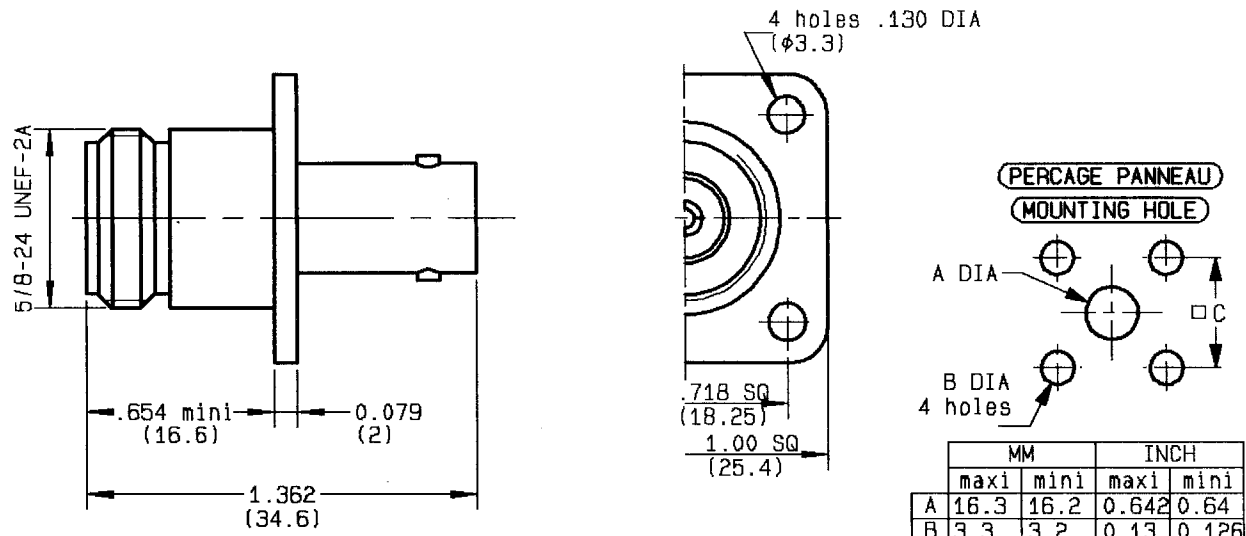

CABLES : -

CHARACTERISTICS

NOMINAL IMPEDANCE	50 Ω	STANDARDISATION	-
FREQUENCY RANGE	0 - 4 GHz		-
TEMPERATURE RATING	-65/+165 °C		-
VSWR	1.30 Maxi		-
RF INSERTION LOSS	.12 √F(GHz) dB Maxi	CABLE RETENTION	- 1lb min N
VOLTAGE RATING	500 Vrms Max	CENTER CONTACT RETENTION	
DIELECTRIC WITHSTANDING VOLTAGE	1500 Vrms min	Axial force - mating end	5.95 27 1lb min N
INSULATION RESISTANCE	5000 MΩ min	Axial force - opposite end	5.95 27 1lb min N
HERMETIC SEAL	- cc/s - Atm.cm3/s	Torque (Min)	NA NA Inch.oz cm.N
LEAKAGE (pressurized only)	- psi - MPa	RECOMMENDED TORQUES	
WEIGHT	0 Oz - g	Mating	NA NA Inch.lb cm.N
		Panel nut	NA NA Inch.lb cm.N
		Clamp nut	NA NA Inch.lb cm.N

CONSTRUCTION

CONNECTOR PARTS	MATERIALS	FINISH
BODY	BRASS	NICKEL
OUTER CONTACT	-	-
CENTER CONTACT	BERYLLIUM COPPER	GOLD over NICKEL
INSULATOR	PTFE	-
-	-	-
-	-	-
-	-	-
-	-	-
-	-	-

ISSUE	REVISION No	DESCRIPTION	BY	DATE

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R191424000](#)