
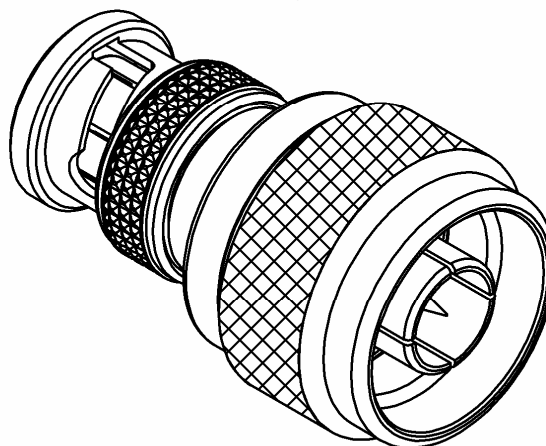
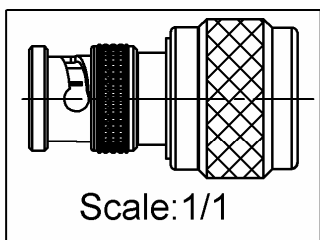


BNC 75 HDTV MALE-N MALE

 
STRAIGHT ADATER

R192.417.010

Série : ADAPTER 75

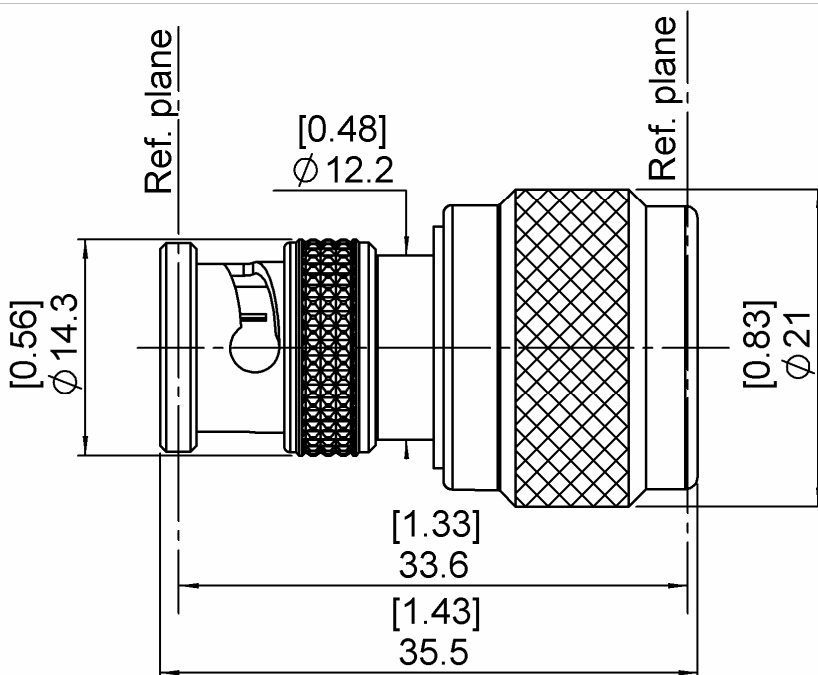

All dimensions are in mm.



COMPONENTS	MATERIALS	PLATING (μm)
BODY	BRASS	BBR2
CENTER CONTACT	BRASS	NPGR
OUTER CONTACT	BRASS	BBR2
INSULATOR	PTFE	
GASKET	SILICONE RUBBER	
OTHERS PARTS	BRASS	BBR2
-	-	-
-	-	-

Issue : 1147 A

In the effort to improve our products, we reserve the rights to make changes judged to be necessary.



BNC 75 HDTV MALE-N MALE**STRAIGHT ADATER****R192.417.010**Série : **ADAPTER 75****PACKAGING**

Standard	Unit	Other
1	-	Contact us

SPECIFICATION**ELECTRICAL CHARACTERISTICS**

Impedance	75	Ω
Frequency	0-6	GHz
VSWR	1.03 + 0,0200	x F(GHz) Maxi
Insertion loss	0.1	$\sqrt{F}(\text{GHz})$ dB Maxi
RF leakage	- (55*	- F(GHz)) dB Maxi
Voltage rating	500	Veff Maxi
Dielectric withstanding voltage	1500	Veff mini
Insulation resistance	5000	M Ω mini

ENVIRONMENTAL

Operating	-55/+155	$^{\circ}\text{C}$
Hermetic seal	NA	Atm.cm3/s
Panel leakage	NA	

MECHANICAL CHARACTERISTICS

Center contact retention	
Axial force – Mating end	15 N mini
Axial force – Opposite end	15 N mini
Torque	NA N.cm mini

Recommended torque

Mating	BNC 75 HDTV	0 N.cm
	N	60 N.cm
		0 N.cm
Panel nut		NA N.cm

Mating life	500	Cycles mini
Weight	36,2300	g

OTHER CHARACTERISTICS

*From 2 to 3 GHz

Issue : **1147 A**

In the effort to improve our products, we reserve the rights to make changes judged to be necessary.

RADIAL 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R192417010](#)