


FEEDTHROUGH FOR P.C.B SOLDER TYPE


R280.222.000

CRIMP TYPE CABLE 2.6/50


Series : MCX

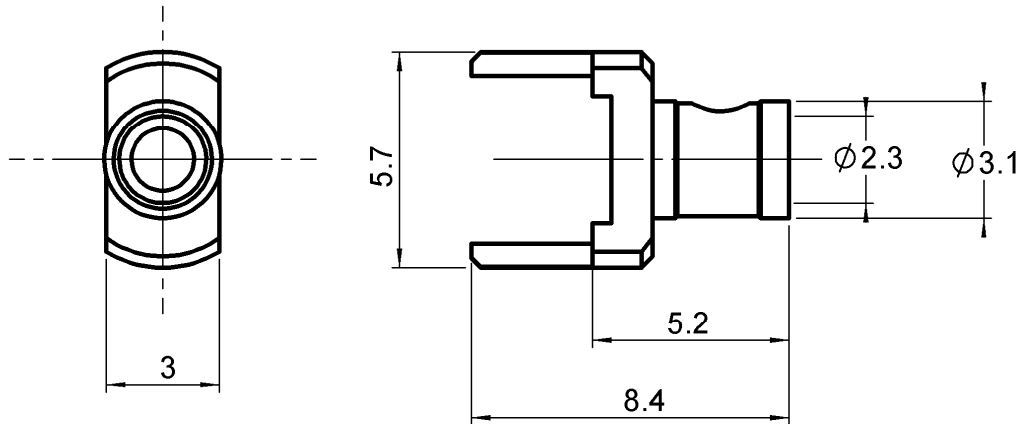

PANEL CUT OUT

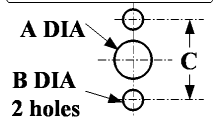

	mm	
	Maxi	mini
A	1.15	1.05
B	1.15	1.05
C	5.15	5.05

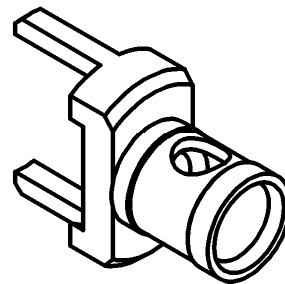

SCALE; 1/1

All dimensions are in mm.



COMPONENTS	MATERIALS	PLATING (μm)
BODY	BRASS	GOLD OVER NICKEL
CENTER CONTACT	-	-
OUTER CONTACT	-	-
INSULATOR	-	-
GASKET	-	-
OTHERS PARTS	-	-
-	-	-
-	-	-

Issue : 0902 C

In the effort to improve our products, we reserve the right to make changes judged to be necessary



RADIALL®

FEEDTHROUGH FOR P.C.B SOLDER TYPE

R280.222.000

CRIMP TYPE CABLE 2.6/50

Series : MCX

PACKAGING

Standard	Unit	Other
100	'W' option	Contact us

SPECIFICATIONCABLE ASSEMBLY

Stripping	a	b	c	d	e	f
mm						

ELECTRICAL CHARACTERISTICS

Impedance		50	Ω
Frequency		0-3	GHz
VSWR	+	NA	x F(GHz) Maxi
Insertion loss		NA	$\sqrt{F}$ (GHz) dB Maxi
RF leakage	- (	NA	-F(GHz)) dB Maxi
Voltage rating		2000	Veff Maxi
Dielectric withstanding voltage		900	Veff mini
Insulation resistance		NA	M Ω mini

Assembly instruction :

Recommended cable(s)

MECHANICAL CHARACTERISTICS

Recommended torque			
Panel nut		NA	N.cm
Clamp nut		NA	N.cm
A/F clamp nut		NA	mm
Mating life		NA	Cycles mini
Weight		0,2660	g

Cable retention

- pull off	53	N mini
- torque	NA	N.cm

TOOLING

Part Number	Description	Hexagon
.	.	.

OTHER CHARACTERISTICS

-

ENVIRONMENTAL

Operating temperature	-55/+155	$^{\circ}\text{C}$
Panel leakage		

Issue : 0902 C

In the effort to improve our products, we reserve the right to make changes judged to be necessary


**RADIALL**®

FEEDTHROUGH FOR P.C.B SOLDER TYPE


R280.222.000

CRIMP TYPE CABLE 2.6/50


Series : MCX

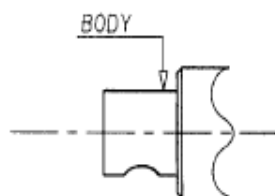


1-1 Cable stripping

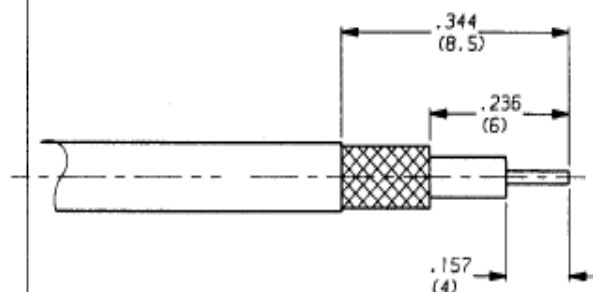

2-1 To introduce cable into the connector body until contact with it according to F direction

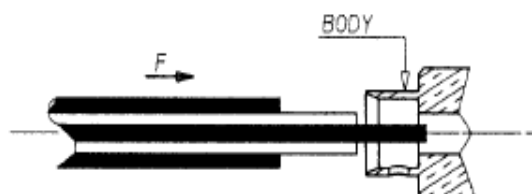

3-1 To solder the braid on the body through F hole

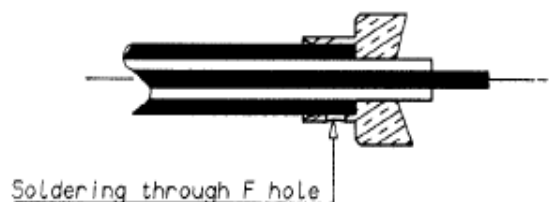

Issue : 0902 C

In the effort to improve our products, we reserve the right to make changes judged to be necessary



RADIALL®

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

R280222000