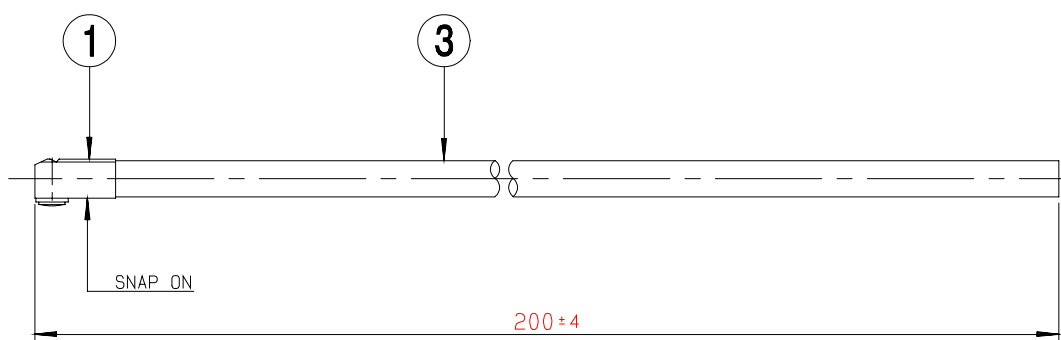


UMP HIGHT 2.6 RIGHT ANGLE SNAP**R285.020.311****20CM CABLE 2/50 S-BR****Series : CORD-STD****PACKAGING**

Standard	Unit	Other
100	'W' option	Contact us

* 1 * Connector A : **R107.111.200**
 * 2 * Connector B :
 * 3 * Cable : **C291.140.087**
 Type : **CAB HF 2/50 S - FTX 111258 MARRON**

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 ° C
VSWR	NA + 0.000 x F(GHz) Maxi
Insertion loss	NA √F(GHz) dB Maxi
Voltage rating	100 Veff Maxi
Dielectric withstanding voltage	350 Veff mini
Insulation resistance	1000 MΩ mini

SPECIFICATION

Weight	1.600 g
Cable retention	NA N mini
Others :	

**Edition : 0145 A**

Design changes may be in order to improve the product.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R285020311](#)