
 


PAGE 1/2	ISSUE 04-12-19M	SERIES COUPLER	PART NUMBER R432273000
----------	-----------------	-------------------	------------------------

Scale 1 : 1

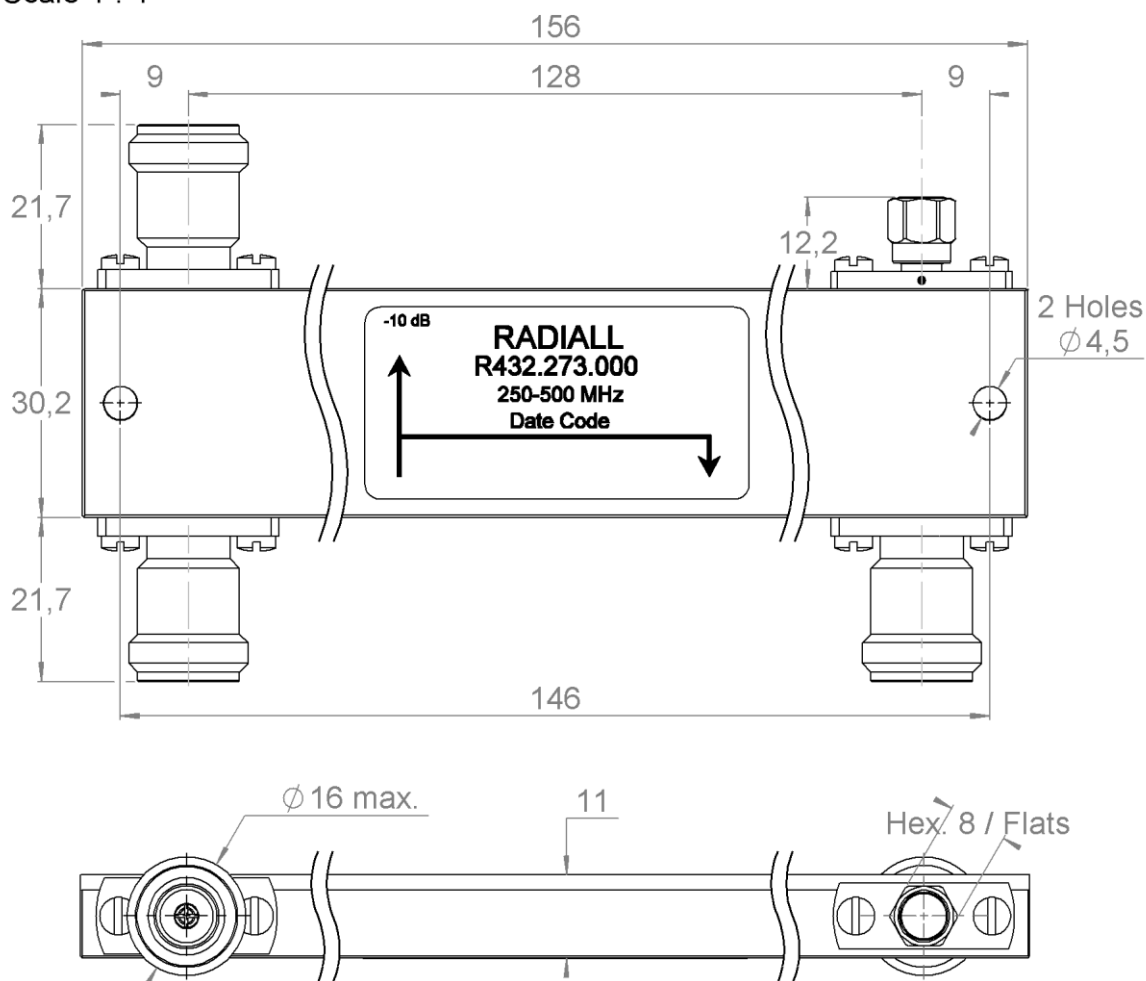

All dimensions are in mm. Tolerances according ISO 2768 m-H



Weight Specification	175,1000	g
----------------------	----------	---

PAGE 2/2

ISSUE **04-12-19M**

SERIES
COUPLER

PART NUMBER **R432273000**

ELECTRICAL CHARACTERISTICS

Frequency operating range :	0.25 – 0.50 GHz
Impedance :	50 Ω
VSWR : - Main Line	1.12 max.
- Coupled Line	1.12 max.
Nominal Coupling :	10 dB
Coupling Precision :	± 0.3 dB
Insertion Loss :	1 dB max.
Directivity :	30 dB mini
Frequency Sensitivity :	± 0.8 dB
Average Power at 25°C	500W
Peak Power at 25°C	5000W

MECHANICAL CHARACTERISTICS

Connector type :	N female per MIL-C 39012
Coaxial Termination :	SMA 50 Ω , 1W

ENVIRONMENTAL CHARACTERISTICS

Operating temperature :	-25°C / +70°C
Storage temperature :	-25°C / +70°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

R432273000