


PAGE 1/2

ISSUE **13-07-17C**

SERIES
COUPLEUR

PART NUMBER **R432571000**


Scale 1 : 1

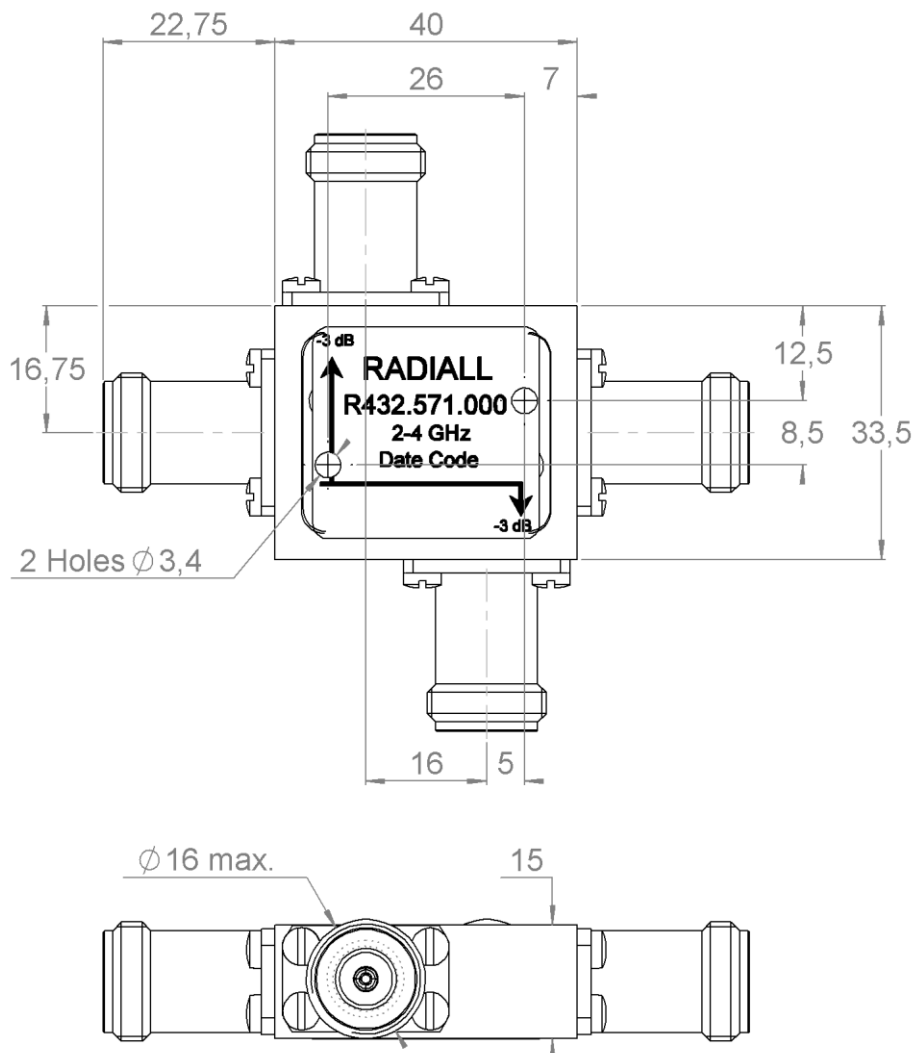

All dimensions are in mm. Tolerances according ISO 2768 m-H

Weight
Specification

 148,5400 g



PAGE 2/2

ISSUE 13-07-17C

SERIES
COUPLEUR

PART NUMBER **R432571000**

ELECTRICAL CHARACTERISTICS

Frequency operating range :	2 – 4 GHz
Impedance :	50 Ω
VSWR	1.20 max.
Nominal Coupling :	3 dB
Insertion Loss :	0.3 dB max.
Isolation :	20 dB mini
Amplitude Balance :	± 0.5 dB
Phase Balance :	$\pm 5^\circ$
Average Power at 25°C	80W
Peak Power at 25°C	3000W

MECHANICAL CHARACTERISTICS

Connector type :	N female per MIL-C 39012
------------------	--------------------------

ENVIRONMENTAL CHARACTERISTICS

Operating temperature :	-25°C / +70°C
Storage temperature :	-25°C / +70°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R432571000](#)