

4112-9212 This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary



18 GHz    SMA    N/O    S.P.10T. SWITCH

OPTIONS :

### R F CHARACTERISTICS

NUMBER OF WAYS : 10  
FREQUENCY RANGE : 0 - 18 GHz  
IMPEDANCE : 50 Ohms

| FREQUENCY (GHz) | 0 - 3   | 3 - 8   | 8 -12.4 | 12.4-15.5 | 15.5- 18 |
|-----------------|---------|---------|---------|-----------|----------|
| V.S.W.R    <=   | 1.20    | 1.30    | 1.40    | 1.50      | 1.70     |
| INSERT. LOSS <= | 0.20 dB | 0.30 dB | 0.40 dB | 0.50 dB   | 0.70 dB  |
| ISOLATION    >= | 80 dB   | 70 dB   | 60 dB   | 60 dB     | 55 dB    |
| AVER. POWER (*) | 240 W   | 150 W   | 120 W   | 110 W     | 100 W    |

### ELECTRICAL CHARACTERISTICS

ACTUATOR : NORMALLY OPEN  
NOMINAL CURRENT AT 25° C (\*10%) : 102 mA  
ACTUATOR VOLTAGE (Vcc) : 28V (24 to 30V) / POSITIVE COMMON  
TERMINALS : 25 pins D-SUB male connector

### MECHANICAL CHARACTERISTICS

CONNECTORS : SMA female per MIL-C 39012  
LIFE : 2.000.000 cycles per position  
SWITCHING TIME (nominal voltage;25° C) : < 15 ms  
CONSTRUCTION : splashproof  
WEIGHT : < 360 g

### ENVIRONMENTAL CHARACTERISTICS

OPERATING TEMPERATURE RANGE (°C) : -40 , +85  
STORAGE TEMPERATURE RANGE (°C) : -55 , +85

(\* : average power at 25° C per RF path)



This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary

DRAWING

General tolerance:  $\pm 0,5$  mm


R573 403015

Page  
2/2

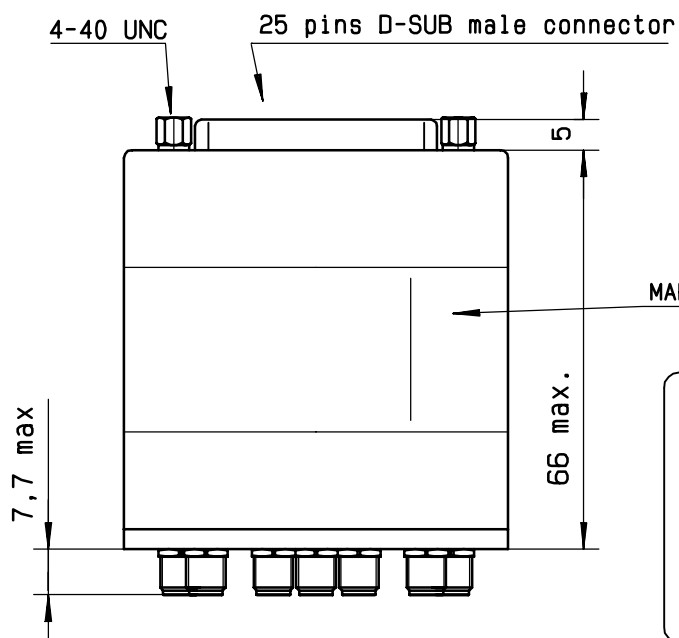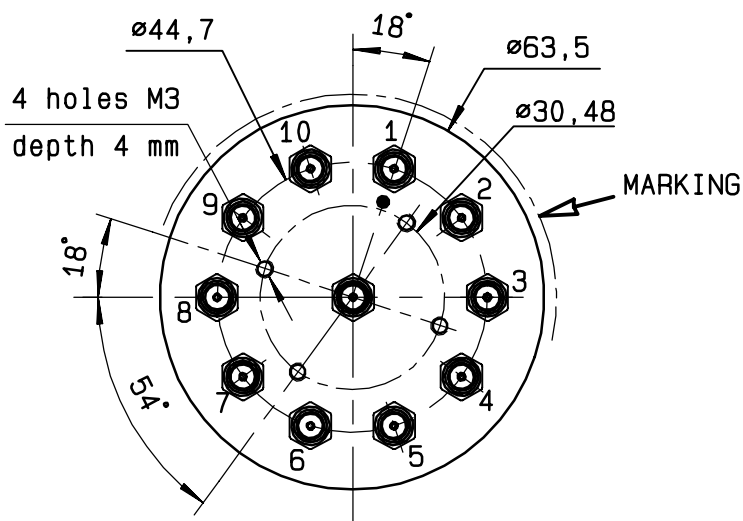


| Voltage | RF continuity |
|---------|---------------|
| +C -1   | IN ↔ 1        |
| +C -2   | IN ↔ 2        |
| +C -3   | IN ↔ 3        |
| +C -4   | IN ↔ 4        |
| +C -5   | IN ↔ 5        |
| +C -6   | IN ↔ 6        |
| +C -7   | IN ↔ 7        |
| +C -8   | IN ↔ 8        |
| +C -9   | IN ↔ 9        |
| +C -10  | IN ↔ 10       |

MARKING TOP VIEW (TERMINALS)

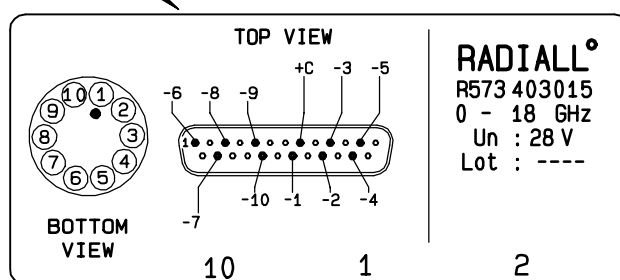

SCHEMATIC DIAGRAM

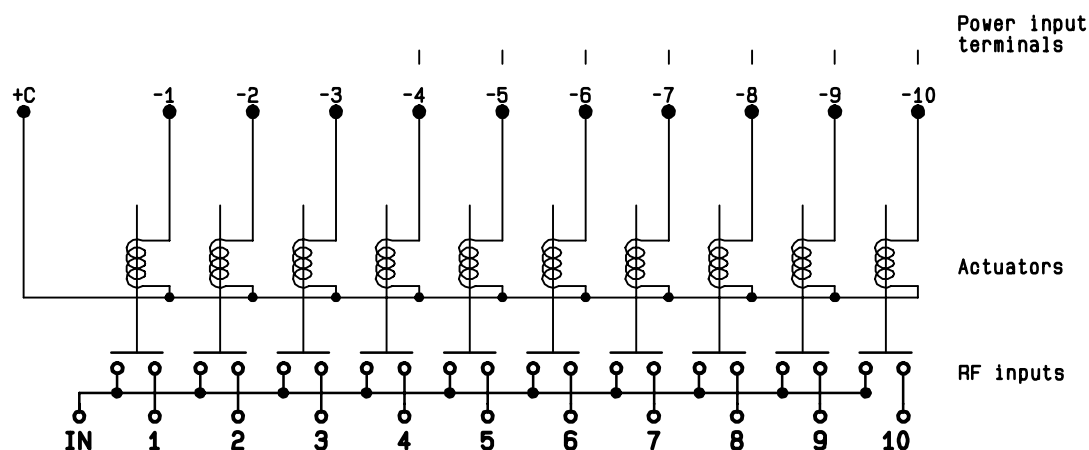

ISSUE 22.Jan.08

4113-9212

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R573403015](#)