


BNC

50 Ω


CABLE CLAMP FOR FLEXIBLE CABLES

STRAIGHT PLUG

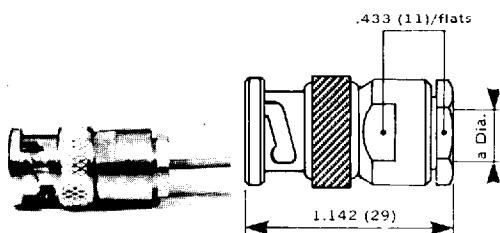


CABLE DIA. Ω	.079 (2) 50	.102 (2,6) 50 + 75
PART NUMBER	R 141 003	R 141 004
a dia. max.	.086 (2,2)	.116 (2,95)
Captive contact	YES	YES
Assembly	M 04	M 04

STRAIGHT PLUG

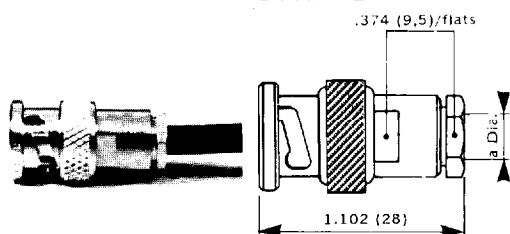


CABLE DIA. Ω	.138 (3,5) 50 + 75	.197 (5) 50	.236 (6) 75	.236 (6) 50 + 75
PART NUMBER	R 141 005	R 141 007	R 141 011	R 141 015
Equival. MIL		UG. 88/U	UG. 260/U	
a dia. max.	.145 (3,7)	.220 (5,6)	.256 (6,5)	.268 (6,8)
Captive contact	NO	NO	NO	NO
Assembly	M 01	M 01	M 01	M 01

STRAIGHT PLUG

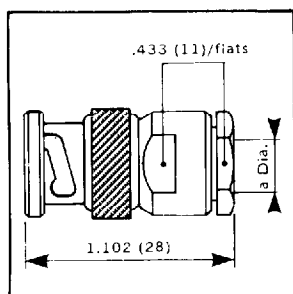

CABLE DIA. Ω	.197 (5) 50	.197 (5) 50	.197 (5) 50	.236 (6) 75 + 93	.236 (6) 75 + 93	.236 (6) 75 + 93
PART NUMBER	R 141 008	R 141 009	R 141 010	R 141 012	R 141 013	R 141 014
Equival. MIL	UG. 88 C/U	UG. 88 E/U	UG. 88 G/U	UG. 260 B/U	UG. 260 D/U	
Equival. MIL		KBN 1			KBN 11	
a dia. max.	.220 (5,6)	.220 (5,6)	.220 (5,6)	.260 (6,6)	.260 (6,6)	.260 (6,6)
Captive contact	NO	NO	YES	NO	NO	YES
Assembly	M 02	M 02	M 02	M 02	M 02	M 02

STRAIGHT PLUG

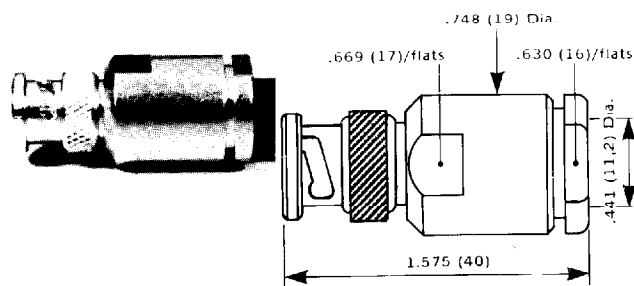

CABLE DIA. Ω	.394 (10) + .433 (11) 50
PART NUMBER	R 141 018
Captive contact	YES
Assembly	M 08

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R141005000](#)