


### STRAIGHT PLUGS, CRIMP TYPE, FOR FLEXIBLE CABLES

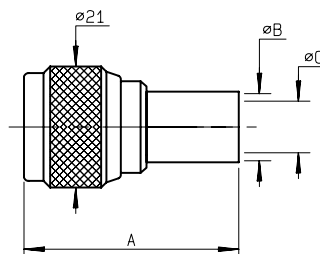

| cable       | part number         | dimensions |       |      | captured center contact | mounting |
|-------------|---------------------|------------|-------|------|-------------------------|----------|
|             |                     | A          | B     | C    |                         |          |
| 6 / 75 / S  | <b>R162 084 000</b> | 33.9       | 6.6   | 4    | YES                     | M33      |
| 10 / 75 / S | <b>R162 075 000</b> | 37.25      | 11.05 | 7.46 | YES                     | M33      |
| 11 / 75 / D | <b>R162 088 000</b> | 37.25      | 11.4  | 7.46 | YES                     | M33      |

### STRAIGHT PLUGS, CLAMP TYPE, FOR FLEXIBLE CABLES

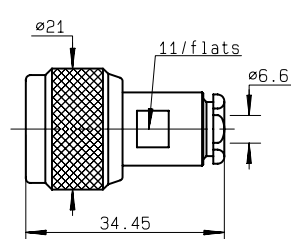


Fig. 1

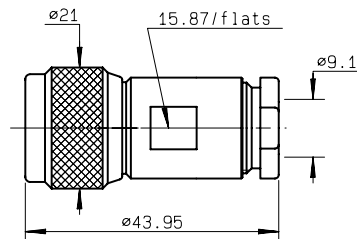


Fig. 2


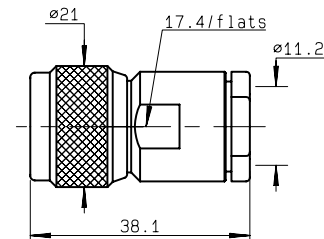


Fig. 3


| cable        | part number         | fig. | captured center contact | mounting |
|--------------|---------------------|------|-------------------------|----------|
| 6 / 75 + 93  | <b>R162 012 000</b> | 1    | NO                      | M02      |
| 8 / 75 / D   | <b>R162 013 000</b> | 2    | NO                      | M16      |
| 10 + 11 / 75 | <b>R162 017 000</b> | 3    | NO                      | M04      |

### RIGHT ANGLE PLUGS, CRIMP TYPE, FOR FLEXIBLE CABLES

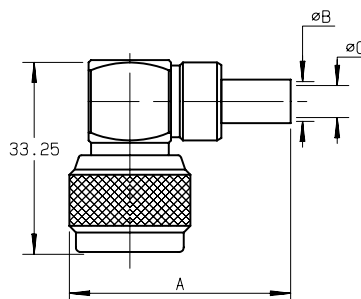


| cable       | part number         | dimensions |       |      | captured center contact | mounting |
|-------------|---------------------|------------|-------|------|-------------------------|----------|
|             |                     | A          | B     | C    |                         |          |
| 6 / 75 / S  | <b>R162 184 000</b> | 38.25      | 6.6   | 4    | YES                     | M33      |
| 10 / 75 / S | <b>R162 185 000</b> | 42.25      | 11.05 | 7.46 | YES                     | M33      |
| 11 / 75 / D | <b>R162 187 000</b> | 42.25      | 11.4  | 7.46 | YES                     | M33      |

 Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.




### RIGHT ANGLE PLUGS, CLAMP TYPE, FOR FLEXIBLE CABLES

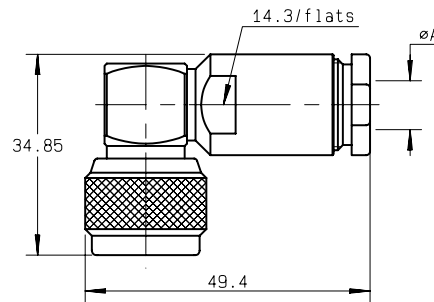

| cable        | part number         | dimensions A | captured center contact | mounting |
|--------------|---------------------|--------------|-------------------------|----------|
| 6 / 75 + 93  | <b>R162 162 000</b> | 6.5          | YES                     | M16      |
| 10 + 11 / 75 | <b>R162 168 000</b> | 11.2         | YES                     | M16      |

### STRAIGHT JACKS, CRIMP TYPE, FOR FLEXIBLE CABLES

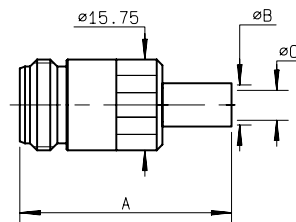

| cable       | part number         | dimensions |       |      | captured center contact | mounting |
|-------------|---------------------|------------|-------|------|-------------------------|----------|
|             |                     | A          | B     | C    |                         |          |
| 6 / 75 / S  | <b>R162 239 000</b> | 36.6       | 6.6   | 4    | YES                     | M33      |
| 10 / 75 / S | <b>R162 241 000</b> | 40.6       | 11.05 | 7.46 | YES                     | M33      |
| 11 / 75 / D | <b>R162 243 000</b> | 40.6       | 11.4  | 7.46 | YES                     | M33      |

### STRAIGHT JACKS, CLAMP TYPE, FOR FLEXIBLE CABLES

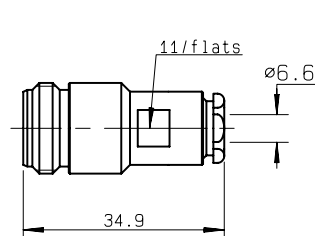


Fig. 1

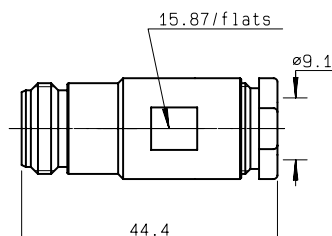


Fig. 2

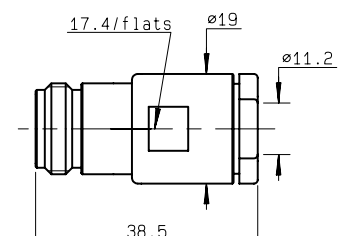


Fig. 3

| cable           | part number         | fig. | captured center contact | mounting |
|-----------------|---------------------|------|-------------------------|----------|
| 6 / 75 + 93 / S | <b>R162 212 000</b> | 1    | NO                      | M02      |
| 8 / 75 / D      | <b>R162 213 000</b> | 2    | NO                      | M16      |
| 10 + 11 / 75    | <b>R162 217 000</b> | 3    | NO                      | M04      |

Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Radial:

[R162017000](#) [R162013000](#) [R162084000](#) [R162084000W](#) [R162013000W](#) [R162075000W](#)