



(2,54 mm) .100"

SMSS, SMSD, ISSM, ISDM, CC83 SERIES

SMSS-05-24-L-04.00-D

SMSD-05-24C-L-05.00-D-K-KUS

ISSM-05

CC83L-2426-L

UNIVERSAL DISCRETE WIRE CABLE

Mates with:

Any .025" (0,64 mm) SQ
.100" x .100"
(2,54 mm) x (2,54 mm)
unshrouded terminal strip,
TSW, HTSW, TSM,
MTSW, HMTSW, PHT,
TLW, MTLW, DW, EW,
ZW, HW, TSSH, TSS, TST,
HTSS, HTST, ZSS, ZST

SPECIFICATIONS

For complete specifications
see www.samtec.com?SMSS
or www.samtec.com?SMSD

Insulator Material:

Nylon 6/6, White

Contact Material:

Phosphor Bronze

Plating:

Au or Sn over

50µ" (1,27 µm) Ni

Operating Temp Range:

-40°C to +105°C

Current Rating:

2.8A per contact
(6 contacts powered)

Voltage Rating:

375 VAC

Wire:

24 or 26 AWG

RoHS Compliant: Yes



APPLICATION

-24C CABLE COLOR CODING

PIN	COLOR
1	BROWN
2	RED
3	ORANGE
4	YELLOW
5	GREEN
6	BLUE
7	VIOLET
8	GRAY
9	WHITE
10	BLACK
ETC	REPEAT

MINI APPLICATOR



CAT-MA-383-2426-XX-01
Contact Samtec.

HAND TOOL

CAT-HT-383-2426-01
Contact Samtec.

Note: For wiring option
information refer to drawing on web.

Note: Some lengths, styles
and options are non-standard,
non-returnable.

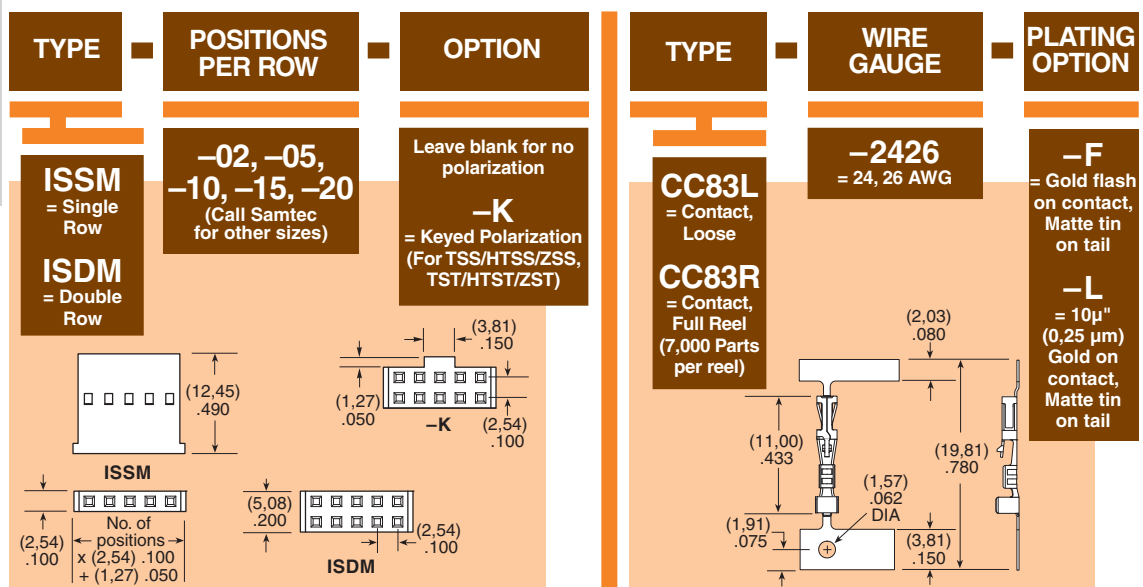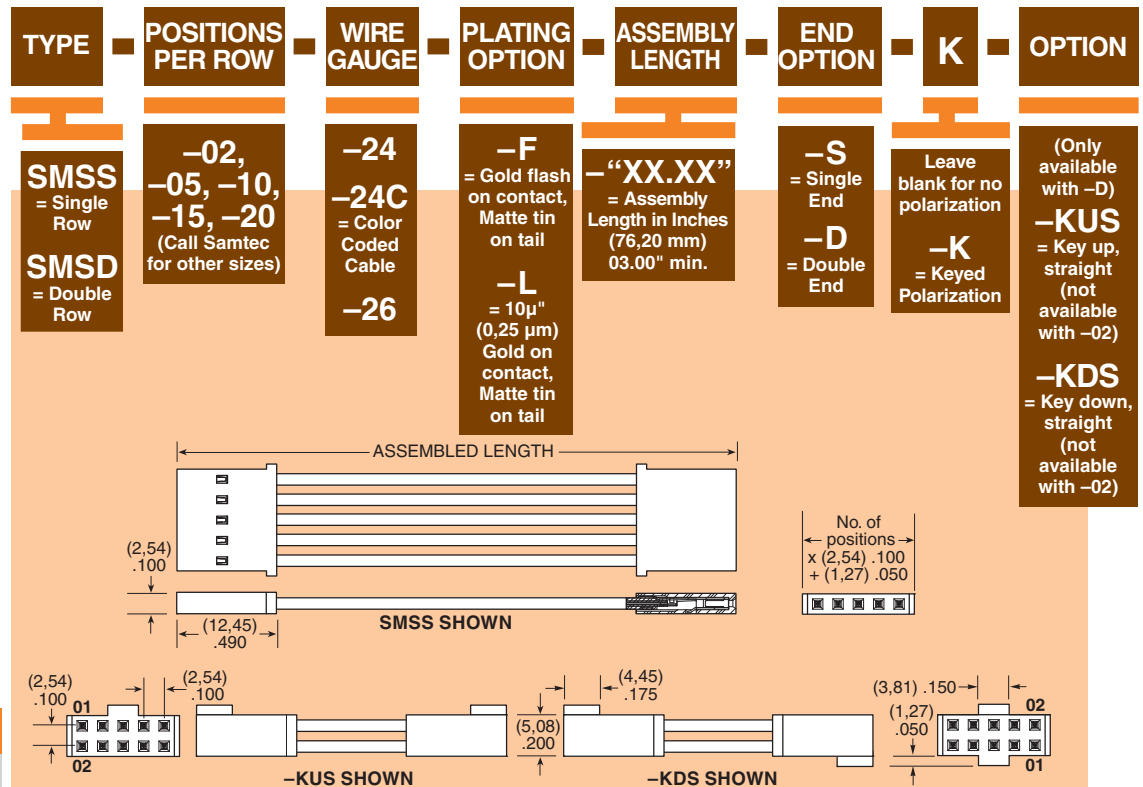

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[SMSS-05-26-F-05.00-D-KDS](#) [SMSS-05-24-F-04.00-D-KUS](#) [SMSS-10-26-F-05.00-D-KDS](#) [SMSS-02-24C-F-05.00-S](#)