

**COST EFFECTIVE****CCPK-22, CC81, T1M82 SERIES**

IP68 22 mm CRIMPED TERMINATION KIT

Mates with:
CCR-22, CCRK-22

SPECIFICATIONS

For complete specifications and processing guidelines see www.samtec.com?CCPK-22

Insulator Material:
PBT
Terminal Material:
Phosphor Bronze
Contact Material: BeCu
Housing:
-P: Black Nylon
-M: Zinc Alloy
RoHS Compliant: Yes

DUST CAP

- DCA-ACP-22-M-X (Metal)
- DCA-ACP-22-P-X (Plastic)



- Visit sealedio.samtec.com for a complete list of sealed systems

CCPK**22****LEAD
STYLE****GENDER****HOUSING
MATERIAL**

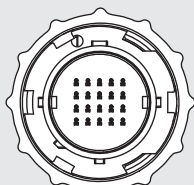
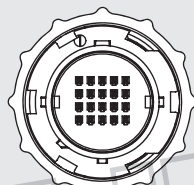
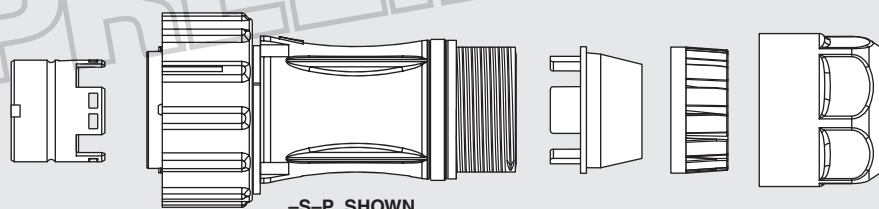
-1
= 20 Positions

-T
= Terminal

-S
= Socket

-P
= Plastic

-M
= Metal

**-T END****-S END****-S-P SHOWN**

OTHER SOLUTIONS

- Solder cup version available
- For specifications, see www.samtec.com?ACPK-22

SPECIFICATIONS

For complete specifications see www.samtec.com?T1M82 or www.samtec.com?CC81

Terminal Material:
Phosphor Bronze
Contact Material:
BeCu

TOOLING

- CC81 Hand tool:
CAT-HT-281-2430-11
- T1M82 Hand tool:
CAT-HT-182-2430-11
- CC81 Mini Applicator (24-26 AWG):
CAT-MA-281-2426-XX-01
- CC81 Mini Applicator (28-30 AWG):
CAT-MA-281-2830-XX-01
- T1M82 Mini Applicator (24-26 AWG):
CAT-MA-182-2426-XX-01
- T1M82 Mini Applicator (28-30 AWG):
CAT-MA-182-2830-XX-01
- Extraction tool:
CAT-EX-169-01

TYPE**WIRE
GAUGE****01****L**

T1M82-L
= Terminal, Loose

T1M82-R
= Terminal, Full Reel
(17,000 Parts per Reel)

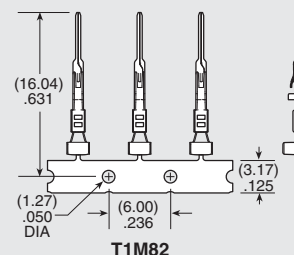
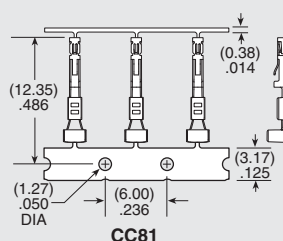
CC81L
= Contact, Loose

CC81R
= Contact, Full Reel
(17,000 Parts per Reel)

-2426
= 24 to 26 AWG

-2830
= 28 to 30 AWG

-L
= 10 μ " (0.25 μ m)
Gold on contact



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[T1M82-L-2830-01-L](#) [T1M82-R-2426-01-L](#) [T1M82-R-2830-01-L](#)