

22 mm IP68 FIELD TERMINATION KIT

SPECIFICATIONS

For complete specifications and processing guidelines see www.samtec.com?ACRK-22

Terminal Material:

Brass

Contact Material:

Brass/BeCu

Operating Temp Range:

-10 °C to +105 °C

Housing:

-P: Thermoplastic

-M: Zinc Alloy

RoHS Compliant:


Yes

Mates with:

ACP-22, ACPK-22

CURRENT RATING		
LEAD STYLE	PINS POWERED	CCC per PIN
-01	30	2.0 A
-02	20	2.3 A
-03	8	8.3 A

For general reference only. See www.samtec.com?ACRK-22 for complete test data or contact AccliMate@samtec.com for applications requiring higher current carrying capacity.

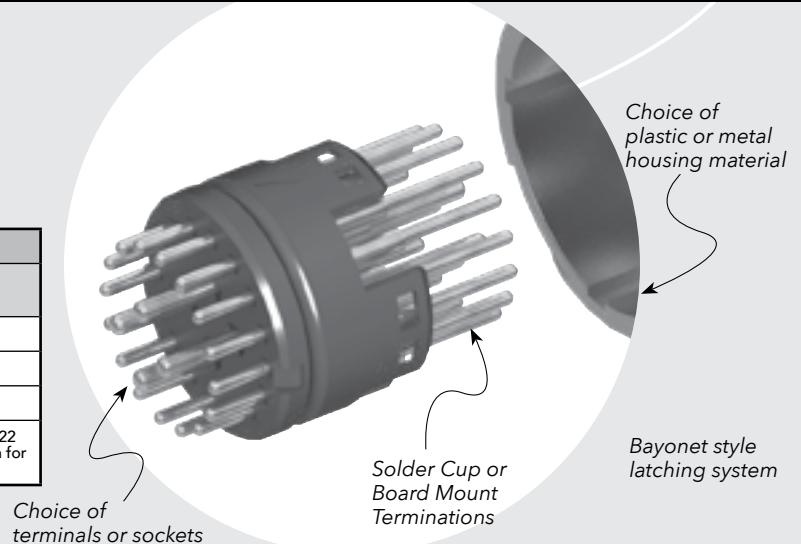


DUST CAPS

- DCA-ACR-22-M-X (Metal)
- DCA-ACR-22-P-X (Plastic)



- Visit sealedio.samtec.com for a complete list of sealed systems

PANEL OPENING

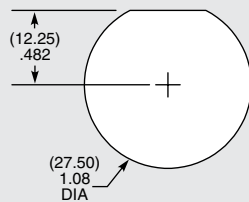

NOTE

For complete specifications and processing guidelines see www.samtec.com?ACRK-22

Note:
Some lengths, styles and options are non-standard, non-returnable.

ACRK	22	LEAD STYLE	PLATING	GENDER	TERMINATION	HOUSING MATERIAL	KEY
		-01 = 1.0 mm DIA (30) (20-24 AWG) -02 = 1.0 mm DIA (20) (20-24 AWG) -03 = 1.5 mm DIA (8) (14-18 AWG)	-G = 10 μ" (0.25 μm) Gold over 50 μ" (1.27 μm) Ni on contact	-T = Terminal -S = Socket	-C = Solder Cup -B1 = (1.60 mm) .062" Board Mount	-P = Plastic -M = Metal	-1 = Orange, 45°

-C END SHOWN

-01

-02

-03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[ACRK-22-03-G-S-C-P-1](#) [ACRK-22-01-G-S-B1-P-1](#) [ACRK-22-01-G-S-C-P-1](#) [ACRK-22-03-G-S-B1-P-1](#) [ACRK-22-01-G-S-B1-M-1](#) [ACRK-22-01-G-S-C-M-1](#) [ACRK-22-03-G-S-B1-M-1](#) [ACRK-22-03-G-S-C-M-1](#) [ACRK-22-03-G-T-C-P-1](#)