

50 Ω BNC TO 4 GHz

BNC Cable Assemblies RF174, RF178, RF316, RS316



SERIES	END 1 CONNECTOR	END 2 CONNECTOR	OVERALL LENGTH
RF174 = RG 174 Cable	-04SP3 = BNC Straight Plug (RS316 not available)		-“XXXX” = Overall Length in millimeters
RF178 = RG 178 Cable	-04BJ2 = BNC Bulkhead Jack		-0100 (100 mm) 3.94" minimum
RF316 = RG 316 Cable, Single Braid Shield	ALSO AVAILABLE 50 Ω: MCX, MMCX, SMA, SMB, TNC, N Type = RF174, RF178, RF316 50 Ω: MCX, MMCX, SMA, TNC = RS 316		
RS316 = RG 316 Cable, Double Shielded			


BNC Cable Connectors BNC5-CA



Supplied with pins, washers,
nuts, gaskets and ferrules.
See website for dimensions.

CONNECTORS FOR INDUSTRY STANDARD CABLES	
BNC5-P-C-GN-ST-CA1	RG 174/316 Cable
BNC5-P-C-GN-ST-CA2	RG 178 Cable
BNC5-J-C-GN-ST-BH1	RG 174/316 Cable, Bulkhead
BNC5-J-C-GN-ST-BH2	RG 178 Cable, Bulkhead
BNC5-J-C-GN-ST-BH1S	RG 316 Double Shielded Cable, Bulkhead

P-C = Cable Plug
J-C = Cable Jack
GN = Plating (10 μ" Gold on contact, Nickel on body)
ST = Straight

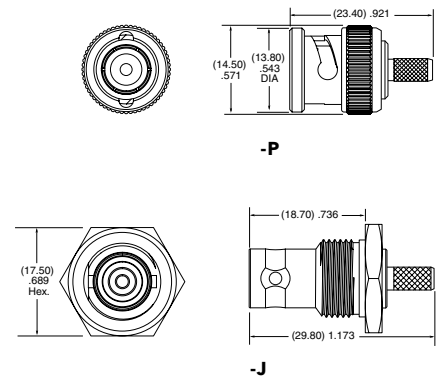

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[BNC5-J-P-GN-RA-BH2D](#) [BNC5-P-C-GN-ST-CA1](#) [BNC5-J-C-GN-ST-BH1](#) [BNC5-J-C-GN-ST-BH2](#) [BNC5-J-P-GN-ST-TH2D](#) [BNC5-P-C-HN-ST-CA1](#) [BNC5-P-C-MN-ST-CA1](#) [BNC5-P-C-GN-ST-CA2](#) [BNC5-J-C-HN-ST-BH1](#)