

50 Ω BNC TO 4 GHz

BNC Cable Assemblies

RF174, RF178, RF316, RS316



SERIES	END 1 CONNECTOR	END 2 CONNECTOR	OVERALL LENGTH
RF174 = RG 174 Cable	-04SP3 = BNC Straight Plug (RS316 not available)		-“XXXX” = Overall Length in millimeters
RF178 = RG 178 Cable	-04BJ2 = BNC Bulkhead Jack		-0100 (100 mm) 3.94" minimum
RF316 = RG 316 Cable, Single Braid Shield	ALSO AVAILABLE 50 Ω: MCX, MMCX, SMA, SMB, TNC, N Type = RF174, RF178, RF316 50 Ω: MCX, MMCX, SMA, TNC = RS316		
RS316 = RG 316 Cable, Double Shielded			

BNC Cable Connectors

BNC5-CA



Supplied with pins, washers, nuts, gaskets and ferrules. See website for dimensions.

CONNECTORS FOR INDUSTRY STANDARD CABLES	
*BNC5-P-C-GN-ST-CA1	RG 174/316 Cable
*BNC5-P-C-GN-ST-CA2	RG 178 Cable
*BNC5-J-C-GN-ST-BH1	RG 174/316 Cable, Bulkhead
BNC5-J-C-GN-ST-BH2	RG 178 Cable, Bulkhead
BNC5-J-C-GN-ST-BH1S	RG 316 Double Shielded Cable, Bulkhead


*Add "-B" to the end of the part number for bulk packaging

P-C = Cable Plug

J-C = Cable Jack

GN = Plating (10 μ" Gold on contact, Nickel on body)

ST = Straight

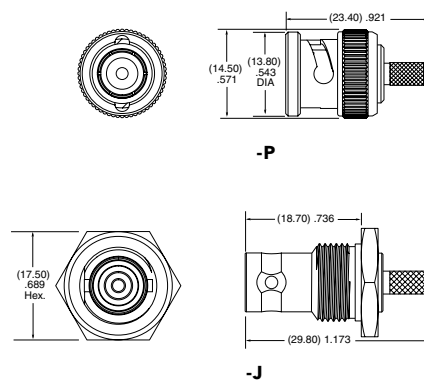

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[BNC5-P-C-GN-ST-CA1](#) [BNC5-J-C-GN-ST-BH1](#) [BNC5-J-C-GN-ST-BH2](#) [BNC5-J-P-GN-ST-TH2D](#) [BNC5-P-C-HN-ST-CA1](#) [BNC5-P-C-MN-ST-CA1](#) [BNC5-P-C-GN-ST-CA2](#) [BNC5-J-C-HN-ST-BH1](#)