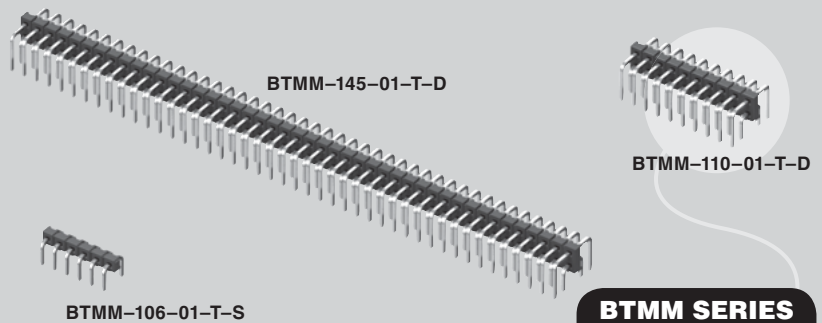


(2,00 mm) .0787"

**BTMM SERIES**

LOW PROFILE SQUARE POST JUMPER

SPECIFICATIONS

For complete specifications see www.samtec.com?BTMM

Insulator Material:
Black Liquid Crystal Polymer

Terminal Material:
Phosphor Bronze

Plating:
Sn over 50 μ " (1,27 μ m) Ni

Operating Temp Range:
-55°C to +105°C

RoHS Compliant:
Yes

Lead-Free Solderable:
Yes

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



Choice of Single or Double row



Up to 50 pins per row

(0,50 mm)
.020"
square

(2,00 mm)
.0787"
pitch

(8,00 mm)
.315" pitch

(4,00 mm)
.157" pitch

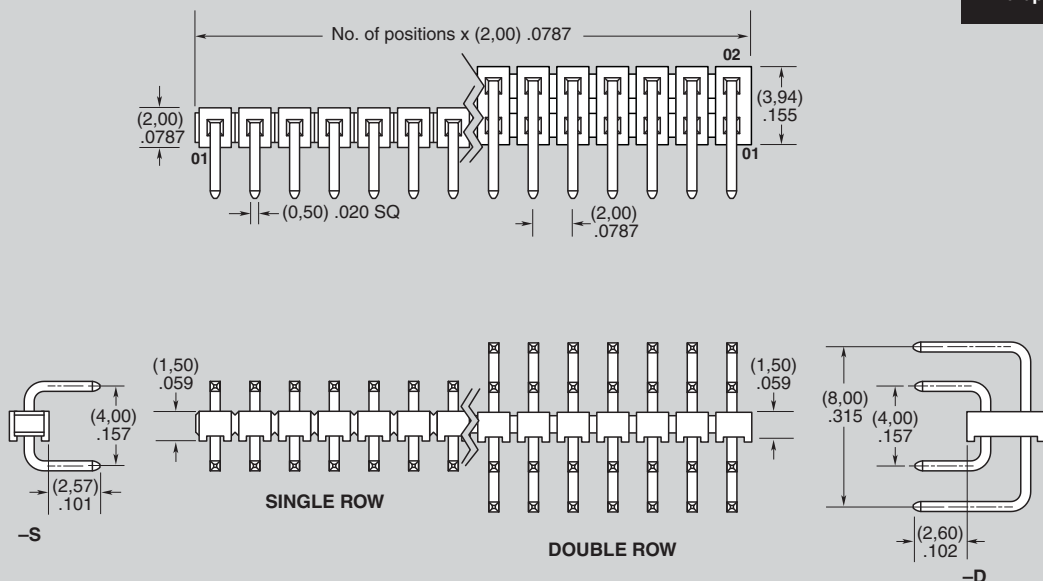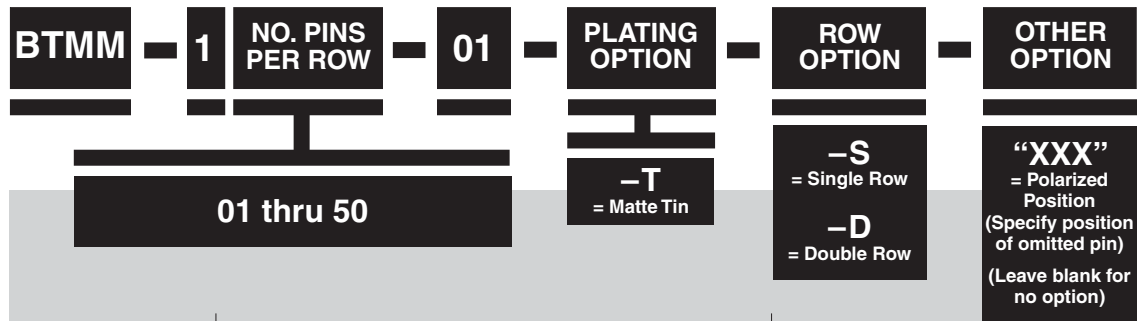

Note: Some sizes, styles and options are non-standard, non-returnable.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[BTMM-108-01-G-D](#)