




(2,00 mm) .0787"

(2,54 mm) .100"

BTMM, BTSW SERIES

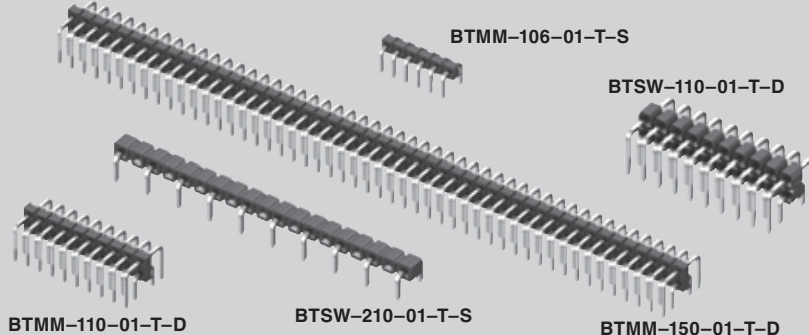

LOW PROFILE SQUARE POST JUMPER

SPECIFICATIONS

For complete specifications see www.samtec.com?BTMM

Insulator Material:

Black Liquid

Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Sn over 50µ" (1,27 µm) Ni

Operating Temp Range:


-55°C to +105°C

RoHS Compliant:

Yes

Lead-Free Solderable:

Yes

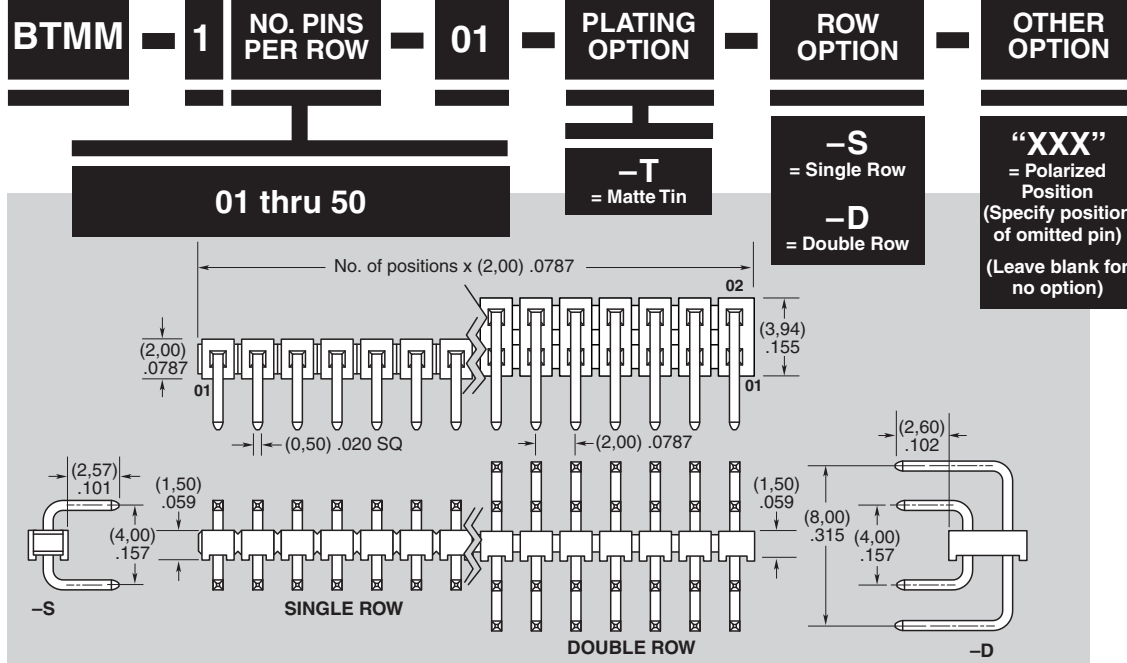

Note: Some sizes, styles and options are non-standard, non-returnable.

SPECIFICATIONS

For complete specifications see www.samtec.com?BTSW

Insulator Material:

Black Glass Filled

Polyester

Terminal Material:

Phosphor Bronze

Plating:

Sn over 50µ" (1,27 µm) Ni

Operating Temp Range:


-55°C to +105°C

RoHS Compliant:


Yes

Lead-Free Solderable:

Wave Only

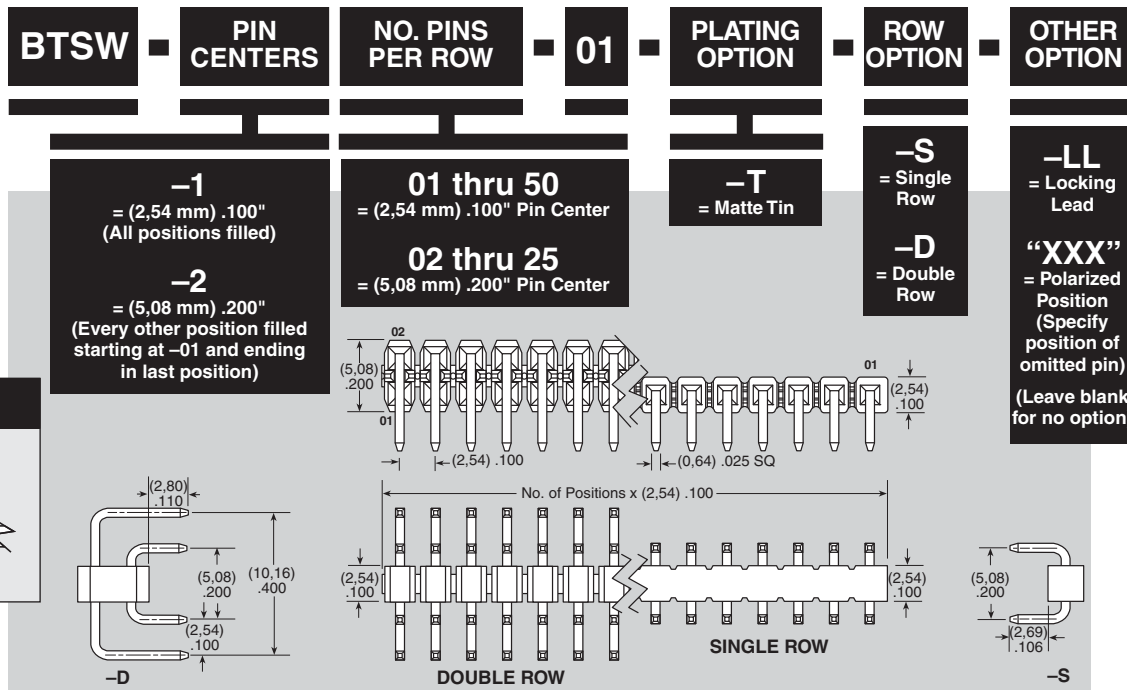

APPLICATION

 

Note: Some sizes, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[BTSW-210-01-T-S](#) [BTSW-210-01-T-D](#) [BTSW-110-01-F-S-LL](#)