

MCRK-8-S



CC393-2830-L-S

**MCRK, CC393 SERIES**

8 SERIES IP67 FIELD TERMINATION KIT

Mates with:
MCP(K)

SPECIFICATIONS

For complete specifications see www.samtec.com?MCRK

Insulator Material:

PPS

Contact Material:

Phosphor Bronze

Operating Temp Range:

-20 °C to +80 °C

Gasket Material:

Neoprene Rubber

Lock Washer:

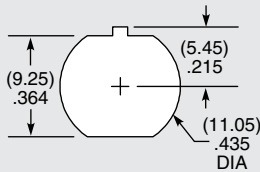
Phosphor Bronze, Ni plated

Hex Nut:

Brass, Ni plated

RoHS Compliant:

Yes

**PANEL
OPENING**

Note: Samtec's MCRK Series is dual sourced by Hirose Electric Co., LTD.

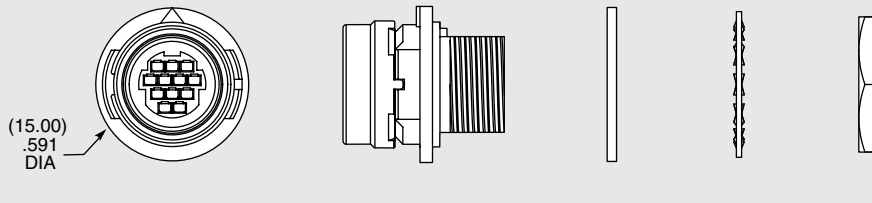
MCRK**8****GENDER****-S**

= Socket (12 positions)

DUST CAPS

- DCA-MCR-8

Visit sealedio.samtec.com for a complete list of sealed systems

**SPECIFICATIONS**

For complete specifications see www.samtec.com?CC393

Plating:

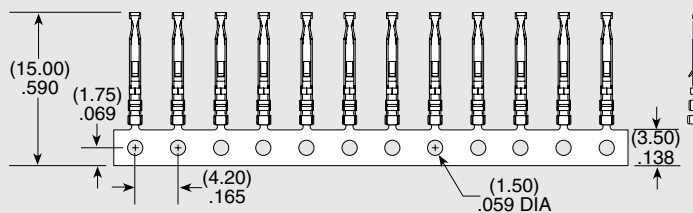
10 µ" (0.25 µm) Gold on contact

TOOLING

- Hand Tool:
CAT-HT-393-2430-13
- Mini Applicator
(28-30 AWG):
CAT-MC-393-2830-XX-01
- Extraction Tool:
CAT-EX-MCX-8-01

TYPE**LEAD STYLE****L****PACKING
OPTION****CC393**
= Contact**-2830**

= 28 to 30 AWG

-S= Strip
(15 contacts)**-M**= Mini Reel
(1,000 - 5,000 contacts)**-R**= Reel
(30,000 contacts)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[CC393-2830-L-S](#) [CC393-2830-L-M](#) [CC393-2830-L-R](#)