

CJT-T-P-HH-RA-TH1

CJT-T-P-HH-RA-BH1



CJT SERIES

100 Ω CIRCULAR RF TWINAX JACK

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?CJT-TH or www.samtec.com?CJT-BH

Shell Material:

Brass

Insulator Material:

PTFE

Contact Material:

Phosphor Bronze

Operating Temperature:

-20 °C to +105 °C

Frequency Range:

0 - 4 GHz

Working Voltage:

200 VAC

Impedance:

100 Ω

RoHS Compliant:

Yes

Lead-Free Solderable:


Yes

Mates with:
C28S

Heavy Gold plating
on inner and outer
contacts

Right-angle or
vertical orientations

Bayonet style quick
connect feature

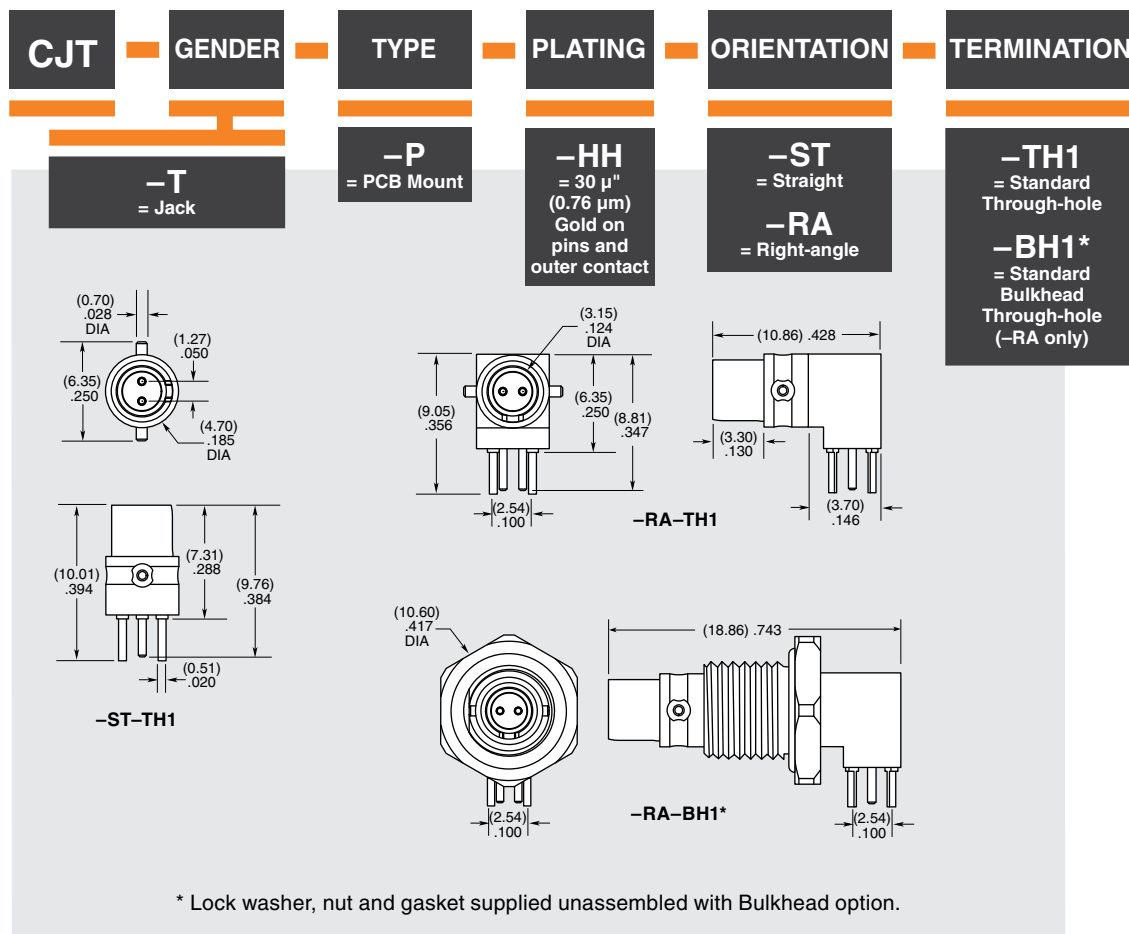

* Lock washer, nut and gasket supplied unassembled with Bulkhead option.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[CJT-T-P-HH-RA-TH1](#) [CJT-T-P-HH-ST-TH1](#) [CJT-T-P-HH-RA-BH1](#)