


FLEXIBLE ELEVATED & SELF-NESTING SOCKETS

(2.00 mm) .0787" PITCH • ESQT/ESQT (-368)/PTHF SERIES

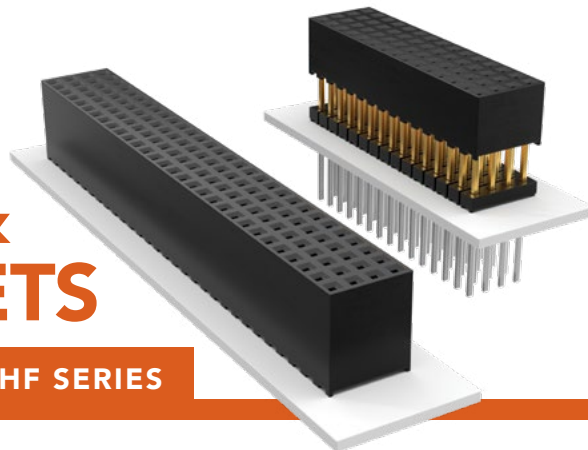

ESQT

Board Mates:

TMMH, TMM, MTMM,
MMT, TW, LTMM, ZLTMM,
ESQT, PTT, TSH, TMMS

Cable Mates:

TCMD

SPECIFICATIONS

Insulator Material:

Black Liquid Crystal Polymer

Contact Material:

Phosphor Bronze

Plating:

Sn or Au over

50 μ " (1.27 μ m) Ni

Current Rating (ESQT/TMMH):

4.5 A per pin

(2 pins powered)

Operating Temp Range:

-55 °C to +125 °C

Insertion Depth:

(2.62 mm) .103" to

(5.03 mm) .198" with

(0.38 mm) .015" wipe

Max Cycles:


100 with 10 μ " (0.25 μ m) Au

Lead-Free Solderable:


Yes, for -S, -D & -Q

(Wave only for -T, -5 & -6)

| ESQT | 1 | NO. PINS PER ROW | LEAD STYLE | PLATING OPTION | ROW OPTION | BODY HEIGHT | OTHER OPTION |
|------|---|------------------|-------------------------------|--|---|--|--|
| | | 02 thru 50 | Specify LEAD STYLE from chart | -F = Gold flash on contact, Matte Tin on tail -L = 10 μ " (0.25 μ m) Gold on contact, Matte Tin on tail -M = 20 μ " (0.51 μ m) Gold on contact, Matte Tin on tail -GF = 15 μ " (0.38 μ m) Gold on contact, Gold flash on tail (Recommended for self-nesting) (-02 lead style only) | -S = Single Row -D = Double Row -T = Triple Row -Q = Quad Row -5 = Five Row -6 = Six Row | - "XXX" = Body Height (in inches) (7.87 mm) .310" minimum for -S, -D, -Q (9.53 mm) .375" minimum for -T, -5, -6 | - "XXX" = Polarized Position (Indicate position number) |

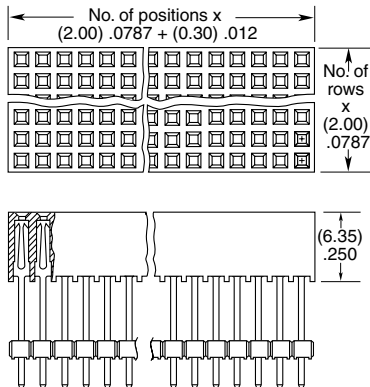

| LEAD STYLE | A | MAX TAIL | MAX BODY HEIGHT |
|------------|--------------|--------------|-----------------|
| -02 | (21.59) .850 | (13.72) .540 | (20.32) .800 |
| -03 | (11.63) .458 | (3.76) .148 | (10.36) .408 |

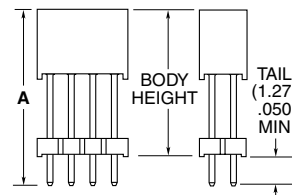

ESQT (-368)/PTHF

Mates:

ESQT, PTHF

SPECIFICATIONS

Insulator Material:

Black Liquid Crystal Polymer (ESQT-368)

Black High Temp Nylon (PTHF)

Contact Material:

Phosphor Bronze

Plating:

Au or Sn over

50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +125 °C




Max Cycles:

100 with 10 μ " (0.25 μ m) Au

Lead-Free Solderable:

Yes (ESQT-368)

| SERIES | 1 | NO. PINS PER ROW | LEAD STYLE | PLATING OPTION | Q | 368 |
|--------|---|------------------|-------------------------------|--|---|-----|
| ESQT | | 30 | Specify LEAD STYLE from chart | -GF = 15 μ " (0.38 μ m) Gold on contact, Gold flash on tail (-02 Lead Style only) -M = 20 μ " (0.51 μ m) Gold on contact, Matte Tin on tail (-03 Lead Style only) | | |
| PTHF | | | | | | |

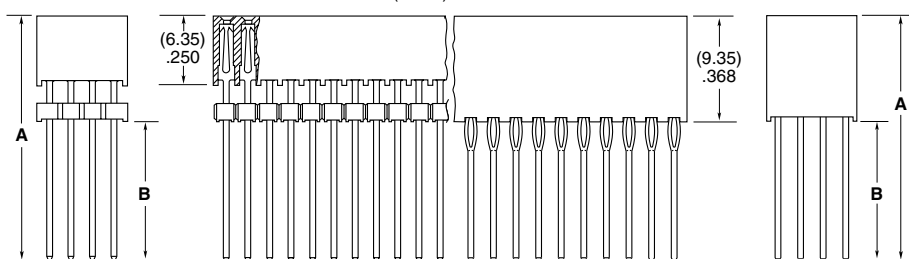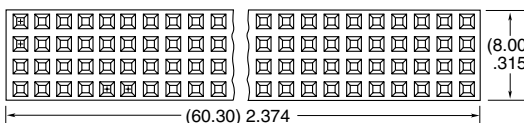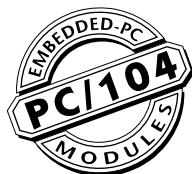

ESQT (-368) SERIES

PTHF SERIES

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[ESQT-107-03-L-Q-329](#)