



SMPM TO 65 GHz

SMPM Ganged Block: GPPB

Mates With:
PRFIA

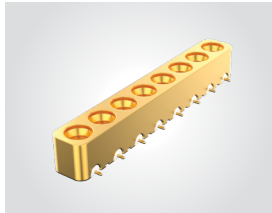

GPPB	GENDER	NO. OF ROWS	NO. OF POSITIONS	PLATING	ST	SM	CHANNEL PITCH
	-PF = Plug Full Detent -PS = Plug Smooth Bore -PC = Catcher's Mitt	-1	-02, -04, -06, -08, -10	-EG = 50 μ" (1.27 μm) heavy Gold center contact, 10 μ" (0.25 μm) Gold outer body			-1N = 3.56 mm (.140") Pitch

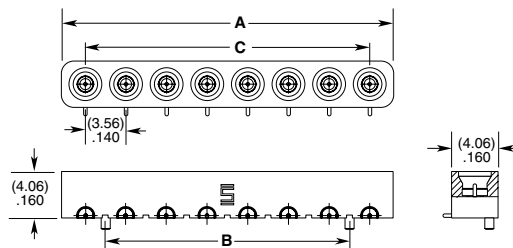

GPPB-PF-1-08-EG-ST-SM-1N SHOWN

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	N/A	(3.56) .140
-04	(14.73) .580	(7.11) .280	(10.67) .420
-06	(21.84) .860	(14.22) .560	(17.78) .700
-08	(28.96) 1.14	(21.34) .840	(24.89) .980
-10	(36.07) 1.42	(28.45) 1.12	(32.00) 1.26


ALSO AVAILABLE

(8.33 mm) .328" Pitch
(5.08 mm) .200" Pitch
Edge Mount termination
Contact RFGroup@samtec.com


DUAL PORT SOLDERLESS COMPRESSION MOUNT

SMPM Ganged Block: GPPC

Mates With:
GC47, GC86, PRFIA

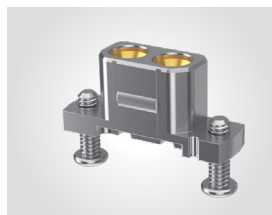

GPPC	GENDER	1	2	PLATING	ORIENTATION	TERMINATION	PACKAGING
	-PF = Plug Full Detent -PS = Plug Smooth Bore			-EP = 50 μ" (1.27 μm) heavy Gold center contact, Passivated outer body	-ST = Straight	-CMM = Compression Mount	Leave blank for individually bagged -B = Full Tray (Multiples of 100 required)

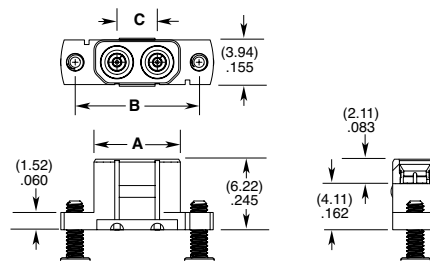

GPPC-PX-1-2-EP-ST-CMM-X SHOWN

NO. OF POSITIONS	A	B	C
-02	(7.62) .300	(10.92) .430	(3.56) .140

Adaptors or visit Samtec.com?PRFIA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[GPPB-PF-1-02-EG-ST-SM-1N](#) [GPPB-PF-1-04-EG-ST-SM-1N](#) [GPPB-PF-1-06-EG-ST-SM-1N](#) [GPPB-PF-1-08-EG-ST-SM-1N](#) [GPPB-PF-1-10-EG-ST-SM-1N](#) [GPPB-PS-1-02-EG-ST-SM-1N](#) [GPPB-PS-1-04-EG-ST-SM-1N](#) [GPPB-PS-1-06-EG-ST-SM-1N](#) [GPPB-PS-1-08-EG-ST-SM-1N](#) [GPPB-PS-1-10-EG-ST-SM-1N](#)