




# HIGH-SPEED EDGE CARD SYSTEMS

0.60 mm, 0.80 mm and 1.00 mm PITCH

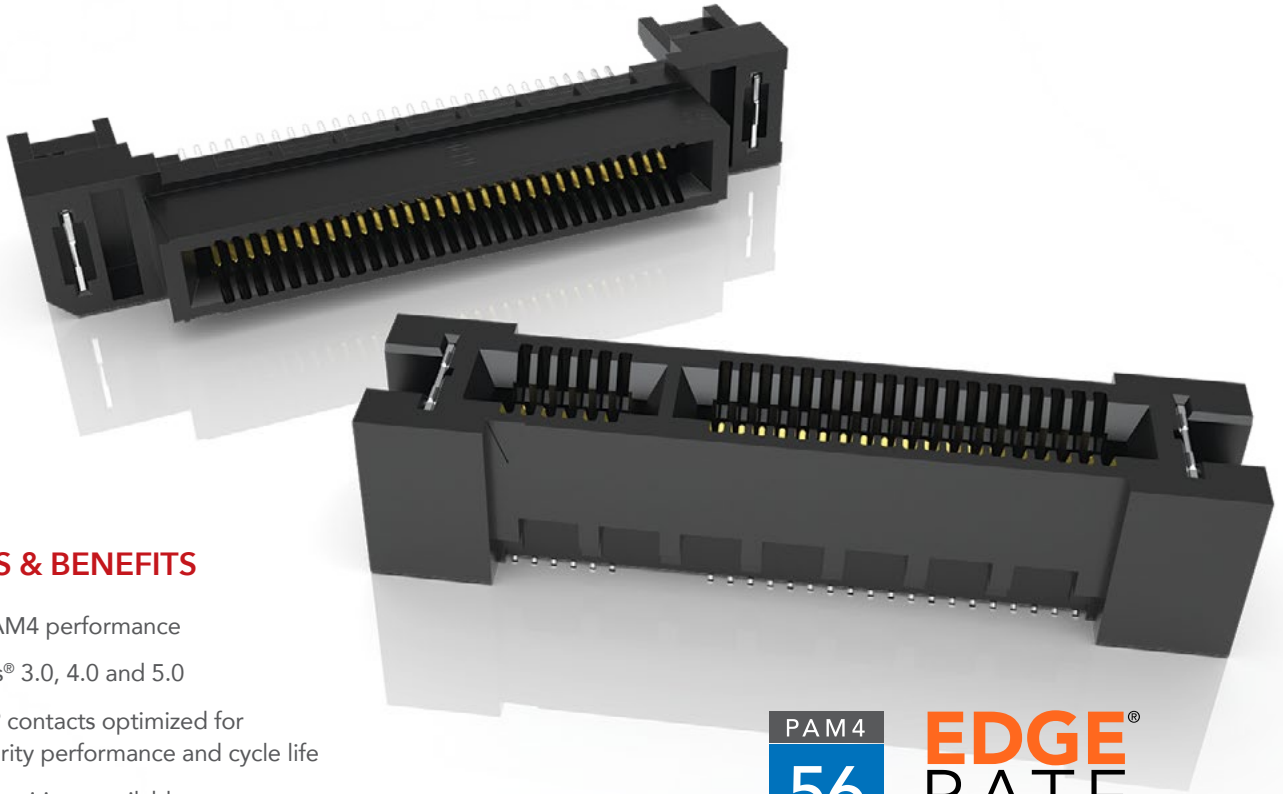

## FEATURES & BENEFITS

 - 56 Gbps PAM4 performance
- PCI Express® 3.0, 4.0 and 5.0
- Edge Rate® contacts optimized for signal integrity performance and cycle life
- Up to 200 positions available
- Vertical, right-angle, edge mount, pass-through orientations
- Power/signal combo, press-fit tails, rugged weld tabs, locks and latches
- Mating cable assemblies available

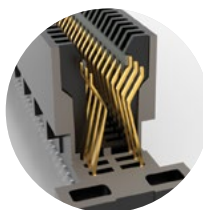

Rugged tucked beam technology (HTEC8)



Differential pair for increased speed (HSEC8-DP)



Custom designs allow for misalignment in the X-Y axes (HSEC1)

## KEY SPECIFICATIONS

| SERIES | PITCH   | TOTAL POSITIONS | INSULATOR MATERIAL | CONTACT MATERIAL | OPERATING TEMP RANGE | CURRENT RATING  | VOLTAGE RATING | LEAD-FREE SOLDERABLE |
|--------|---------|-----------------|--------------------|------------------|----------------------|-----------------|----------------|----------------------|
| HSEC6  | 0.60 mm | 56-168          | Black LCP          | Copper Alloy     | -55 °C to +125 °C    | 0.8 A (12 pins) | 300 VAC        | Yes                  |
| HTEC8  | 0.80 mm | 40-200          | Black LCP          | Copper Alloy     | -55 °C to +125 °C    | 3.0 A (2 pins)  | 215 VAC        | Yes                  |
| HSEC8  | 0.80 mm | 18-200          | Black LCP          | BeCu             | -55 °C to +125 °C    | 2.8 A (2 pins)  | 240 VAC        | Yes                  |
| HSEC1  | 1.00 mm | 20-140          | Black LCP          | Phosphor Bronze  | -55 °C to +125 °C    | 2.2 A (2 pins)  | 215 VAC        | Yes                  |

**(0.80 mm) .0315" PITCH • RIGHT-ANGLE & EDGE MOUNT SOCKET**

| HSEC8 | 1 | POSITIONS PER ROW | CARD THICKNESS | PLATING OPTION | RA | OTHER OPTIONS | "X"R |
|-------|---|-------------------|----------------|----------------|----|---------------|------|
|-------|---|-------------------|----------------|----------------|----|---------------|------|

09, 10, 13, 20,  
25, 30, 40, 49,  
50, 60

**-01**  
= (1.60 mm) .062"  
thick card

**-L**  
= 10 μ" (0.25 μm)  
Gold on contact area,  
Matte Tin on tail

**-S**  
= 30 μ" (0.76 μm)  
Gold on contact area,  
Matte Tin on tail

**-BL**  
= Board Locks (09, 13,  
25, 40, 49, 50, 60 only)

**-L2**  
= ECDP Latching  
(09, 13, 25, 49 only)

Leave blank for  
Tray Packaging


**-TR**  
= Tape & Reel

**-FR**  
= Full Reel  
Tape & Reel Packaging  
(must order max.  
quantity per reel;  
contact Samtec for  
quantity breaks)


**HSEC8-RA**

**Card Mates:**  
(1.60 mm) .062"  
thick card,  
HSC8

**Cable Mates:**  
ECDP

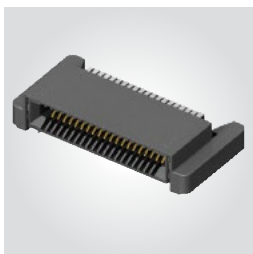


| POSITIONS PER ROW | A             | B             | C             |
|-------------------|---------------|---------------|---------------|
| 40                | (43.80) 1.724 | (18.90) .744  | (36.60) 1.441 |
| 50                | (51.80) 2.039 | (22.90) .902  | (44.60) 1.756 |
| 60                | (59.80) 2.354 | (26.90) 1.059 | (52.60) 2.071 |
| 40-BL             | (51.30) 2.020 | (18.90) .744  | (36.60) 1.441 |
| 50-BL             | (59.30) 2.335 | (22.90) .902  | (44.60) 1.756 |
| 60-BL             | (67.30) 2.650 | (26.90) 1.059 | (52.60) 2.071 |


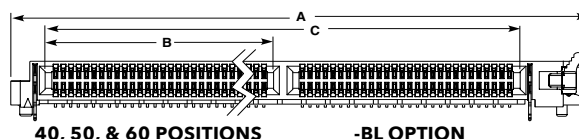


40, 50, & 60 POSITIONS

-BL OPTION

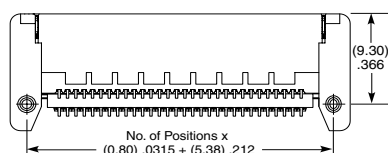

10, 20 & 30 POSITIONS

  

View complete specifications at: [samtec.com?HSEC8-RA](http://samtec.com?HSEC8-RA)

| HSEC8 | 1 | POSITIONS PER ROW | 01 | PLATING OPTION | D | EM2 |
|-------|---|-------------------|----|----------------|---|-----|
|-------|---|-------------------|----|----------------|---|-----|

10, 20, 30, 40,  
50, 60

**-L**  
= 10 μ" (0.25 μm)  
Gold on contact area,  
Matte Tin on tail


**-S**  
= 30 μ" (0.76 μm)  
Gold on contact area,  
Matte Tin on tail

**-EM2**  
= (1.60 mm) .062"  
thick PCB


**HSEC8-EM**

**Card Mates:**  
(1.60 mm) .062"  
thick card,  
HSC8

**Cable Mates:**  
ECDP

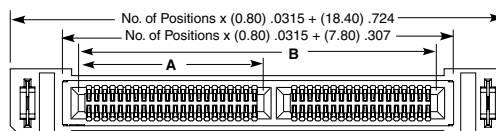


40, 50 & 60 POSITIONS

 

10, 20 & 30 POSITIONS

| POSITIONS PER ROW | A             | B             |
|-------------------|---------------|---------------|
| 40                | (18.90) .744  | (36.60) 1.441 |
| 50                | (22.90) .902  | (44.60) 1.756 |
| 60                | (26.90) 1.059 | (52.60) 2.071 |

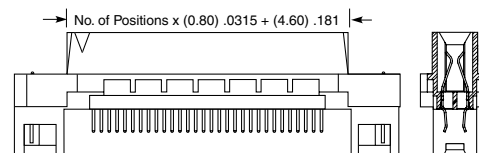

**Note:**  
Some sizes, styles and  
options are non-standard,  
non-returnable.

View complete specifications at: [samtec.com?HSEC8-EM](http://samtec.com?HSEC8-EM)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[HSEC8-160-01-S-D-EM2](#)