


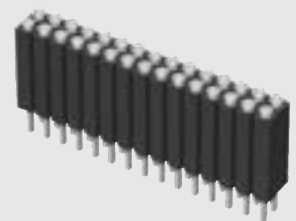

SS-132-G-2



ESD-115-TT-05

(2.54 mm) .100"

SS, SD, ESD, ESS, HSS SERIES

PRECISION MACHINED SOCKET STRIPS

Mates with:

TS, TD, HTS, BBS,
BBD, BBL, BDL, BHS

SPECIFICATIONS

For complete specifications see www.samtec.com?SS,
www.samtec.com?ESS,
www.samtec.com?SD,
www.samtec.com?ESD or
www.samtec.com?HSS

Insulator Material:

SS, SD, ESS, ESD= Black G.F. Polyester

HSS= Black Liquid Crystal Polymer

Contact:

BeCu

Shell:

Brass except Style 5A

Phosphor Bronze

Plating:

Au over 50 μ " (1.27 μ m) Ni or

Sn over 50 μ " (1.27 μ m) Ni

Operating Temp Range:

-55 °C to +125 °C

Lead Size Range:

(0.38 mm to 0.56 mm)

.015" to .022" DIA

and most IC leads

RoHS Compliant:

Yes

Lead-Free Solderable:

SS, SD, ESS, ESD:

No, Lead Wave only

HSS: Yes

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



FILE NO. E111594

TYPE STRIP	1	NO. PINS PER ROW	PLATING OPTION	LEAD STYLE	OPTION	OTHER OPTION
------------	---	------------------	----------------	------------	--------	--------------

01 thru 32
=SS, ESS Series


01 thru 36
=HSS, SD & ESD Series

SS
= Standard
Single Row Socket

HSS
= High Temp
Single Row Socket

ESS
= Elevated Single Row Socket


Styles -5A & -05 socket heads not countersunk.

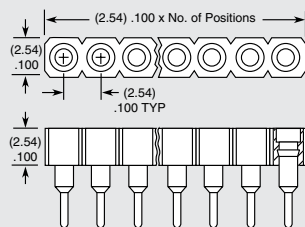

SD
= Standard Double Row Socket

ESD
= Elevated Double Row Socket

Style -5A not available.
Styles -5A & -05 socket heads not countersunk.

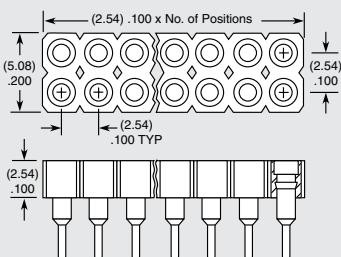

Note:
Some lengths, styles and options are non-standard, non-returnable.

-S
= 10 μ " (0.25 μ m) Gold contact, Tin shell (Styles 2 & 22 only)

-T
= 30 μ " (0.76 μ m) Gold contact, Tin shell


-G
= 30 μ " (0.76 μ m) Gold contact, 10 μ " (0.25 μ m) Gold shell

-TT
= Tin contact and shell (Styles 1, 2, 4, and 05 except LIF N/A)

LIF= Low Insertion Force


-L = Locking Socket

Add -L suffix for locking lead socket in end positions. Requires Style -2 or -22 and .035" $\pm$.003 DIA board hole.

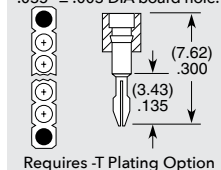

Requires -T Plating Option

-N
= Non Flush

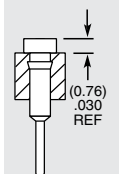


N/A Style -5A

ALSO AVAILABLE (MOQ Required)


- Locking lead option on ESS and ESD series

-1A, -1B OR -1C
For LIF specify -21A, -21B or -21C (SS, HSS, SD)

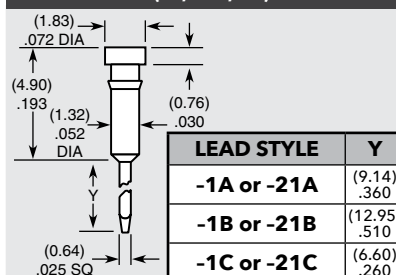


-2, -22*, -5A, or -38*

*For LIF specify -22 or -38 (SS, HSS, SD)

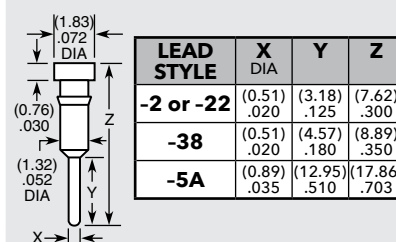

Locking lead available. See OPTION.

-03, -04, -05
For LIF specify -23 (ESS, ESD)

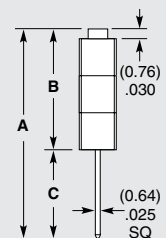

LEAD STYLE	A	B	C
-05	(17.86) .703	(13.46) .530	(4.39) .173
-03 or -23	(11.51) .453	(8.38) .330	(3.12) .123
-04	(14.05) .553	(10.92) .430	(3.12) .123

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[HSS-136-T-5A](#) [HSS-118-T-5](#) [HSS-120-T-5A](#) [HSS-126-T-5A](#) [HSS-117-T-28](#) [HSS-120-T-28](#) [HSS-125-T-5](#) [HSS-110-T-28](#) [HSS-136-T-28](#) [HSS-114-T-5](#) [HSS-136-T-5](#) [HSS-102-T-5A](#) [HSS-132-T-5](#) [HSS-120-T-5](#) [HSS-103-T-5](#) [HSS-105-T-5](#) [HSS-110-T-5](#) [HSS-104-T-5](#) [HSS-116-T-5A](#) [HSS-110-T-5A](#) [HSS-108-T-5A](#)