

(4.00 mm) .1575"

IJ5-04-05.0-L-S-1-TR

IJ5-01-05.0-L-S-1-TR

IJ5-04-05.0-L-D-1-TR

IJ5-08-05.0-L-S-1-TR

IJ5 SERIES

50 Ω HIGH ISOLATION RF JACKS

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com/IJ5

Shell Material:

Copper Alloy

Insulator Material:

Black LCP

Contact Material:

Copper Alloy

Dielectric Material:

Black LCP

Plating:

Au or Sn over

50 μ" (1.27 μm) Ni

Current Rating (Vertical):

Signals: 2.36 A per pin

(2 adjacent pins powered)

Grounds: 4.4 A per pin

(2 adjacent pins powered)

Operating Temp Range:

-55 °C to +125 °C

Dielectric

Withstanding Voltage:

600 VAC

Working Voltage:

200 VAC

RoHS Compliant:


Yes

Mates with:
IP5

IP5/IJ5 10 mm Stack Height	Frequency
Insertion Loss = 3 dB	10.5 GHz / 21.0 Gbps
Return Loss = 15 dB	5.5 GHz / 11.0 Gbps
Isolation = 60 dB	8.8 GHz / 17.6 Gbps
Isolation = 70 dB	7.6 GHz / 15.2 Gbps
Isolation = 80 dB	1.3 GHz / 2.6 Gbps

Complete test data available at www.samtec.com/IJ5 or contact sig@samtec.com

Single or
Double Row

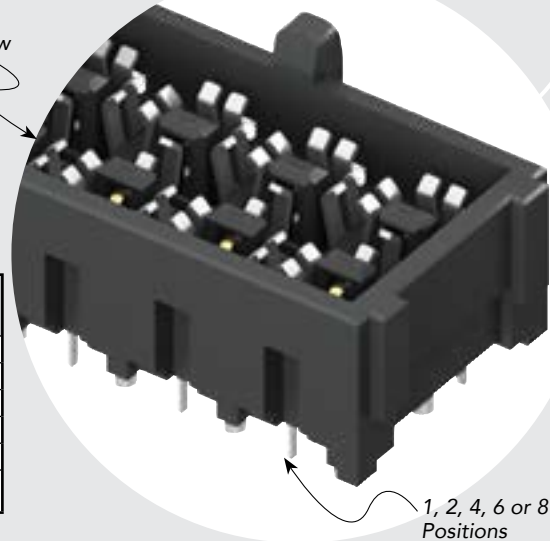

PROCESSING

Lead-Free Solderable:
Yes


RECOGNITIONS

For complete scope
of recognitions see
www.samtec.com/quality



FILE NO. E111594

APPLICATION

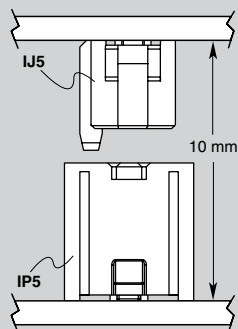


OTHER SOLUTIONS

- Cable assembly (see IJ5C Series)

IJ5	JACKS PER ROW	05.0	PLATING	ROW OPTION	TAIL	"X"R
	-01, -02, -04, -06, -08		-L = 10 μ" (0.25 μm) Gold on contact area, Matte Tin on tail	-S = Single Row -D = Double Row (Not available with -01)	-1 = (1.60 mm) .062" board thickness	-TR = Tape & Reel -FR = Full Reel Tape & Reel (must order max. quantity per reel; Contact Samtec for quantity breaks)

NO. OF JACKS	A
-01	(5.55) .219
-02	(9.55) .376
-04	(17.55) .691
-06	(25.55) 1.006
-08	(33.55) 1.321

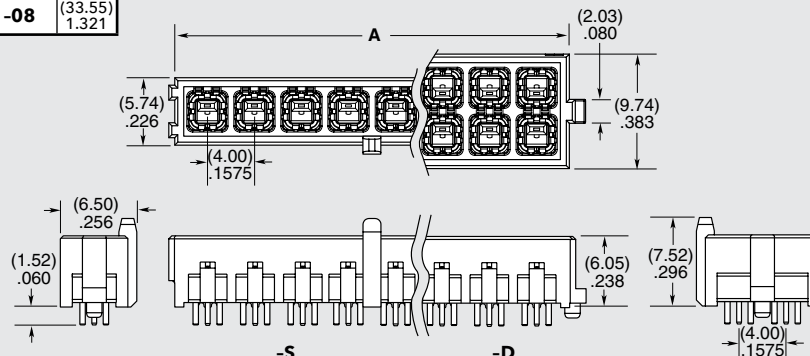

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[IJ5-04-05.0-L-S-1-TR](#) [IJ5-08-05.0-L-S-1-TR](#) [IJ5-02-05.0-L-S-1-TR](#) [IJ5-01-05.0-L-S-1-TR](#) [IJ5-02-05.0-L-D-1-TR](#) [IJ5-04-05.0-L-D-1-TR](#) [IJ5-06-05.0-L-S-1-TR](#) [IJ5-06-05.0-L-D-1-TR](#) [IJ5-08-05.0-L-D-1-TR](#) [IJ5C-02-1000-S-D-NUS](#) [IJ5C-02-1000-S-D-NUS-1](#) [IJ5C-02-1000-S-D-NUS-2](#) [IJ5C-02-0300-S-D-NUS-1](#) [IJ5C-04-0240-S-S-1](#) [IJ5C-04-0458-S-D-NUS-2](#) [IJ5C-04-0150-S-D-NUS-1](#) [IJ5C-06-0100-S-D-NUS-1](#) [IJ5C-06-0152-S-D-NUS-1](#) [IJ5C-04-0200-S-S-1](#) [IJ5C-04-0610-S-S-1](#) [IJ5C-06-0150-S-D-NUS-1](#) [IJ5C-08-0250-S-D-NUS-1](#) [IJ5C-02-1000-S-S-1](#) [IJ5C-02-1000-S-S-2](#) [IJ5C-06-0153-S-S-1](#) [IJ5C-06-0300-S-D-NUS-1](#) [IJ5C-06-0450-S-D-NUS-1](#) [IJ5C-06-0610-S-S-1](#) [IJ5C-02-0100-S-S-1](#) [IJ5C-02-0500-S-D-NUS-2](#) [IJ5C-02-0150-S-D-NUS-1](#) [IJ5C-04-0500-S-S-2](#) [IJ5C-08-0254-S-D-NUS-1](#) [IJ5C-08-0500-S-S-1](#) [IJ5C-08-0500-S-S-2](#) [IJ5C-02-0400-S-S-1](#) [IJ5C-04-0127-S-D-NUS-1](#) [IJ5C-08-0150-S-D-NUS-1](#) [IJ5C-08-1000-S-S-1](#) [IJ5C-02-0458-S-D-NUS-1](#) [IJ5C-02-0300-S-S-1](#) [IJ5C-04-0100-S-S-1](#) [IJ5C-01-0100-S-D-NUS](#) [IJ5C-04-0400-S-D-NUS-2](#) [IJ5C-08-0500-S-D-NUS-2](#) [IJ5C-08-0100-S-S-1](#) [IJ5C-08-0200-S-S-1](#) [IJ5C-08-1000-S-D-NUS-2](#) [IJ5C-04-0600-S-D-NUS-1](#) [IJ5C-04-0914-S-D-NDS-2](#) [IJ5C-04-1000-S-S-2](#) [IJ5C-04-0102-S-D-NUS-1](#) [IJ5C-04-0508-S-D-NUS-1](#) [IJ5C-02-0250-S-D-NUS-1](#) [IJ5C-06-0500-S-S-2](#) [IJ5C-04-0406-S-D-NUS-1](#) [IJ5C-02-0115-S-D-NUS-1](#) [IJ5C-02-0500-S-S-2](#) [IJ5C-08-0457-S-D-NUS-2](#) [IJ5C-08-0610-S-D-NUS-2](#) [IJ5C-02-0610-S-S-2](#) [IJ5C-02-0800-S-D-NUS-2](#) [IJ5C-04-0400-S-S-1](#) [IJ5C-08-1397-S-D-NUS-1](#) [IJ5C-08-2000-S-S-2](#) [IJ5C-04-0508-S-D-NUS-2](#) [IJ5C-08-0600-S-S-1](#) [IJ5C-04-0600-S-D-NDS-2](#) [IJ5C-01-0500-S-S-1](#) [IJ5C-04-0500-S-D-NUS-2](#) [IJ5C-04-2020-S-S-2](#) [IJ5C-02-0914-S-S-2](#) [IJ5C-04-0600-S-S-2](#) [IJ5C-02-1500-S-S-1](#) [IJ5C-02-0171-S-D-NUS-1](#) [IJ5C-08-0150-S-D-NUS-2](#) [IJ5C-08-2000-S-S-1](#) [IJ5C-02-0320-S-D-NUS-1](#) [IJ5C-06-0600-S-S-2](#) [IJ5C-01-0100-S-S-1](#) [IJ5C-01-0500-S-D-NUS-1](#) [IJ5C-04-0200-S-D-NDS-1](#) [IJ5C-04-0310-S-D-NUS-1](#) [IJ5C-04-0470-S-D-NUS-1](#) [IJ5C-08-0914-S-D-NUS-1](#) [IJ5C-08-1000-S-D-NUS-1](#) [IJ5C-02-0914-S-D-NDS-1](#) [IJ5C-04-0360-S-D-NUS-1](#) [IJ5C-06-0178-S-D-NUS-1](#) [IJ5C-06-1000-S-D-NUS-1](#) [IJ5C-08-2500-S-S-2](#) [IJ5C-02-0200-S-S-1](#) [IJ5C-04-1000-S-D-NUS-1](#) [IJ5C-04-0533-S-D-NDS-1](#) [IJ5C-08-0200-S-D-NUS-1](#) [IJ5C-02-0100-S-D-NDS-1](#) [IJ5C-06-0100-S-S-1](#) [IJ5C-08-0200-S-D-NDS-1](#) [IJ5C-08-0204-S-D-NUS-1](#) [IJ5C-08-1000-S-D-NDS-1](#)