

IJ5C-08-0600-S-D-NUS-1

IJ5C-04-0400-S-D-NUS-1

IJ5C SERIES

50 Ω HIGH ISOLATION RF CABLE ASSEMBLY

EDGE[®]
RATE
CONTACT

Positive latching system

1 Meter Cable Assembly	Frequency
Insertion Loss = 3 dB	9.5 GHz / 19.0 Gbps
Return Loss = 15 dB	2.2 GHz / 4.4 Gbps
Isolation = 60 dB	3.1 GHz / 6.2 Gbps

Performance and complete test data available at www.samtec.com?IJ5C or contact sja@samtec.com

IJ5C – **NO. OF POSITIONS** – **ASSEMBLED LENGTH** – **PLATING OPTION** – **END OPTION** – **END 2 OPTION** – **CABLE TYPE**

–01, –02, –04, –06, –08

–“XXXX”
= Assembled Length in millimeters
–0100 to –1000 (100 mm) 3.94” minimum

–S
= 30 μm (0.76 μm) Gold on contact

–S
= Single Ended

–D
= Double Ended

–NUS
= Notch up, straight P1 to P1


–NDS
= Notch down, straight P1 to PN

–1
= CTB-2650F-01 cable

–2
= RG 316 cable

NO. OF POSITIONS	A
–01	(20.87) .822
–02	(24.87) .979

NO. OF POSITIONS	A
-01	(20.87) .822
-02	(24.87) .979
-04	(32.87) 1.294
-06	(40.87) 1.609
-08	(48.87) 1.924

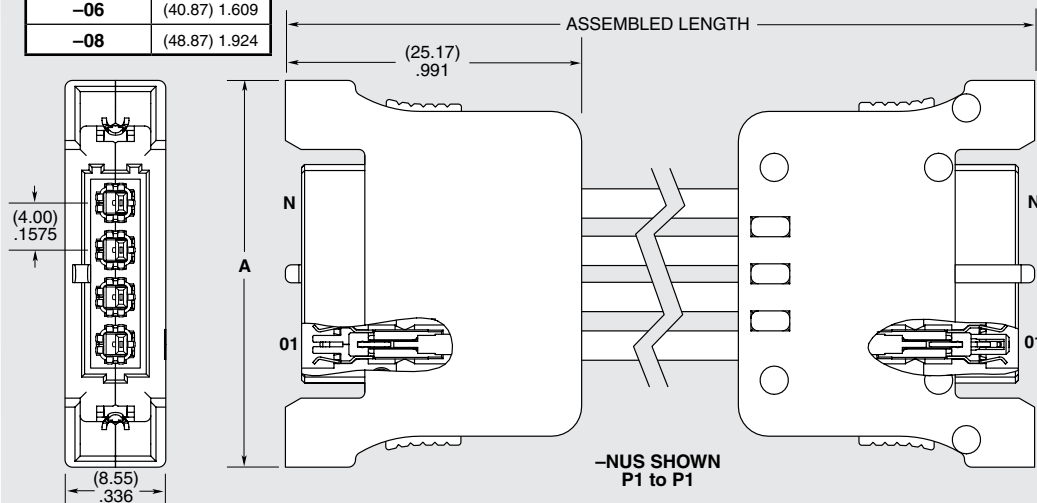

RU[®]
FILE NO. E111594

Note:
This Series is non-standard,
non-returnable.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[IJ5C-01-0100-S-S-1](#)