

(4.00 mm) .1575"

IJ5H-02-0600-S-2-02SP2

IJ5H-08-0300-S-2-03SP2

IJ5H SERIES

50 Ω HYBRID RF CABLE ASSEMBLY

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com/IJ5H

Insulator Material:

Black LCP

Contact Material:

Copper Alloy

Pin Material:

Copper Alloy

Dielectric Material:

Black LCP

Plating:

Au over 50 μ" (1.27 μm) Ni

Operating Temp Range:

-40 °C to +90 °C

RoHS Compliant:

Yes

Cable (-2):

Conductor Size:

26 AWG,

(0.51 mm) .020" dia.

Conductor Material:

Silver and Copper

Plated Steel Wire

Insulator Diameter:

(1.52 mm) .060"

Insulator Material:

PTFE

Shield Material:

Silver Plated Copper Wire

Jacket Material:

FEP

Jacket Diameter:

(2.54 mm) .100"

Bend Radius:

12.8 mm

Impedance:

50 Ω

Current Rating:

5 A DC

RoHS Compliant:

Yes

Mates with:

IP5

End 2 Mates:

SMA, MCX,

MMCX, SMB5

Low-cost isolated
transmission line
system

RG 316 Cable

Positive
latching

1, 2, 4, 6 or 8
Positions

**EDGE
RATE®**
 CONTACT

Choice of traditional
RF end options

IJ5H**NO. OF
POSITIONS****ASSEMBLED
LENGTH****END 1
PLATING****CABLE
TYPE****END 2
OPTION**
**-01, -02,
-04, -06, -08**

- "XXXX"
= Assembled Length
in millimeters
-0300 to -1000
(1000 mm) 39.40"
maximum

-S
= 30 μ" (0.76 μm)
Gold on contact

-2
= RG 316
cable


**Specify
END 2
OPTION
from
chart.**

NO. OF POSITIONS	A
-01	(20.87) .822
-02	(24.87) .979
-04	(32.87) 1.294
-06	(40.87) 1.609
-08	(48.87) 1.924

END 2 OPTION
All Gold
-01SP1 = SMA Straight Plug
-01RP1 = SMA Right-angle plug
-01BJ1 = SMA Bulkhead Jack
-01SR1 = SMA Straight Bulkhead Jack, Sealed, Reversed Polarity

END 2 OPTION
All Gold
-02SP1 = MCX Straight Plug
-02RP1 = MCX Right-angle Plug
-03SP1 = MMCX Straight Plug
-03RP1 = MMCX Right-angle Plug
-07SP1 = SMB Straight Plug

END 2 OPTION
Gold/Nickel Combination
-02SP2 = MCX Straight Plug
-03SP2 = MMCX Straight Plug
-07SP2 = SMB Straight Plug

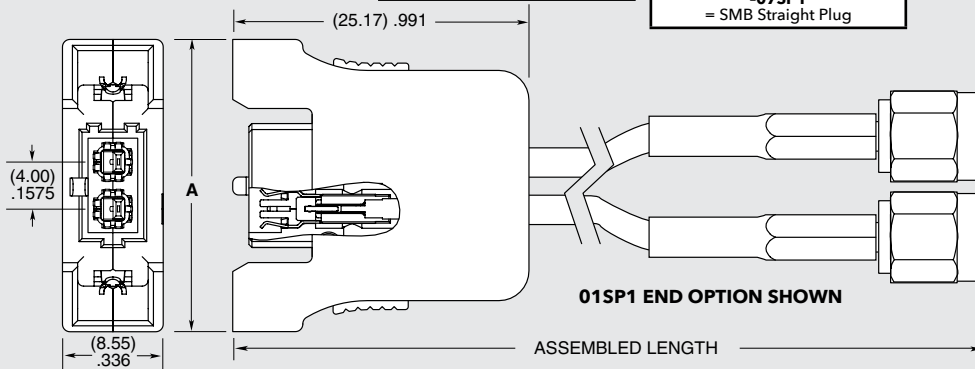

Note:
This Series is non-standard,
non-returnable.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[IJ5H-04-0300-S-2-03SP1](#) [IJ5H-08-0300-S-2-02SP2](#) [IJ5H-02-0500-S-2-01SP1](#) [IJ5H-08-0300-S-2-03SP1](#) [IJ5H-04-1000-S-2-01SP1](#) [IJ5H-06-0300-S-2-01SP1](#) [IJ5H-08-1000-S-2-01SP1](#) [IJ5H-08-0300-S-2-07SP1](#) [IJ5H-02-0300-S-2-07SP1](#) [IJ5H-08-0914-S-2-01SP1](#) [IJ5H-08-1000-S-2-07SP1](#) [IJ5H-04-0500-S-2-07SP1](#) [IJ5H-04-0400-S-2-01SP1](#) [IJ5H-06-1000-S-2-07SP1](#) [IJ5H-08-0400-S-2-01SP1](#) [IJ5H-02-0305-S-2-01SP1](#) [IJ5H-04-0350-S-2-01SP1](#) [IJ5H-04-0500-S-2-01SP1](#) [IJ5H-04-0572-L-2-02SP2](#) [IJ5H-04-1000-S-2-07SP1](#) [IJ5H-06-0500-S-2-01SP1](#) [IJ5H-06-0914-S-2-01SP1](#) [IJ5H-08-0305-S-2-01SP1](#) [IJ5H-08-0610-S-2-01SP1](#) [IJ5H-02-0350-S-2-01SP1](#) [IJ5H-04-0305-S-2-01SP1](#) [IJ5H-04-0301-L-2-03SP1](#) [IJ5H-04-1000-S-2-03SP1](#) [IJ5H-06-0400-S-2-07SP1](#) [IJ5H-01-0300-S-2-07SP1](#) [IJ5H-02-0300-S-2-02SP1](#) [IJ5H-08-3000-S-2-01SP1](#) [IJ5H-02-0900-S-2-01SP1](#) [IJ5H-04-1200-S-2-03SP1](#) [IJ5H-04-0330-S-2-03SP1](#) [IJ5H-04-0750-S-2-01SP1](#) [IJ5H-02-0381-S-2-01SP1](#) [IJ5H-02-0400-S-2-01SP1](#) [IJ5H-04-0460-S-2-07SP1](#) [IJ5H-02-0914-S-2-03SP1](#) [IJ5H-04-0600-S-2-01SP1](#) [IJ5H-08-0750-S-2-01SP1](#) [IJ5H-02-0333-S-2-01SP1](#) [IJ5H-06-0300-S-2-02SP1](#) [IJ5H-06-0500-S-2-03SP1](#) [IJ5H-08-0760-S-2-01SP1](#) [IJ5H-02-0300-S-2-01SP1](#) [IJ5H-08-0500-S-2-01SP1](#) [IJ5H-08-1000-S-2-02SP1](#) [IJ5H-02-0666-S-2-07SP1](#) [IJ5H-04-0450-S-2-01SP1](#) [IJ5H-08-0600-S-2-01SP1](#) [IJ5H-04-0700-S-2-01SP1](#) [IJ5H-08-0305-S-2-03SP1](#) [IJ5H-08-0762-S-2-01SP1](#) [IJ5H-06-0350-S-2-03SP1](#) [IJ5H-08-1000-S-2-03SP1](#) [IJ5H-08-1000-L-2-01SP1](#) [IJ5H-04-0300-S-2-01SP1](#) [IJ5H-06-0610-S-2-01SP1](#) [IJ5H-02-1000-S-2-01SP1](#) [IJ5H-08-3000-S-2-07SP2](#) [IJ5H-08-1200-S-2-01SP1](#) [IJ5H-08-3700-S-2-01SP1](#) [IJ5H-04-0305-S-2-03SP1](#) [IJ5H-04-1000-S-2-02SP1](#) [IJ5H-06-0310-S-2-01SP1](#) [IJ5H-06-0457-S-2-01SP1](#) [IJ5H-02-0300-S-2-03SP1](#) [IJ5H-04-0609-S-2-01SP1](#) [IJ5H-06-1000-S-2-01SP1](#) [IJ5H-08-0600-S-2-03SP1](#) [IJ5H-02-0305-S-2-07SP1](#) [IJ5H-04-0305-S-2-02SP1](#) [IJ5H-04-0305-S-2-03SP2](#) [IJ5H-02-0600-S-2-01SP1](#) [IJ5H-04-0300-S-2-03SP2](#) [IJ5H-04-0650-S-2-02SP1](#) [IJ5H-06-0300-S-2-03SP1](#) [IJ5H-08-0300-S-2-02SP1](#) [IJ5H-06-0450-S-2-01SP1](#) [IJ5H-08-0400-S-2-07SP1](#) [IJ5H-06-1000-S-2-03SP1](#) [IJ5H-01-0500-S-2-01SP1](#) [IJ5H-02-0600-S-2-02SP2](#) [IJ5H-04-0914-S-2-01SP1](#) [IJ5H-08-0300-S-2-01SP1](#) [IJ5H-08-3400-S-2-01SP1](#)