



MICRO EDGE CARD SYSTEMS

0.50 mm, 0.635 mm, 0.80 mm, 1.00 mm, 1.27 mm, 2.00 mm PITCH

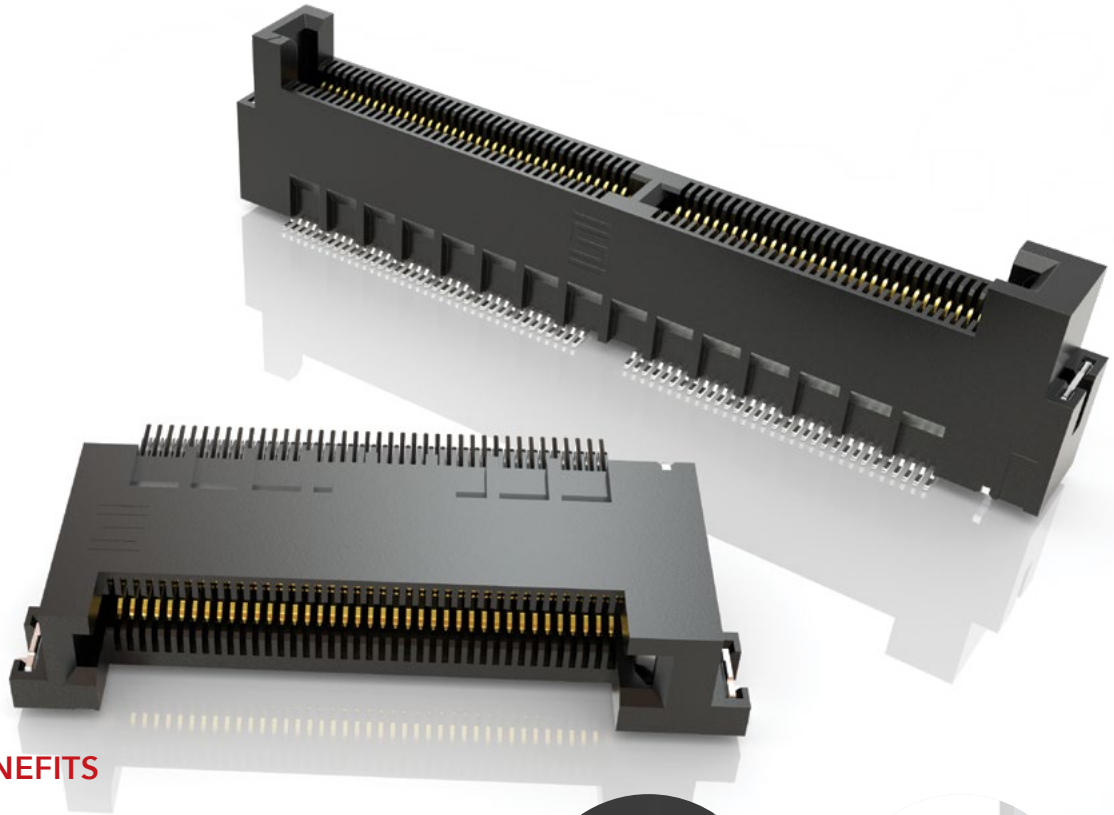


FEATURES & BENEFITS

- Up to 56 Gbps PAM4
- PCI Express® 4.0 (MEC5 Series)
- Solutions for .062" (1.60 mm), and .093" (2.36 mm) thick cards
- Choice of pitch: 0.50 mm, 0.635 mm, 0.80 mm, 1.00 mm, 1.27 mm, 2.00 mm
- Vertical, right-angle, edge mount
- Available in surface mount and through-hole

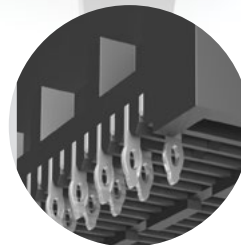

Staggered press-fit tails
(MEC8-VP)

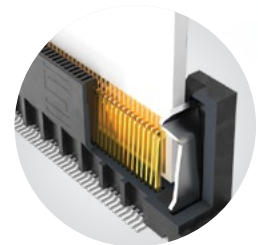

Justification beam ensures
card and body are flushed
(MEC5)

KEY SPECIFICATIONS

SERIES	PITCH	TOTAL POSITIONS	INSULATOR MATERIAL	CONTACT MATERIAL	OPERATING TEMP RANGE	CURRENT RATING	VOLTAGE RATING	LEAD-FREE SOLDERABLE
MEC5	0.50 mm	60-200	Black LCP	Phosphor Bronze	-55 °C to +125 °C	1.5 A (2 pins)	125 VAC	Yes
MEC6	0.635 mm	20-140	Black LCP	Phosphor Bronze	-55 °C to +125 °C	2.4 A (2 pins)	195 VAC	Yes
MEC8	0.80 mm	20-140	Black LCP	Phosphor Bronze	-55 °C to +125 °C	1.8 A (4 pins)	185 VAC	Yes
MEC1	1.00 mm	20-140	Black LCP	Phosphor Bronze	-55 °C to +125 °C	2.2 A (2 pins)	250 VAC	Yes
MECF	1.27 mm	10-100	Black/Natural LCP	BeCu	-55 °C to +125 °C	3.5 A (2 pins)	280 VAC	Yes
MEC2	2.00 mm	10-100	Black/Natural LCP	BeCu	-55 °C to +125 °C	3.5 A (2 pins)	238 VAC	Yes

(0.635 mm) .025" PITCH • VERTICAL AND RIGHT-ANGLE EDGE CARD SOCKET

MEC6	- 1	POSITIONS PER ROW	- 02	PLATING OPTION	- DV	A	OPTION	"X"R
-------------	------------	--------------------------	-------------	-----------------------	-------------	----------	---------------	-------------

10, 20, 30, 40,
50, 60, 70

-L
= 10 μ " (0.25 μ m)
Gold on contact,
Matte Tin on tail

-K
= (5.50 mm) 2.17" DIA
Polyimide Pick
& Place Pad


Leave blank
for Tray Packaging

-TR
= Tape & Reel


-FR
= Full Reel
Tape & Reel
(must order max.
quantity per reel;
contact Samtec for
quantity breaks)

MEC6-DV


Card Mates:
(1.60 mm) .062"
thick card

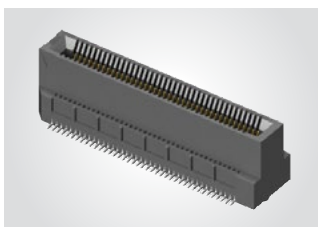



POSITIONS PER ROW	A	B
50	(21.06) .829	(36.49) 1.437
60	(24.87) .979	(42.84) 1.687
70	(28.68) 1.129	(49.19) 1.937

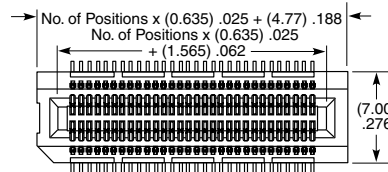

10, 20, 30 & 40 POSITIONS

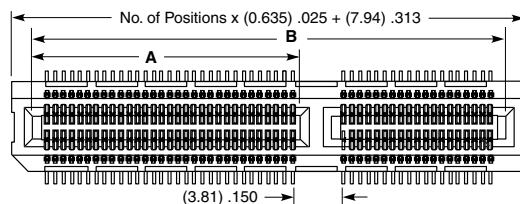

50, 60 & 70 POSITIONS

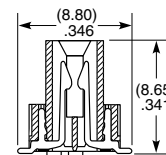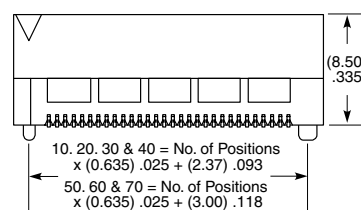

View complete specifications at: samtec.com?MEC6-DV

MEC6	- 1	POSITIONS PER ROW	- 02	PLATING OPTION	- D	TAIL	OPTIONS
-------------	------------	--------------------------	-------------	-----------------------	------------	-------------	----------------

10, 20, 30,
40, 50

-L
= 10 μ " (0.25 μ m)
Gold on contact,
Matte Tin on tail



-RA1
= Right angle

-TR
= Tape & Reel


-FR
= Full Reel Tape & Reel
(must order max. quantity
per reel; contact Samtec
for quantity breaks)

MEC6-RA



Card Mates:
(1.60 mm) .062"
thick card

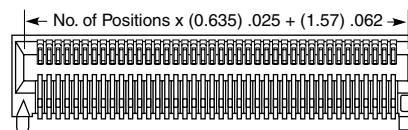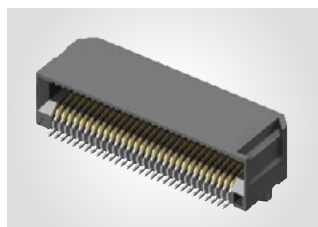

10, 20, 30 & 40 POSITIONS

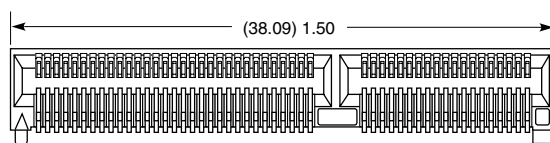

50 POSITIONS

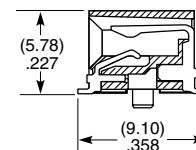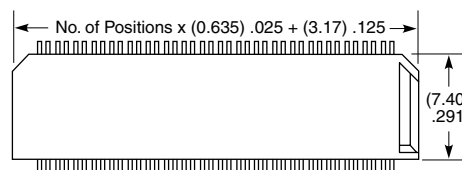

Note:
Some sizes, styles and
options are non-standard,
non-returnable.

View complete specifications at: samtec.com?MEC6-RA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[MEC6-120-02-L-D-RA1](#) [MEC6-110-02-L-D-RA1](#) [MEC6-120-02-S-D-RA1](#) [MEC6-120-02-L-D-RA1-TR](#) [MEC6-150-02-L-D-RA1](#) [MEC6-130-02-L-D-RA1](#) [MEC6-140-02-S-D-RA1](#) [MEC6-150-02-S-D-RA1](#) [MEC6-150-02-L-D-RA1-TR](#) [MEC6-140-02-L-D-RA1](#) [MEC6-110-02-S-D-RA1](#) [MEC6-140-02-L-D-RA1-TR](#) [MEC6-110-02-L-D-RA1-TR](#) [MEC6-150-02-S-D-RA1-TR](#) [MEC6-130-02-S-D-RA1](#) [MEC6-130-02-S-D-RA1-TR](#) [MEC6-140-02-S-D-RA1-TR](#) [MEC6-110-02-S-D-RA1-TR](#) [MEC6-118-02-L-D-RA1](#) [MEC6-120-02-S-D-RA1-TR](#) [MEC6-130-02-L-D-RA1-TR](#)