


HORIZONTAL & MODIFIED HEADERS

(2.00 mm) .0787" PITCH • MMT/MTMM SERIES

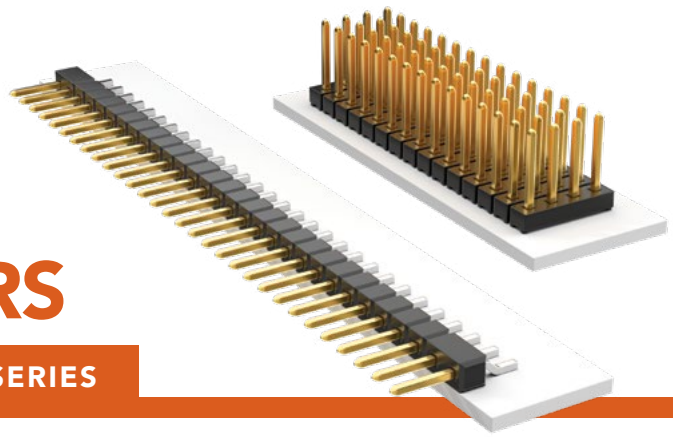

MMT/MTMM

Board Mates:

CLT, SQT*, SQW, ESQT,
TLE, SMM, MMS

Cable Mates:

TCSD

*Important Note:

SQT will not mate to the
MMT -02 lead style.

SPECIFICATIONS

Insulator Material:

Black Liquid Crystal Polymer

Terminal Material:

Phosphor Bronze

Plating:

Au or Sn over
50 μ" (1.27 μm) Ni

Operating Temp Range:

-55 °C to +105 °C with Tin;
-55 °C to +125 °C with Gold

PROCESSING

Lead-Free Solderable:

Yes

SMT Lead Coplanarity (MMT):

(0.10 mm) .004" max (02-25)

(0.15 mm) .006" max (26-36)*

*(.004" stencil solution
may be available; contact
ipg@samtec.com)

MMT	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	ROW OPTION	OPTION
		02 thru 36	-01 = (3.20 mm) .126" post -02 = (4.45 mm) .175" post	-F = Gold flash on post, Matte Tin on tail -L = 10 μ" (0.25 μm) Gold post, Matte Tin on tail -T = Matte Tin	-SH = Single Row -DH = Double Row -MT = Double Row Mixed Technology	-K = (4.00 mm) .157" DIA Polyimide Film Pick & Place Pad (3 positions min.) -P = Pick & Place Pad (2 positions min.) -"XXX" = Polarized Position Specify position of omitted pin -TR = Tape & Reel -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

ALSO AVAILABLE MOQ Required

Alignment pins
Locking clips
Molded pick &
place pads

MTMM	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	ROW OPTION	POST HEIGHT	OPTION
		01 thru 50	Specify LEAD STYLE from chart	-F = Gold flash on post, Matte Tin on tail -L = 10 μ" (0.25 μm) Gold post, Matte Tin on tail -T = Matte Tin	-S = Single Row -D = Double Row -Q = Quad Row	- "XXX" = Post Height in inches (0.13 mm) .005" increments Example: -070 = (1.78 mm) .070"	- "XXX" = Polarized Position Specify position of omitted pin

LEAD STYLE	OAL
-02	(6.48) .255
-03	(7.67) .302
-04	(8.20) .323
-05	(9.58) .377
-06	(10.08) .397
-07	(11.58) .456
-08	(12.09) .476
-09	(13.59) .535
-10	(14.10) .555
-11	(15.09) .594
-12	(15.60) .614
-13	(17.09) .673
-14	(19.08) .751
-15	(21.08) .830

Note:

Some lengths, styles and
options are non-standard,
non-returnable.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[MMT-102-01-F-DV](#) [MMT-102-01-T-DV](#) [MMT-102-01-S-DV](#) [MMT-103-02-SM-MT](#) [MMT-103-02-T-DV-P-TR](#) [MMT-106-01-L-MT-FR](#) [MMT-113-02-F-DH-A-P-TR](#) [MMT-132-01-L-DH-P-FR](#) [MMT-134-01-L-DH-P-FR](#) [MMT-106-02-F-DH-A-TR](#) [MMT-110-02-F-DH-A-K-FR](#) [MMT-106-02-F-DH-A-FR](#) [MMT-110-02-F-SH-A-P-TR](#) [MMT-112-02-F-DH-A-K](#) [MMT-107-01-F-DH-P-FR](#) [MMT-107-01-F-DH-FR](#) [MMT-107-01-F-DH-P-TR](#) [MMT-110-02-F-SH-LC](#) [MMT-112-02-F-DH-FR](#) [MMT-113-02-F-DH-A-P-FR](#) [MMT-105-01-T-SH-A-P](#)