


POWER™ STRIP™ 40

(6.35 mm) .250" PITCH • 40 A CABLE ASSEMBLY/COMPONENTS

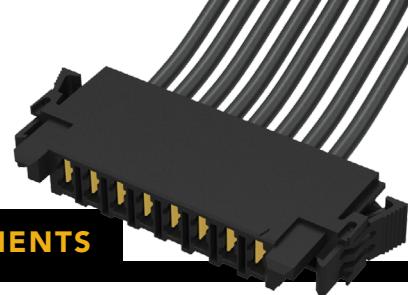


PESS	NO. OF POSITIONS	WIRE GAUGE	PLATING OPTION	ASSEMBLED LENGTH	END 1 OPTION	END 2 OPTION
	-02, -04, -06, -08	-10 -12	-L = 10 μ " (0.25 μ m) Gold on contact, Matte Tin on tail	"XX.XX" = Wire length in inches (152.4 mm) 06.00" min.	-SR = Single End	(Available with -DR only)
			-T = Matte Tin on tail		-DR = Double End	-NUS = Notch up, straight (Available with -DR only)

PESS
Board Mates:
PET

SPECIFICATIONS

Insulator Material: Nylon Black
Contact Material: Copper Alloy
Plating: Sn or Au over 50 μ " (1.27 μ m) Ni
Operating Temp Range: -30 °C to +105 °C
Voltage Rating: 450 VAC/636 VDC
Wire: 10 or 12 AWG

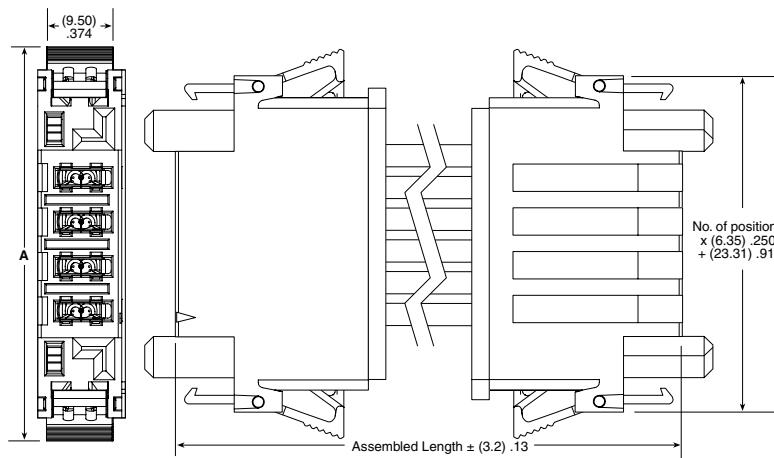





NO. OF POSITIONS	A
-02	(43.9) 1.73
-04	(56.6) 2.23
-06	(69.3) 2.73
-08	(82.0) 3.23

PESS/PET	WIRE GAUGE	CURRENT RATING (PER PIN)
	10 AWG	34.5 A
	12 AWG	29.7 A

1 PIN POWERED

View complete specifications at: samtec.com/PESS

IPS6	POSITIONS PER ROW	01	LATCH	SERIES	WIRE GAUGE	PLATING OPTION
	-02, -04, -06, -08		-L = Latch	CC10R = Contact, Full Reel	-1012 = 10 to 12 AWG	-L = 10 μ " (0.25 μ m) Gold on contact, Matte Tin on tail
				CC10L = Contact, Loose		-T = Matte Tin on tail

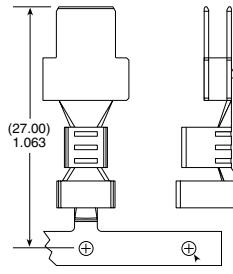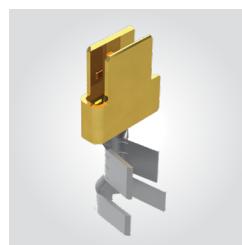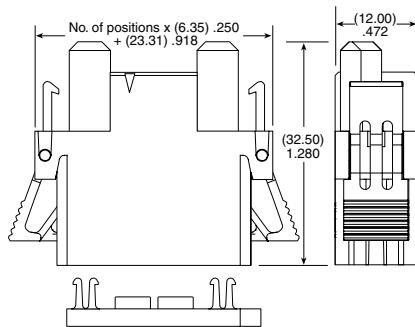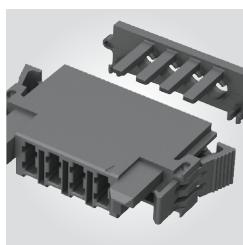

TOOLING

Hand Tool: CAT-HT-310-1012-14

Mini Applicator: CAT-MC-310-1012-XX-02

Note:
Some lengths, styles and options are non-standard, non-returnable

View complete specifications at: samtec.com/IPS6, samtec.com/CC10L & samtec.com/CC10R

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[PESS-02-10-L-16.00-SR](#) [PESS-02-10-L-40.00-DR-NUS](#) [PESS-02-10-L-48.00-SR](#) [PESS-02-10-L-22.00-SR](#) [PESS-02-10-S-20.00-DR-NUS](#) [PESS-02-10-S-80.00-DR-NDS](#) [PESS-02-10-L-36.00-DR-NUS](#) [PESS-02-10-T-10.00-SR](#) [PESS-02-12-L-16.00-DR-NDS](#) [PESS-02-12-S-12.00-SR](#) [PESS-04-10-L-15.00-SR](#) [PESS-04-10-L-50.00-DR-NUS](#) [PESS-04-10-L-60.00-SR](#) [PESS-02-10-L-90.00-SR](#) [PESS-02-10-T-36.00-DR-NDS](#) [PESS-02-12-L-36.00-DR-NUS](#) [PESS-02-12-L-39.37-DR-NUS](#) [PESS-04-10-L-10.00-DR-NDS](#) [PESS-04-10-L-12.00-DR-NDS](#) [PESS-04-10-L-12.00-DR-NUS](#) [PESS-04-10-L-99.99-SR](#) [PESS-04-10-S-24.00-DR-NDS](#) [PESS-04-12-L-08.00-DR-NUS](#) [PESS-02-10-L-22.00-DR-NDS](#) [PESS-02-10-L-22.50-DR-NDS](#) [PESS-02-10-L-24.00-SR](#) [PESS-02-10-S-20.00-DR-NDS](#) [PESS-02-12-T-12.00-SR](#) [PESS-02-12-T-20.00-SR](#) [PESS-04-10-L-22.00-SR](#) [PESS-04-10-T-10.00-SR](#) [PESS-04-10-T-24.00-DR-NDS](#) [PESS-04-10-T-24.00-SR](#) [PESS-04-12-L-20.00-DR-NDS](#) [PESS-04-12-L-24.00-SR](#) [PESS-04-12-L-30.00-DR-NDS](#) [PESS-04-12-T-18.00-SR](#) [PESS-04-12-T-36.00-DR-NDS](#) [PESS-06-10-S-36.00-SR](#) [PESS-06-10-S-80.00-DR-NDS](#) [PESS-08-10-L-10.00-DR-NDS](#) [PESS-08-10-S-14.00-SR](#) [PESS-02-10-L-09.00-DR-NDS](#) [PESS-02-10-L-60.00-SR](#) [PESS-02-10-L-72.00-DR-NDS](#) [PESS-02-10-L-99.00-SR](#) [PESS-02-12-L-06.01-SR](#) [PESS-02-12-L-12.00-SR](#) [PESS-02-12-L-36.00-SR](#) [PESS-04-12-L-09.00-SR](#) [PESS-04-12-S-14.00-SR](#) [PESS-06-10-L-36.00-DR-NUS](#) [PESS-06-10-L-39.37-DR-NUS](#) [PESS-06-12-L-08.00-SR](#) [PESS-06-12-L-18.00-SR](#) [PESS-08-10-T-30.00-SR](#) [PESS-08-10-T-39.37-SR](#) [PESS-02-10-L-07.87-DR-NDS](#) [PESS-02-10-L-18.00-SR](#) [PESS-02-10-T-26.00-SR](#) [PESS-02-12-L-24.00-DR-NDS](#) [PESS-04-10-L-08.00-DR-NUS](#) [PESS-04-12-T-06.01-SR](#) [PESS-02-10-L-16.00-DR-NDS](#) [PESS-02-12-L-15.00-DR-NUS](#) [PESS-02-12-L-24.00-SR](#) [PESS-02-12-L-30.00-SR](#) [PESS-02-12-T-25.40-SR](#) [PESS-04-10-L-20.00-DR-NUS](#) [PESS-04-10-L-48.00-DR-NDS](#) [PESS-04-10-T-07.87-DR-NUS](#) [PESS-04-12-L-132.0-SR](#) [PESS-04-12-L-30.00-SR](#) [PESS-04-12-L-36.00-SR](#) [PESS-04-12-T-08.00-DR-NUS](#) [PESS-04-12-T-12.00-DR-NUS](#) [PESS-06-10-L-40.00-DR-NUS](#) [PESS-06-10-L-80.00-SR](#) [PESS-08-10-L-12.00-DR-NUS](#) [PESS-08-12-L-06.00-DR-NUS](#) [PESS-08-12-L-08.00-SR](#) [PESS-02-12-L-12.00-DR-NDS](#) [PESS-06-12-L-12.60-SR](#) [PESS-06-12-L-15.75-DR-NDS](#) [PESS-08-10-L-56.00-SR](#) [PESS-02-10-L-10.00-DR-NDS](#) [PESS-02-10-L-20.00-DR-NUS](#) [PESS-04-12-T-24.00-SR](#) [PESS-06-12-S-12.00-SR](#) [PESS-02-12-L-09.00-DR-NDS](#) [PESS-04-10-T-15.00-SR](#) [PESS-04-10-T-72.00-DR-NUS](#) [PESS-04-12-L-06.01-SR](#) [PESS-02-10-L-39.37-SR](#) [PESS-04-10-L-06.01-DR-NDS](#) [PESS-02-12-L-08.70-SR](#) [PESS-04-12-L-38.00-SR](#) [PESS-06-12-L-11.81-DR-NDS](#) [PESS-08-10-L-18.00-SR](#) [PESS-08-10-L-84.00-SR](#)