


(2.54 mm) .100"

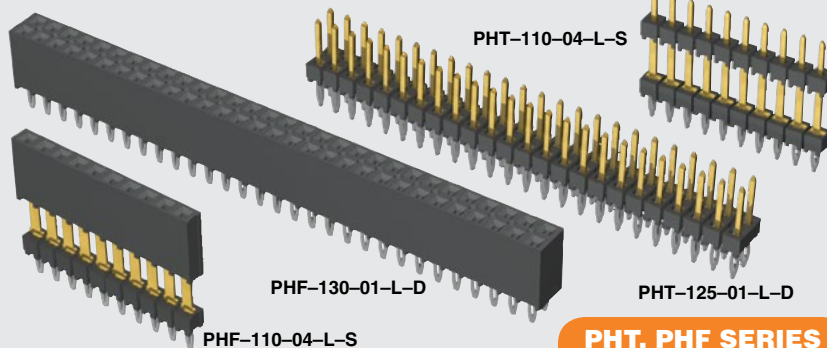

PHT, PHF SERIES

PRESS-FIT HEADERS & SOCKETS

PHT Board Mates:

SSW, SSQ, ESW,
ESQ, BCS, BSW,
CES, SLW, PHF, SSM

PHT Cable Mates:

IDSD, IDSS

PHF Board Mates:

TSW, MTSW, MTLW,
EW, ZW, TSS, ZSS,
TSM, TSSH, PHT, DW, HW

SPECIFICATIONS

For complete specifications
see www.samtec.com?PHT
or www.samtec.com?PHF

Insulator Material:

Liquid Crystal Polymer

Contact Material:

Phosphor Bronze

Plating:

Au or Sn over

50 μ " (1.27 μ m) Ni

Current Rating (PHT/PHF):

4.8 A per pin

(2 pins powered)

Operating Temp Range:

-55 °C to +125 °C with Gold

(PHF) Insertion Depth:

(3.68 mm) .145" to

(6.35 mm) .250"

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[PHT-140-02-L-S](#)