

SERIES	PINS PER ROW	WIRE GAUGE	K	ASSEMBLED LENGTH	END OPTION	LATCH OPTION
PMSSD = Double Row PVC Cable	-02, -03	-16	-K = Keyed Polarization	-"XX.XX" = Wire length in inches (88.90 mm) 03.50" min.	-S = Single End	-LUS = Plastic Latch up, straight
PMSSDT = Double Row Blue *Teflon® Cable (24 AWG only)	-04, -05	-18				-LDS = Plastic Latch down, straight
PMSS = Single Row PVC Cable	-08, -10	-206 (20 AWG/600 volts)			-D = Double End (Latch Required)	-LUX* = Plastic Latch up, crossed
PMSSS = Single Row Blue *Teflon® Cable (24 AWG only)	-15* (Standard sizes) *Only available for double row	-22				-LDS* = Plastic Latch down, crossed
		-24				*(PMSSD/PMSSDT only)

PMSSD, PMSSDT, PMSS, PMSSS Board Mates:

 
IPBT

*DuPont™ Teflon® is a registered trademark of the E.I. du Pont de Nemours and Company or its affiliates.


Notes:

Teflon® cable is intended for crimp only. Contact Samtec for solderable cable applications.


For wiring option information refer to drawing on web.



PMSS/PMSSS

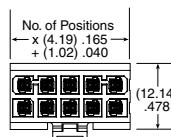




PMSSD/PMSSDT

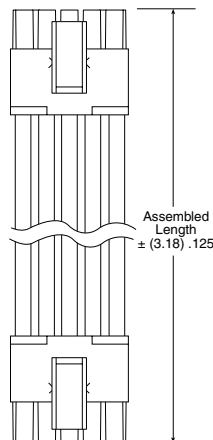

PMSSD/IPBT	
WIRE GAUGE	CURRENT RATING (PER PIN)
16 AWG	10.3 A
18 AWG	8.8 A
22 AWG	5.7 A
24 AWG	5.2 A

2 PIN POWERED

View complete specifications at: samtec.com?PMSSD, samtec.com?PMSSDT, samtec.com?PMSS & samtec.com?PMSSS

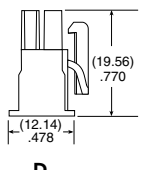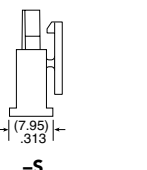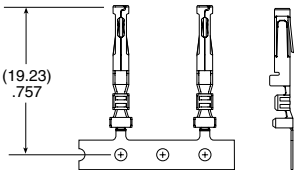IPBD	POSITIONS PER ROW	ROW OPTION	K	SERIES	WIRE GAUGE	01	T	SP
	-02, -03, -04, -05, -08, -10, -15 (Standard sizes)	-S = Single Row -D = Double Row	-K = Keyed Polarization	CC69L = Contact, Loose CC69R = Contact, Full Reel (4,000 Parts per Reel)	-2024 = 20 to 24 AWG -1620 = 16 to 20 AWG		-T = Tin	
  				 				

TOOLING

Hand Tool: CAT-HT-169-1620-13 (16-20 AWG)
Hand Tool: CAT-HT-169-2024-13 (20-24 AWG)

Mini Applicator: CAT-MC-169-1620-XX-02 (16-20 AWG)
Mini Applicator: CAT-MC-169-2024 XX-01 (20-24 AWG)
Extraction Tool: CAT-EX-169-01

Note:

Some lengths, styles and options are non-standard, non-returnable.

View complete specifications at: samtec.com?IPBD, samtec.com?CC69L & samtec.com?CC69R

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[PMSDT-03-24-K-39.37-S](#) [PMSDT-02-24-K-10.00-D-LUS](#) [PMSDT-03-24-K-39.37-D-LUS](#) [PMSDT-02-24-K-12.00-S](#)
[PMSDT-02-24-K-03.90-D-LDS](#) [PMSDT-04-24-K-03.50-D-LDS](#) [PMSDT-04-24-K-19.68-S](#) [PMSDT-10-24-K-05.91-S](#)
[PMSDT-10-24-K-07.87-S](#) [PMSDT-10-24-K-30.00-S](#) [PMSDT-02-24-K-07.00-S](#) [PMSDT-08-24-K-18.00-S](#) [PMSDT-10-](#)
[24-SP-80.00-S-M](#) [PMSDT-04-24-K-03.25-D-LUS](#) [PMSDT-10-24-K-80.00-S-M](#) [PMSDT-04-24-K-03.00-S](#) [PMSDT-04-](#)
[24-K-30.00-S](#) [PMSDT-04-24-K-99.99-S](#) [PMSDT-02-24-K-03.50-D-LUS](#) [PMSDT-04-24-K-06.00-S](#) [PMSDT-02-24-K-](#)
[40.00-S](#) [PMSDT-05-24-K-06.00-D-LDS](#) [PMSDT-05-24-K-10.00-S](#) [PMSDT-05-24-K-10.00-S-M](#) [PMSDT-03-24-K-24.00-](#)
[D-LUS](#) [PMSDT-04-24-K-22.00-S](#) [PMSDT-05-24-K-15.00-S-M](#) [PMSDT-02-24-K-24.00-D-MUS](#) [PMSDT-02-24-K-99.99-](#)
[S](#) [PMSDT-03-24-K-05.00-S](#) [PMSDT-03-24-K-09.84-S](#) [PMSDT-03-24-K-17.00-S-M](#) [PMSDT-03-24-K-99.99-S](#) [PMSDT-](#)
[04-24-K-22.00-S-M](#) [PMSDT-04-24-K-32.00-D-LUS](#) [PMSDT-05-24-K-20.00-S](#) [PMSDT-05-24-K-30.00-S](#) [PMSDT-05-24-](#)
[K-10.00-D-LDX](#) [PMSDT-02-24-K-07.00-D-LUS](#) [PMSDT-02-24-K-08.00-S](#) [PMSDT-02-24-K-03.50-D-LDS](#) [PMSDT-02-](#)
[24-K-03.60-D-LDX](#) [PMSDT-08-24-K-04.00-D-LDS](#) [PMSDT-03-24-K-80.00-D-LDX](#) [PMSDT-05-24-K-15.00-S](#) [PMSDT-](#)
[05-24-K-25.00-S](#) [PMSDT-10-24-K-12.00-D-LDX](#) [PMSDT-04-24-K-80.00-D-LDX](#) [PMSDT-02-24-K-43.25-D-LDX](#)
[PMSDT-05-24-K-05.00-D-LDX](#) [PMSDT-05-24-K-08.00-D-MDX](#) [PMSDT-03-24-K-40.00-D-LDX](#) [PMSDT-10-24-K-80.00-](#)
[S](#) [PMSDT-02-24-K-31.00-D-LDX](#) [PMSDT-02-24-K-96.00-D-LDX](#) [PMSDT-05-24-K-08.00-D-LDX](#) [PMSDT-05-24-K-](#)
[08.00-D-LUS](#) [PMSDT-15-24-K-12.00-S](#) [PMSDT-04-24-K-12.00-S](#) [PMSDT-04-24-K-20.00-D-MDS](#) [PMSDT-08-24-K-](#)
[04.00-S](#) [PMSDT-04-24-K-08.00-D-LDX](#) [PMSDT-04-24-K-24.00-D-LUS](#) [PMSDT-10-24-K-04.00-D-LDX](#) [PMSDT-02-24-](#)
[K-12.00-D-LUX](#) [PMSDT-02-24-K-55.00-S](#) [PMSDT-04-24-K-40.00-D-LDX](#) [PMSDT-05-24-K-04.00-S](#) [PMSDT-02-24-K-](#)
[24.00-D-LUS](#) [PMSDT-02-24-K-10.00-S](#) [PMSDT-02-24-K-144.0-D-LDX](#) [PMSDT-03-24-K-03.50-D-LUS](#) [PMSDT-03-24-](#)
[K-48.00-D-LUS](#) [PMSDT-05-24-K-12.00-D-LDX](#) [PMSDT-10-24-K-06.00-D-MUS](#) [PMSDT-02-24-K-24.00-S](#) [PMSDT-05-](#)
[24-K-04.33-D-LDX](#) [PMSDT-05-24-K-16.00-S](#) [PMSDT-05-24-K-400.0-S](#) [PMSDT-10-24-K-40.00-S](#) [PMSDT-08-24-K-](#)
[15.74-D-LUS](#) [PMSDT-03-24-K-10.00-D-LUS](#) [PMSDT-02-24-K-03.50-S](#) [PMSDT-05-24-K-20.00-D-LUS](#) [PMSDT-02-24-](#)
[K-08.00-D-LUS](#) [PMSDT-05-24-K-08.00-D-LDS](#) [PMSDT-03-24-K-12.00-S](#) [PMSDT-05-24-K-09.00-D-LUS](#) [PMSDT-05-](#)
[24-K-04.50-D-LUS](#) [PMSDT-10-24-K-07.00-D-LDX](#) [PMSDT-02-24-K-72.00-S](#) [PMSDT-10-24-K-03.50-D-LDS](#) [PMSDT-](#)
[05-24-K-05.50-D-LDX](#) [PMSDT-02-24-K-78.74-D-LUS](#) [PMSDT-04-24-K-08.00-D-LUS](#) [PMSDT-08-24-K-05.00-D-LDX](#)
[PMSDT-02-24-K-36.00-S](#) [PMSDT-03-24-K-09.00-D-LDX](#) [PMSDT-10-24-K-59.05-D-LUS](#) [PMSDT-02-24-K-04.00-S](#)