



samtec

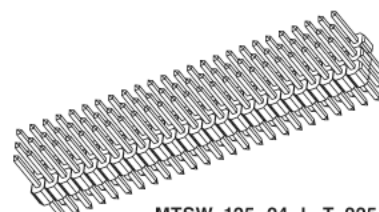

MTSW-118-08-G-D-200-RA

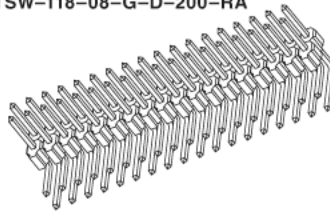

MTSW-125-24-L-T-225




MODIFIED .025" _sq TERMINAL

Mates with:

SSW, SSQ, ESW, ESQ,
BCS, BSW, IDSS, IDSD,
CES, SLW, HLE

Modified .025" strips permit custom post heights.

Samtec offers the greatest stacking flexibility in the industry. The "M" stands for Modified. You tell us the post height you need and we'll deliver it.

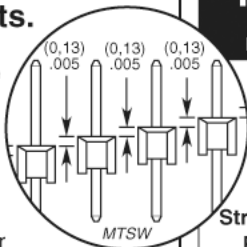

SPECIFICATIONS

For complete specifications see www.samtec.com?MTSW

MTSW

Insulator Material: Black Glass Filled Polyester



Terminal Material: Phosphor Bronze



Plating: Au or Sn over 50µ" (1,27µm) Ni

Current Rating: 3 amp continuous

Operating Temp Range: -55°C to +125°C with Gold

-55°C to +105°C with Tin

RoHS Compliant: Yes

Processing: Lead-Free Solderable: Wave Only

SPECIFICATIONS

For complete specifications see www.samtec.com?HMTSW

HMTSW

Same as MTSW except:



Insulator Material: Natural Liquid Crystal Polymer



Processing: Max Processing Temp: 230°C for 60 seconds, or 260°C for 20 seconds 3x

Lead-Free Solderable: Yes

Note:

These Series are non-standard, non-returnable.

 
TYPE STRIP

MTSW
= Modified Strip


HMTSW
= Hi-Temp Modified Strip

PIN PITCH

-1
= (2,54mm)
.100" Pitch



-2
= (5,08mm)
.200" Pitch

 


NO. PINS PER ROW


LEAD STYLE

SPECIFY "LEAD STYLE" FROM CHART

LEAD STYLE	OAL
-06	(7,62) .300
-07	(10,92) .430
-08	(13,46) .530
-09	(18,54) .730
-10	(21,08) .830
-11	(23,62) .930
-12	(26,16) 1.030
-13	(31,24) 1.230
-21	(36,32) 1.430
-22	(46,00) 1.800
-23	(51,30) 2.010
-24	(56,60) 2.220
-27	(63,78) 2.510
-28	(68,70) 2.700

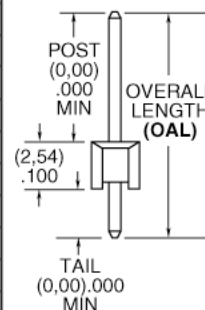


Straight Pin Versions

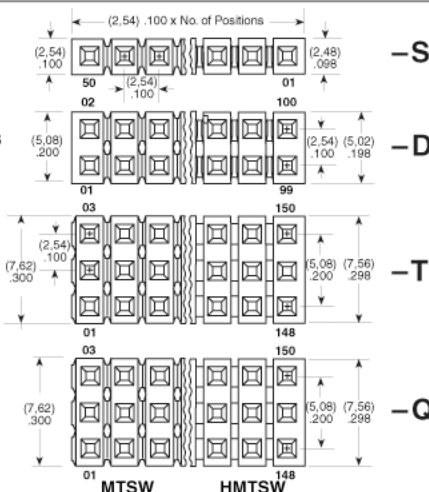

01 thru 50
= (2,54mm)
.100" Center Version


Right Angle Versions

HMTSW -S & -D
= 36 positions maximum

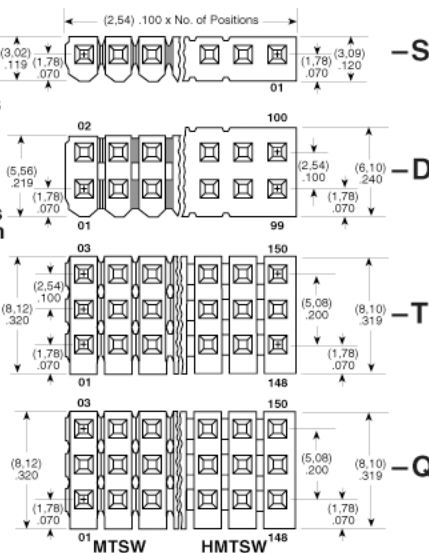

02 thru 25
= (5,08mm)
.200" Center Version

Board Stacking

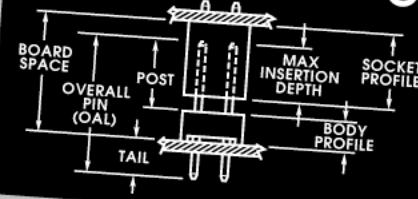

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 • Fax: 812-948-5047

SAMTEC SILICON VALLEY • Tel: 408-395-5900 • Fax: 408-395-1520

SAMTEC UK • Tel: 01236 739292 • Fax: 01236 727113

SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 • Fax: +49 (0) 89 / 89460-299

SAMTEC FRANCE • Tel: 01 60 95 06 60 • Fax: 01 60 95 06 61

SAMTEC ITALY • Tel: 39 039 6890337 • Fax: 39 039 6890315

SAMTEC SCANDINAVIA • Tel: +46-84477280 • Fax: +46-844720413

SAMTEC ISRAEL • Tel: 972-3-7526600 • Fax: 972-3-7526690

SAMTEC INDIA • Tel: 91 80 306 21 612 • Fax: 91 80 4152 8187

SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 • Fax: 65 6841-1502

SAMTEC JAPAN • Tel: 045-475-1385 • Fax: 045-475-1340

SAMTEC CHINA • Tel: 86-21-61103766 • Fax: 86-21-53854047


SAMTEC TAIWAN • Tel: 886 02 2698-3367 • Fax: 886 02 8698-2159

SAMTEC HONG KONG • Tel: 852-26904858 • Fax: 852-26904842


SAMTEC KOREA • Tel: 82-31-717-5685 • Fax: 82-31-717-5681

SAMTEC SOUTH AFRICA • Tel: 27 11 45281112 • Fax: 27 86 6714432



SAMTEC ANZ • Tel: 613 9512 7747 • Fax: 613 9512 7745

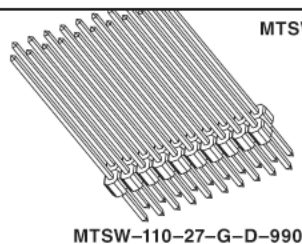

MTSW-126-09-S-S-430-RA

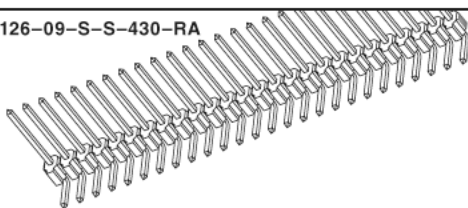

MTSW-112-12-G-Q-730-RA

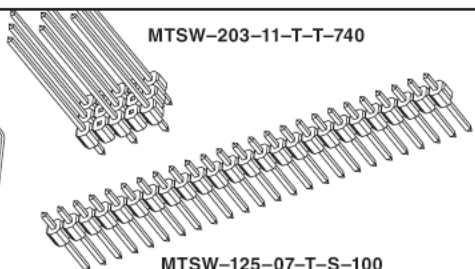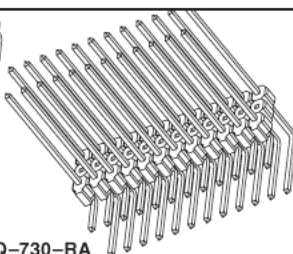

MTSW-203-11-T-T-740

MTSW-125-07-T-S-100

STRIPS

MTSW & HMTSW SERIES

PLATING OPTION

-L

= 10μ" (0,25μm) Gold on contact area,
Matte Tin on tail

-G

= 10μ" (0,25μm) Gold on contact area,
Gold flash on balance

-T

= Matte Tin

-S

= 30μ" (0,76μm) Gold on contact area,
Matte Tin on tail



ROW OPTION

-S

= Single

-D

= Double

-T

= Triple

-Q

= Double Row
.200" (5,08mm)
row space

POST HEIGHT

OTHER OPTION

POLARIZED OPTION

-“XXX”

= Polarized
(Specify ‘XXX’ as
position number)

-RA or -RE = Right Angle

-LL

= Locking Lead
(N/A with -RE)
N/A in single row 1 or 2
positions. Available on
tails from (2,29) .090" to
(10,16) .400" only)



Two leads per strip
crimped in opposite
directions on or near
centerline. See TSW
for availability.

-LA = -RA Option with -LL Option
(Maximum “C” = (13,46) .530)







-“XXXX” = “C” Dimension (Specify post height in INCHES – .005" (0,13mm) increments)





FOR A = (2,29) .090				
LEAD STYLE	OAL	C MAXIMUM STRAIGHT	C MAXIMUM w/RA	C MAXIMUM w/RE
-06	(7,62) .300	(2,79) .110	N/A	N/A
-07	(10,92) .430	(6,10) .240	(3,30) .130	N/A
-08	(13,46) .530	(8,64) .340	(5,84) .230	(3,30) .130
-09	(18,54) .730	(13,72) .540	(10,92) .430	(8,38) .330
-10	(21,08) .830	(16,26) .640	(13,46) .530	(10,92) .430
-11	(23,62) .930	(18,80) .740	(16,00) .630	(13,46) .530
-12	(26,16) 1.030	(21,34) .840	(18,54) .730	(16,00) .630
* -13	(31,24) 1.230	(26,42) 1.040	(23,62) .930	(21,08) .830
* -21	(36,32) 1.430	(31,50) 1.240	(28,70) 1.130	(26,16) 1.030
-22	(16,00) .630	(11,18) .440	(8,38) .330	(5,84) .230
* -23	(11,30) .445	(6,48) .255	(3,68) .145	N/A
* -24	(12,19) .480	(7,37) .290	(4,57) .180	N/A
* -27	(33,78) 1.330	(28,96) 1.140	(26,16) 1.030	(23,62) .930
* -28	(28,70) 1.130	(23,88) .940	(21,08) .830	(18,54) .730

* Styles -21, -23, -24, -27
not available with -D Right Angle
Styles -13, -21, -23, -24, -27, -28
not available with -T or -Q Right Angle

Straight Pin Versions A = OAL - C - (2,54) .100

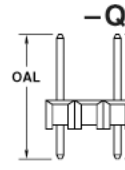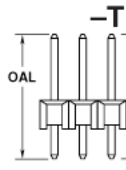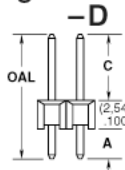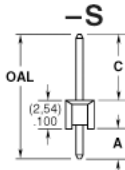


Right Angle Versions (-RA Options) A = OAL - C - (5,33) .210

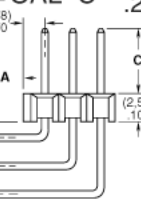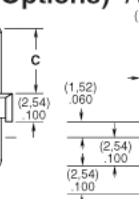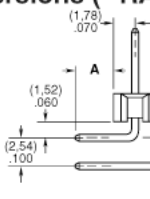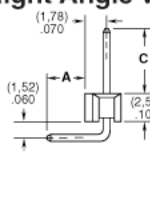

Styles -21, -23, -24, -27 N/A with -D
Styles -13, -21, -23, -24, -27, -28 N/A with -T or -Q

Right Angle Versions
(-RE Options) Single Row Only
A = OAL - C - (7,87) .310

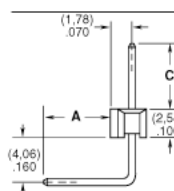

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 • Fax: 812-948-5047
SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 • Fax: +49 (0) 89 / 89460-299
SAMTEC SCANDINAVIA • Tel: +46-84477280 • Fax: +46-844720413
SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 • Fax: 65 6841-1502
SAMTEC HONG KONG • Tel: 852-26904858 • Fax: 852-26904842
SAMTEC SILICON VALLEY • Tel: 408-395-5900 • Fax: 408-395-1520
SAMTEC FRANCE • Tel: 01 60 95 06 60 • Fax: 01 60 95 06 61
SAMTEC ISRAEL • Tel: 972-3-7526600 • Fax: 972-3-7526690
SAMTEC CHINA • Tel: 86-21-61103766 • Fax: 86-21-53854047
SAMTEC SOUTH AFRICA • Tel: 27 11 4528112 • Fax: 27 86 6714432
SAMTEC UK • Tel: 01236 739292 • Fax: 01236 727113
SAMTEC ITALY • Tel: 39 039 6890337 • Fax: 39 039 6890315
SAMTEC INDIA • Tel: 91 80 306 21 612 • Fax: 91 80 4152 8187
SAMTEC TAIWAN • Tel: 886 02 2698-3367 • Fax: 886 02 8698-2159
SAMTEC ANZ • Tel: 613 9512 7747 • Fax: 613 9512 7745

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[HMTSW-109-21-T-Q-990](#) [HMTSW-220-12-S-Q-200-LA](#) [HMTSW-110-06-T-D-100](#) [MTSW-111-07-G-D-200](#) [MTSW-120-08-T-D-100](#) [MTSW-120-09-T-D-100](#) [MTSW-130-06-G-D-200](#) [MTSW-150-07-L-D-225](#) [MTSW-150-08-S-D-225](#) [MTSW-150-28-G-D-740](#) [MTSW-130-23-G-D-200](#)