

T-1R7-02-G

T-1R1-G

T, S SERIES

MACHINED TERMINALS & SOCKETS

Mates with:
SC, SK, SP

Specifications:
T, S

All T and S Series are available with a choice of Gold or Tin plating. Add -G or -T as a suffix to the part number shown.

-G Plating:

Au over 50μ" (1,27μm) Ni

-T Plating:

Sn over 50μ" (1,27μm) Ni
or 100μ" (2,54μm) Cu


Current Rating:

1 A except T-1S6 is 5A

**RECOMMENDED
PC HOLE SIZE:**

LEAD SIZE	HOLE SIZE
(0.46) .018 DIA	(.61) .024 DIA
(.51) .020 DIA	(.66) .026 DIA
(.64) .025 DIA	(.79) .031 DIA
(.76) .030 DIA	(.91) .036 DIA
(.89) .035 DIA	(1.04) .041 DIA
(1.14) .045 DIA	(1.30) .051 DIA
(1.32) .052 DIA	(1.47) .058 DIA
(.46) .018 SQ	(.76) .030 DIA
(.64) .025 SQ	(1.02) .040 DIA
(1.14) .045 SQ	(1.75) .069 DIA
(.20) .008 x (.71) .028	(.89) .035 DIA
(.25) .010 x (.51) .020	(.71) .028 DIA
(.41) .016 x (.51) .020	(.79) .031 DIA
(.41) .016 x (.61) .024	(.89) .035 DIA
(.41) .016 x (.79) .031	(1.04) .041 DIA


T-1R6-, T-3R6-

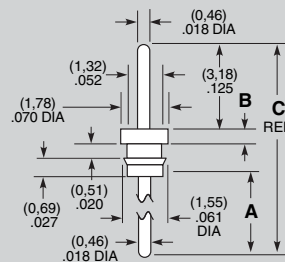

Part No.	A TAIL	B HEAD	C OAL
T-1R6-	(2,74) .108	(0,51) .020	(7,62) .300
T-3R6-	(0,89) .035	(0,76) .030	(5,97) .235

Material: Brass
 -G = 20 μ m (0,51 μ m) Gold
 -T = 200 μ m (5,08 μ m) Tin


T-1R7-

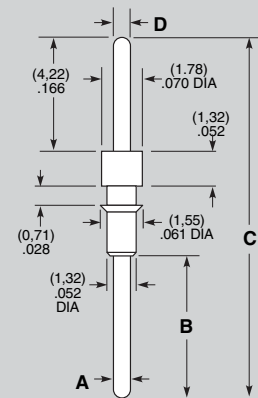

Part No.	A DIA	B TAIL	C OAL	D DIA
T-1R7-01	(0,64) .025			
T-1R7-02	(0,89) .035	(5,33) .210	(13,46) .530	(0,64) .025
T-1R7-03	(1,14) .045			


Material: Brass
 -G = 10 μ " (0,25 μ m) Gold
 -T = 200 μ " (5,08 μ m) Tin

T-1R0-

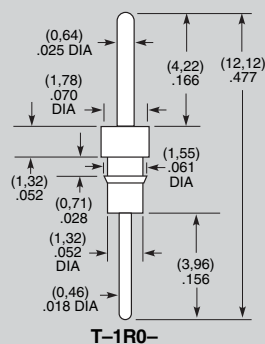

Material: Brass
-G = 20 μ " (0,51 μ m) Gold
-T = 200 μ " (5,08 μ m) Tin

T-1R2-, T-1R9-

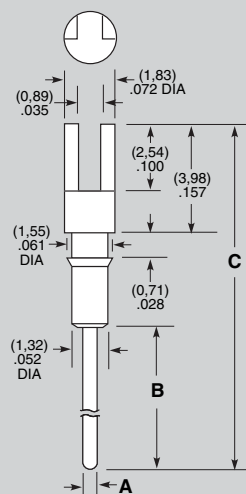

Part No.	A DIA	B TAIL	C OAL
T-1R2-	(0.46) .018	(3.96) .156	(10.57) .416
T-1R9-1-	(0.64) .025	(5.33) .210	(11.94) .470
T-1R9-2-	(0.89) .035		

Material: Brass
 -G = 10 μ m (0,25 μ m) Gold (T-1R9-)
 -G = 20 μ m (0,51 μ m) Gold (T-1R2-)
 -T = 200 μ m (5,08 μ m) Tin

Note:
Some sizes, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 **SAMTEC SILICON VALLEY** • Tel: 408-395-5900 **SAMTEC SOUTHERN CALIFORNIA** • Tel: 1-800-726-8329 **SAMTEC UK** • Tel: 44 01236 739292
SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 **SAMTEC FRANCE** • Tel: 33 01 60 95 06 60 **SAMTEC ITALY** • Tel: 39 039 6890337 **SAMTEC NORDIC/BALTIC** • Tel: +46-84477280 **SAMTEC BENELUX** • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 **SAMTEC INDIA** • Tel: +91-80-3272 1612 **SAMTEC ASIA PACIFIC** • Tel: 65 6745-5955 **SAMTEC JAPAN** • Tel: 045-475-1385 **SAMTEC CHINA** • Tel: 86-21-6110376
SAMTEC TAIWAN • Tel: 886-2-2735-6109 **SAMTEC HONG KONG** • Tel: 852-26904858 **SAMTEC KOREA** • Tel: 82-31-717-5685 **SAMTEC SOUTH AFRICA** • Tel: 27 11 452 8112 **SAMTEC ANZ** • Tel: 613 9512 7747

T-1P1-G




T-1R0-G



T, S SERIES


MACHINED TERMINALS & SOCKETS

T-1S5-

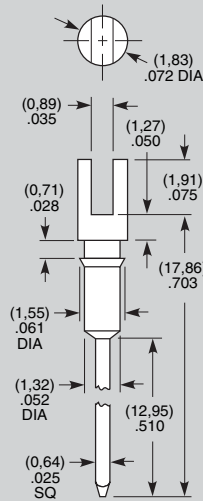


Material: Brass
 -G = 20μ" (0.51μm) Gold
 -T = 200μ" (5.08μm) Tin

T-1R1-

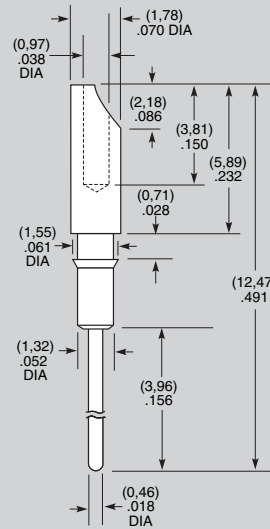

Material: Brass
 -G = 20μ" (0.51μm) Gold
 -T = 200μ" (5.08μm) Tin

 T-1S6-



PART NO.	B
T-1S6-07-X-2	(10.92) .430
T-1S6-08-X-2	(13.46) .530
T-1S6-09-X-2	(18.54) .730
T-1S6-10-X-2	(21.08) .830
T-1S6-11-X-2	(23.62) .930
T-1S6-12-X-2	(26.16) 1.030
T-1S6-13-X-2	(31.24) 1.230
T-1S6-14-X-2	(36.32) 1.430
T-1S6-15-X-2	(41.40) 1.630
T-1S6-16-X-2	(46.48) 1.830
T-1S6-17-X-2	(51.56) 2.030
T-1S6-18-X-2	(56.64) 2.230
T-1S6-19-X-2	(61.72) 2.430
T-1S6-20-X-2	(66.80) 2.630
T-1S6-21-X-2	(71.88) 2.830

Pins are supplied on a bandolier.

Material: Phosphor Bronze


X = Plating option (specify G or T)

-G = 10μ" (0.25μm) Gold on .165" (4.19mm)

contact area. Gold flash on balance


-T = 200μ" (5.08μm) Tin

S-1P1-

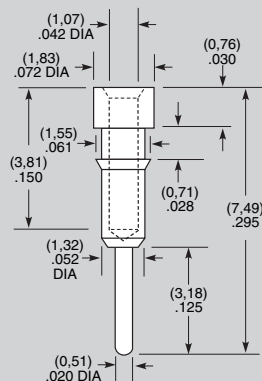

Material: Brass
 -G = 10μ" (0.25μm) Gold
 -T = 200μ" (5.08μm) Tin

S-1W1-

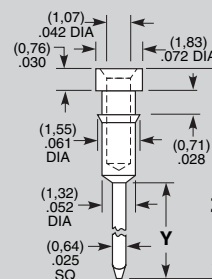

Material: Brass
 -G = 10μ" (0.25μm) Gold
 -T = 200μ" (5.08μm) Tin

Part No.	Y ±.010	Z ±.015
S-1W1-1-	(12.95) .510	(17.86) .703
S-1W1-2-	(9.14) .360	(14.05) .553
S-1W1-3-	(6.60) .260	(11.51) .453

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329 SAMTEC UK • Tel: 44 01236 739292
 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-61103766
 SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC SOUTH AFRICA • Tel: 27 11 452 8112 SAMTEC ANZ • Tel: 613 9512 7747

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[T-1R1-T](#)