

(2,54mm) .100"

CLH SERIES

CLH-108-F-D-DV-P



CLH-120-F-D-BE



CLH-110-F-D-DV



SMT LOW PROFILE SOCKET

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?CLH

Insulator Material:

Black Liquid
Crystal Polymer

Contact Material:

Phosphor Bronze

Operating Temp Range:

-65°C to +125°C with Gold

-65°C to +105°C with Tin

Plating:

Au or Sn over

50µ" (1,27µm) Ni

Contact Resistance:

10 mΩ max

Insertion Depth:

(2,67mm) .105" to

(3,43mm) .135"

plug from top, (3,18mm) .125"
min plus board thickness plug
from bottom

Insertion Force:

4.0oz (1,11N) average

Normal Force:

50 grams (0,48N)

Withdrawal Force:

1.1oz (0,31N) average

Max Cycles:

100 with 10µ" (0,25µm) Au

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,10mm) .004" max



Mates with:
TSW, MTSW, HW, DW,
EW, ZW, TLW, TSM,
MTLW

CLH

1

NO. PINS
PER ROWPLATING
OPTION

D

ENTRY
OPTIONOTHER
OPTION

—DV
= Top
Entry

 
—BE
= Bottom
Entry

—K

= (6,50mm) .256"
DIA Polyimide film
Pick & Place Pad
(3 positions min.)

—P


= Pick & Place Pad
(3 positions
minimum)



Not always necessary
for auto placement.
Call Samtec.


—A

 = Alignment Pin
(4 positions
minimum)



—LC


= Locking
Clip

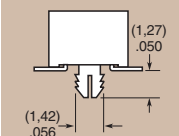

—TR

= Tape & Reel
Packaging
(29 positions
maximum)

02 thru 50

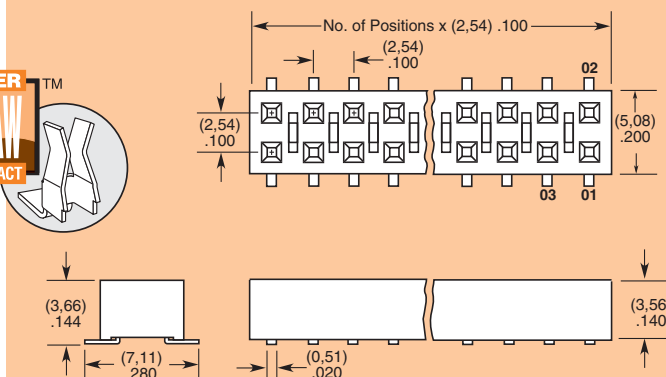

TAPE & REEL AVAILABILITY
No tooling charges.
Minimum order is the lesser of
a full reel quantity or 125 pieces.
Order any quantity above minimum.
In-house design, manufacture.
Quick turn-around.
Call Samtec for specifications
and ordering information.

Note: Some lengths,
styles and options are
non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292 SAMTEC ISRAEL • Tel: 972-3-7526600
SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-61103766 SAMTEC TAIWAN • Tel: 886-2-2735-6109
SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9512 7747 SAMTEC SOUTH AFRICA • Tel: 27 11 452 8112

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[CLH-110-L-D-DV-A](#) [CLH-105-L-D-DV-A](#) [CLH-108-L-D-DV-A](#) [CLH-110-F-D-DV-P](#) [CLH-113-L-D-DV-A](#) [CLH-107-L-D-BE-K](#) [CLH-136-F-D-BE-LC](#) [CLH-102-F-D-BE-TR](#) [CLH-102-F-D-BE-LC](#) [CLH-116-F-D-BE-LC](#) [CLH-105-F-D-BE-LC](#) [CLH-117-F-D-BE-P](#) [CLH-115-F-D-BE-P](#) [CLH-103-F-D-BE-LC](#) [CLH-120-F-D-BE-LC](#) [CLH-125-F-D-BE-K](#) [CLH-103-F-D-BE-P](#) [CLH-106-F-D-BE-LC](#) [CLH-113-F-D-BE-P](#) [CLH-132-F-D-BE-P](#) [CLH-105-F-D-BE-K](#) [CLH-113-F-D-BE-LC](#) [CLH-107-F-D-BE-P](#) [CLH-110-F-D-BE-LC](#) [CLH-115-F-D-BE-LC](#) [CLH-120-F-D-BE-P](#) [CLH-132-F-D-BE-K](#) [CLH-108-F-D-BE-P](#) [CLH-110-F-D-BE-P](#) [CLH-114-F-D-BE-LC](#) [CLH-105-F-D-BE-P](#) [CLH-106-F-D-BE-P](#)