


(2,54mm) .100"

CLH SERIES

CLH-115-F-D-DE



CLH-117-F-D-TE

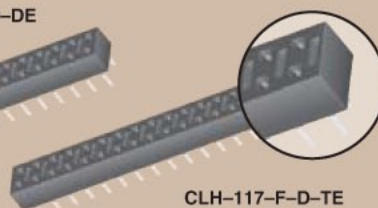

CLH-112-F-D-PE



THROUGH-HOLE LOW PROFILE SOCKET

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?CLH

Insulator Material:

Black Liquid
Crystal Polymer

Contact Material:

Phosphor Bronze

Operating Temp Range:

-65°C to +125°C with Gold

-65°C to +105°C with Tin

Plating:

Au or Sn over
50µ" (1,27µm) Ni

Contact Resistance:

10 mΩ max

Insertion Depth:

(2,67mm) .105" to

(3,43mm) .135"

plug from top, (3,18mm) .125"
min plus board thickness plug
from bottom

Insertion Force:

4.0oz (1,11N) average

Normal Force:

50 grams (0,48N)

Withdrawal Force:

1.1oz (0,31N) average

Max Cycles:

100 with 10µ" (0,25µm) Au

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes



CLH

1

NO. PINS
PER ROWPLATING
OPTION

D

ENTRY
OPTION

Mates with:

TSW, MTSW, HTSW,
HMTSW, DW, EW, ZW,
TLW, TSM, MTLW

-F

= Pre-plated Gold flash on contact,
75µ" (1,91µm) Matte Tin on tail


-L

= Pre-plated 10µ" (0,25µm)
Gold on contact,
75µ" (1,91µm) Matte Tin on tail

Note: Other Gold plating
options available.
Contact Samtec.


-TE

= Top Entry

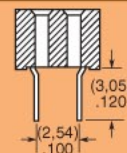


-DE

= Dual Entry
(Top or Bottom Entry)
Cannot be used with
plated through-holes
for bottom entry.

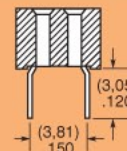


-PE

= Pass-Through
(Top or Bottom
Entry)

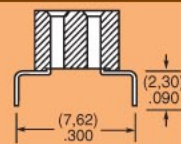

02 thru 50

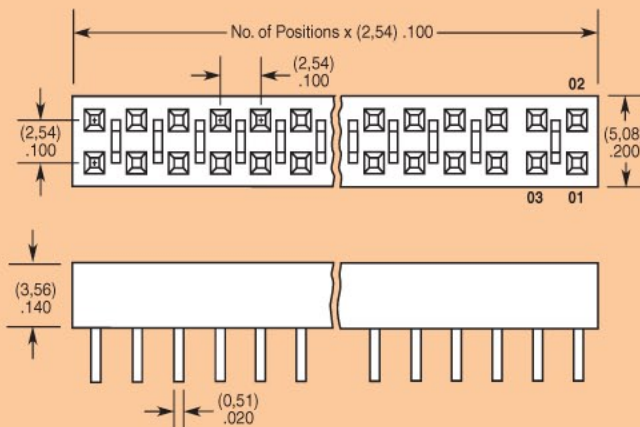

Note: Some lengths,
styles and options are
non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[CLH-112-F-D-PE](#) [CLH-111-L-D-PE](#) [CLH-105-F-D-PE](#) [CLH-106-L-D-PE](#) [CLH-107-L-D-PE](#) [CLH-108-L-D-PE](#) [CLH-112-L-D-PE](#) [CLH-113-L-D-PE](#) [CLH-103-L-D-PE](#) [CLH-117-L-D-PE](#) [CLH-105-L-D-PE](#) [CLH-114-L-D-PE](#) [CLH-118-L-D-PE](#) [CLH-144-L-D-PE](#) [CLH-127-L-D-PE](#) [CLH-136-L-D-PE](#) [CLH-140-L-D-PE](#) [CLH-109-L-D-PE](#) [CLH-120-L-D-PE](#) [CLH-115-L-D-PE](#) [CLH-122-L-D-PE](#) [CLH-130-L-D-PE](#) [CLH-128-L-D-PE](#) [CLH-121-L-D-PE](#) [CLH-102-L-D-PE](#) [CLH-110-L-D-PE](#) [CLH-104-L-D-PE](#) [CLH-125-L-D-PE](#) [CLH-126-L-D-PE](#) [CLH-123-L-D-PE](#) [CLH-134-L-D-PE](#) [CLH-133-L-D-PE](#) [CLH-116-L-D-PE](#) [CLH-131-L-D-PE](#) [CLH-135-L-D-PE](#) [CLH-132-L-D-PE](#)