

(1,27 mm) .050"

SHF, ESHF, EHF, ECF SERIES

SHF-110-01-L-D-RA

EHF-108-01-F-D-SM-LC

EHF-105-01-F-D-SM

ESHF-125-01-L-D-SM-LC

EHF-125-01-L-D-SM-LC

ESHF-105-01-L-D-SM

SHROUDED & EJECTOR IDC HEADER

SHF, ESHF Mates with:
FFSD, FFTP (SHF)

EHF Mates with:
FFSD*, FFTP

SPECIFICATIONS

For complete specifications
see www.samtec.com?SHF,
www.samtec.com?ESHF or
www.samtec.com?EHF



Insulator Material:
Black Liquid Crystal
Polymer

Terminal Material:
Phosphor Bronze
Plating:
Sn or Au over
50µ" (1,27 µm) Ni


Current Rating:
1.75A per contact
@ 80°C ambient
Operating Temp Range:
-55°C to +125°C
RoHS Compliant:
Yes

Processing:

Lead-Free Solderable:
Yes
SMT Lead Coplanarity:
(0,10 mm) .004" max

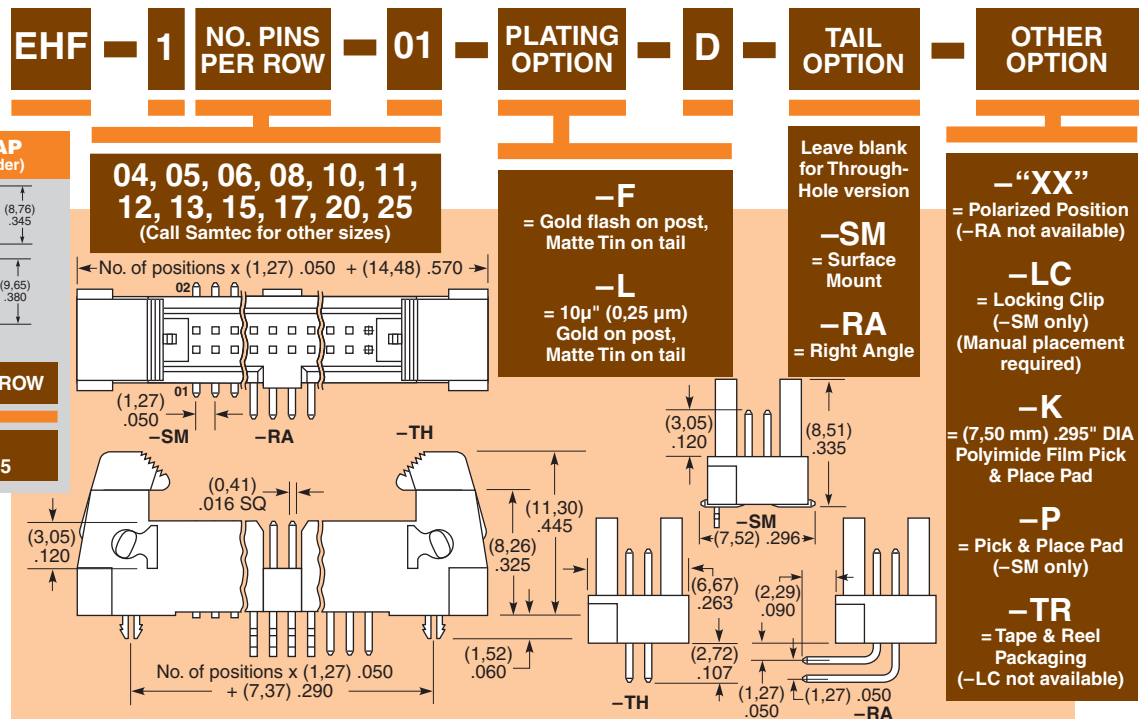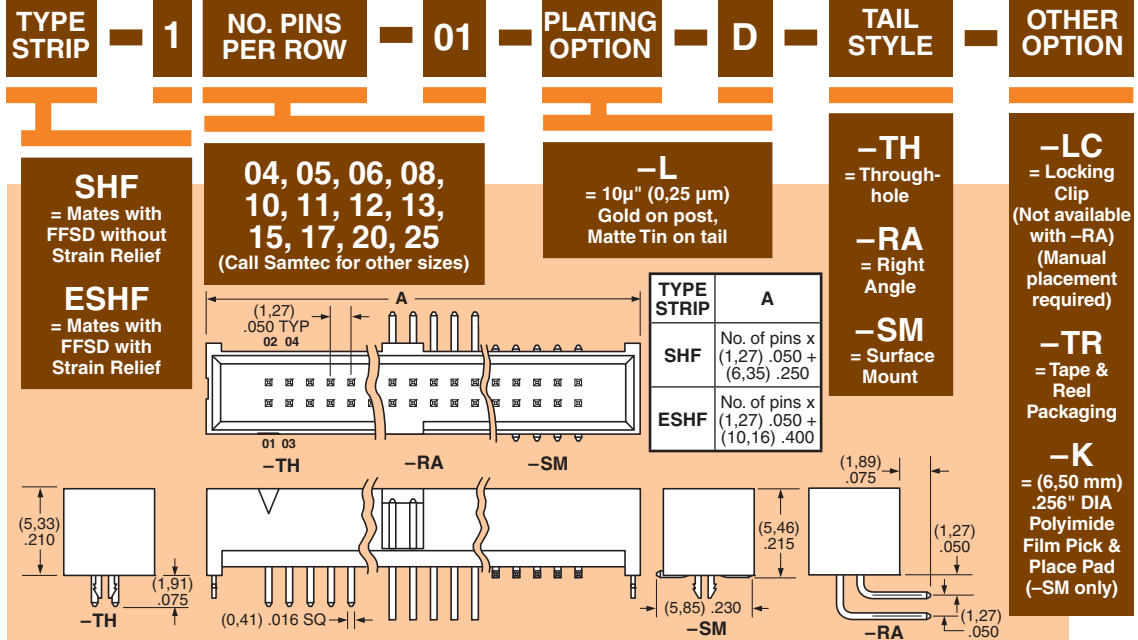

EJECTOR HEADER CAP (Locks FFSD cable to EHF header)

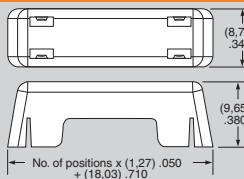

ECF

NO. PINS PER ROW

05, 08, 10,
13, 17, 20, 25

***Important Note:**
EHF will not mate to FFSD
with strain relief (-SR option),
see ESHF series.

Note: Some lengths, styles
and options are non-standard,
non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-6083 3766
SAMTEC TAIWAN • Tel: 886-2-2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[EHF-115-01-F-D](#) [EHF-115-01-F-D-RA](#) [EHF-115-01-F-D-SM](#)