



(1,27 mm) .050"

SFM-110-02-L-D-A

SFML-125-T2-L-D-LC

SFM-125-02-L-SH

SFML-115-T2-L-D-LC

SMT & THROUGH-HOLE TIGER EYE™ SOCKET

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?SFM or www.samtec.com?SFML

Insulator Material:

Black Liquid Crystal Polymer

Plating:

Au or Sn over 50µ" (1,27 µm) Ni

Current Rating (SFM/TFM):

3.2 A per pin

(1 pin powered per row)

Voltage Rating:

250 VAC mated with TFM

Operating Temp Range:

-55°C to +125°C

Contact Resistance:

15 mΩ

Insertion Depth:

(3,05 mm) .120" to

(4,06 mm) .160"

Wiping Distance:

(0,38 mm) .015"

Normal Force:

Standard= 132 g (1,29 N) avg.;

LIF= 90 g (0,88 N) avg.

Insertion Force (SFM):

(Single contact only)

Standard= 2.5 oz (0,69 N) avg.;

LITE= 2.0 oz (0,56 N) avg.;

LIF= 1.4 oz (0,39 N) avg.

Withdrawal Force (SFM):

(Single contact only)

Standard= 2.0 oz (0,56 N) avg.;

LITE= 1.5 oz (0,42 N) avg.;

LIF= 1.0 oz (0,28 N) avg.

Max Cycles:

10,000 with 30µ" (0,76 µm) Au

(Call Samtec for E.L.P.™

plating option)

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,10 mm) .004" max (05-25)

(0,15 mm) .006" max (30-50)

SFM Mates with:
TFM, TFSD, TFSS

SFML Mates with:
TFML



Low insertion force
Tiger Eye™ contacts available


(1,27 mm x 1,27 mm)
.050" x .050" micro pitch

Locking feature
increases unmating
force (SFML)

Choice of SMT or
through-hole tails



- Passes 10 Year MFG
- Locking option
- Locking clip option
- Screw Down option

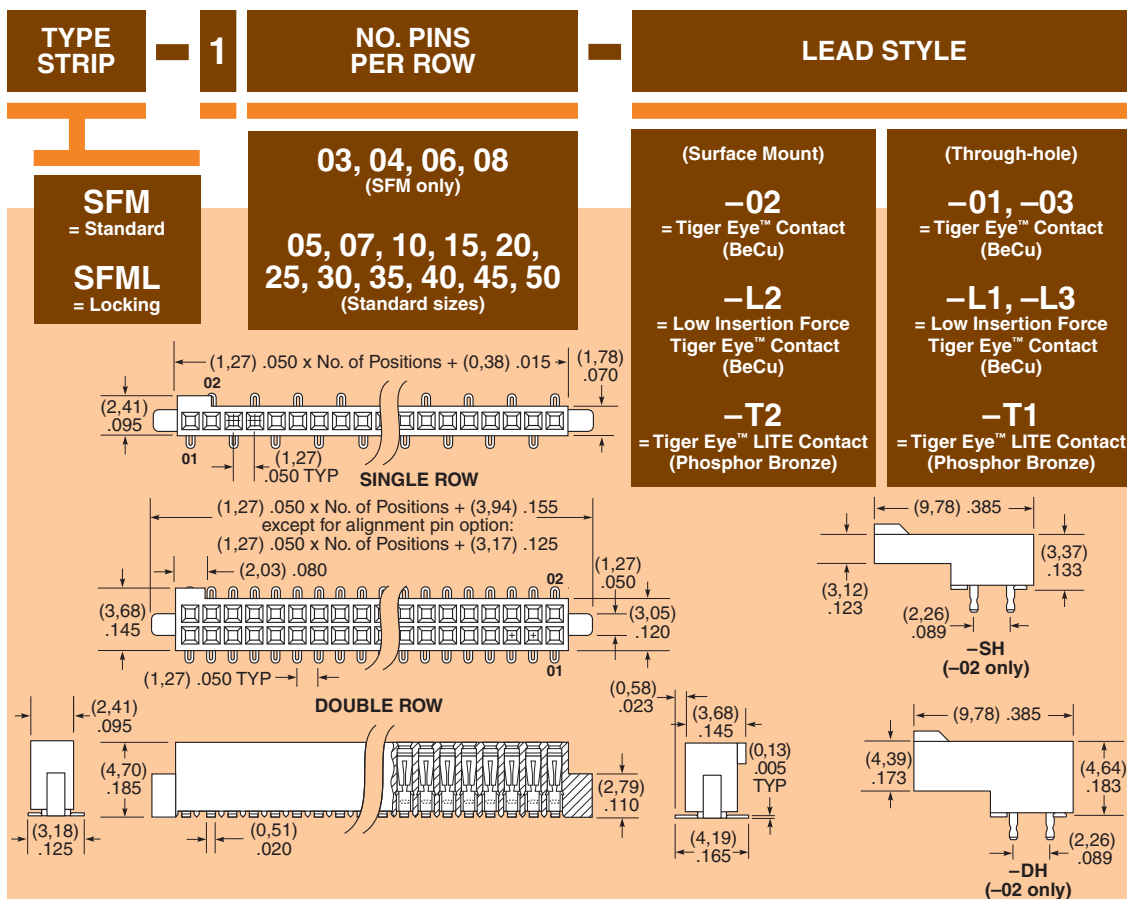

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality




Note: Some sizes, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: +1-800-SAMTEC-9 or +1-812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: +1-408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: +1-800-726-8329
 SAMTEC SOUTH AMERICA • Tel: +55 31 3786 3227 SAMTEC UNITED KINGDOM • Tel: +44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: +33 1 60 95 06 60 SAMTEC ITALY • Tel: +39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46 8 4477280 SAMTEC BENELUX • Tel: +44 01236 739292
 SAMTEC ISRAEL • Tel: +972 3 7526600 SAMTEC INDIA • Tel: +91 80 3272 1612 SAMTEC ANZ • Tel: +613 9580 0683 SAMTEC SINGAPORE • Tel: +65 6745 5955 SAMTEC JAPAN • Tel: +81 45 475 1385
 SAMTEC SHANGHAI • Tel: +86 21 6083 3766 SAMTEC SHENZHEN • Tel: +86 755 83776780 SAMTEC TAIWAN • Tel: +886 2 2735 6109 SAMTEC HONG KONG • Tel: +852 26904658 SAMTEC KOREA • Tel: +82 31 717 5685

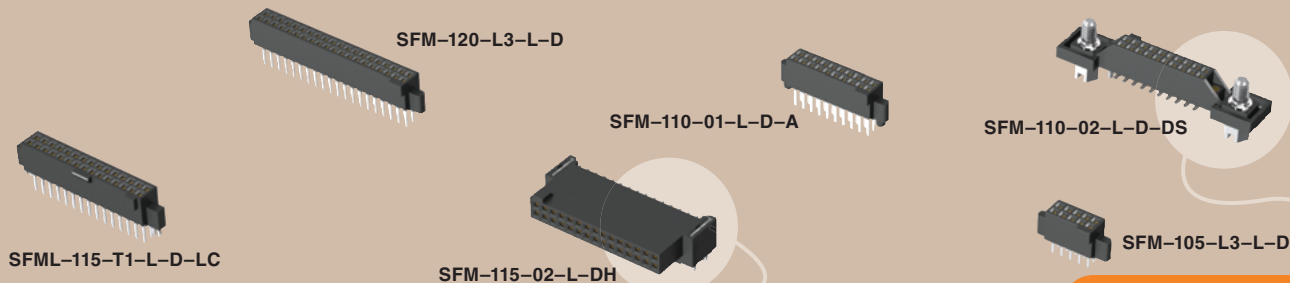

SFM, SFML SERIES



High reliability
Tiger Eye™
contacts

(1,27 mm x 1,27 mm)
.050" x .050" micro pitch

OTHER SOLUTIONS

- Lower cost plating options.
See SFC Series.

Mates with TFM
for coplanar and
perpendicular mating

Surface mount or
Through-hole tails

Screw down
option

ALSO AVAILABLE (MOQ Required)




- Solder nail option
 - Other sizes
 - Other platings
- Contact Samtec.

PLATING OPTION

-L

= 10μ" (0,25 μm) Gold on contact, Matte Tin on tail
(Call Samtec for E.L.P.™ plating option)

LEAD STYLE	A	B
-01, -L1, -T1	(3,05) .120	(0,51) .020
-03, -L3	(1,91) .075	(0,41) .016

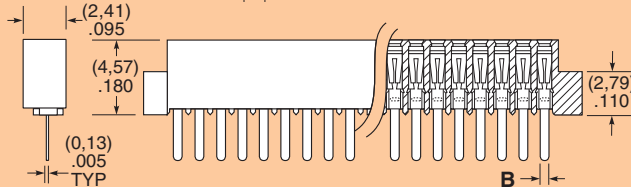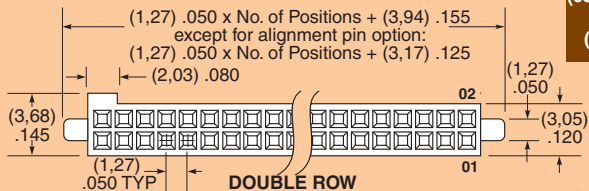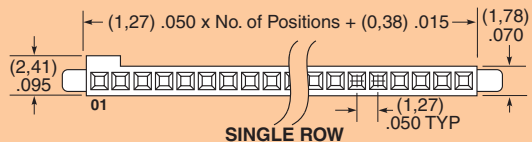

ROW OPTION

-S

= Single Row
(SFM only)

-D

= Double Row

-SH

= Single Horizontal
(05 thru 30 positions only)
(SFM only)
(Lead style -02 only)

-DH

= Double Horizontal
(05 thru 30 positions only)
(SFM only)
(Lead style -02 only)

OPTION

Specify only -A, -LC or -DS
(Not available with -DH, -SH)

-A

= Alignment Pin
(Available with all Lead Styles)

-LC

= Locking Clip
(Available with all lead styles)
(Manual placement required)

-DS

= Dual Screw Down for
(1,60 mm) .062" PCB
(05 thru 40 positions only)
(Lead styles -01, -02 & -03 only)
(Requires -D row option)
(Not available with SFML)
(Mates with TFM-DS option)
(Not available with -A,
-LC, -K, -P, -TR)

Specify only
-K or -P
(Lead styles -02,
-L2, -T2 only)

-K

= Polyimide film
Pick & Place Pad
(Not available
with -DH, -SH)


-P

= Plastic Pick &
Place Pad
(Not available
with -DH, -SH)

Specify -TR last
(Lead styles -02,
-L2, -T2 only)

-TR

= Tape & Reel
(Required callout
for -DH, -SH)

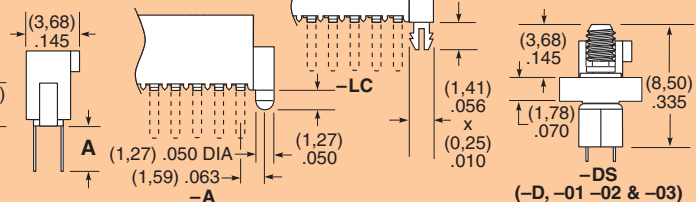

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: +1-800-SAMTEC-9 or +1-812-944-6733 SAMTEC NORTHERN CALIFORNIA • Tel: +1-408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: +1-800-726-8329
SAMTEC SOUTH AMERICA • Tel: +55 31 3786 3227 SAMTEC UNITED KINGDOM • Tel: +44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
SAMTEC FRANCE • Tel: +33 1 60 95 06 60 SAMTEC ITALY • Tel: +39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46 8 4477280 SAMTEC BENELUX • Tel: +44 01236 739292
SAMTEC ISRAEL • Tel: +972 3 7526600 SAMTEC INDIA • Tel: +91 80 3272 1612 SAMTEC ANZ • Tel: +613 9580 0683 SAMTEC SINGAPORE • Tel: +65 6745 5955 SAMTEC JAPAN • Tel: +81 45 475 1385
SAMTEC SHANGHAI • Tel: +86 21 6083 3766 SAMTEC SHENZHEN • Tel: +86 755 83776780 SAMTEC TAIWAN • Tel: +886 2 2735 6109 SAMTEC HONG KONG • Tel: +852 26904658 SAMTEC KOREA • Tel: +82 31 717 5685

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[SFM-135-T2-L-D-K](#) [SFM-104-03-L-D-LC](#) [SFM-108-T1-L-D](#) [SFM-107-T1-L-D-A](#) [SFM-104-T1-L-D-LC](#) [SFM-110-T2-L-D-P](#) [SFM-120-T2-L-D-K](#) [SFM-140-T2-L-D](#) [SFM-140-T2-L-D-LC](#) [SFM-125-T1-L-D](#) [SFM-130-L2-L-D-K](#) [SFM-130-L1-L-D-LC](#) [SFM-135-L1-L-D](#) [SFM-135-L3-L-D](#) [SFM-107-L1-L-D-LC](#) [SFM-140-02-L-D-P](#) [SFM-104-L2-L-D](#) [SFM-104-L1-L-D](#) [SFM-135-T2-L-D-A](#) [SFM-135-L1-L-D-LC](#) [SFM-110-L2-L-D-P](#) [SFM-115-T2-L-D-P](#) [SFM-140-T2-L-D-K](#) [SFM-140-L2-L-D-P](#) [SFM-106-T2-L-D](#) [SFM-107-L2-L-D-K](#) [SFM-107-T2-L-D-LC](#) [SFM-135-L2-L-D-P](#) [SFM-104-L3-L-D-A](#) [SFM-103-L2-L-D-LC](#) [SFM-135-T1-L-D-A](#) [SFM-108-L2-L-D-LC](#) [SFM-120-L2-L-D-P](#) [SFM-107-T2-L-D-P](#) [SFM-106-L2-L-D-LC](#) [SFM-103-03-L-D-A](#) [SFM-115-L1-L-D-LC](#) [SFM-120-L2-L-D-K](#) [SFM-104-L3-L-D-LC](#) [SFM-125-02-L-S](#) [SFM-106-03-L-D-A](#) [SFM-130-T1-L-D-A](#) [SFM-104-L3-L-D](#) [SFM-110-L2-L-D-K](#) [SFM-145-02-L-D-P](#) [SFM-107-03-L-D-LC](#) [SFM-125-L2-L-D-K](#) [SFM-140-03-L-D-LC](#) [SFM-130-L2-L-D-P](#) [SFM-135-L2-L-D](#) [SFM-130-L1-L-D](#) [SFM-104-T1-L-D-A](#) [SFM-103-L1-L-D-LC](#) [SFM-120-T2-L-D-P](#) [SFM-125-T2-L-D-K](#) [SFM-106-T2-L-D-A](#) [SFM-135-L2-L-D-K](#) [SFM-140-L1-L-D](#) [SFM-115-T2-L-D-K](#) [SFM-140-03-L-S](#) [SFM-140-L3-L-D](#) [SFM-135-T2-L-D-P](#) [SFM-140-T2-L-D-P](#) [SFM-105-L2-L-D-P](#) [SFM-130-03-L-D-LC](#) [SFM-107-L2-L-D-P](#) [SFM-130-T2-L-D-P](#) [SFM-140-T1-L-D-A](#) [SFM-140-T1-L-D-LC](#) [SFM-106-03-L-D-LC](#) [SFM-135-T2-L-D-LC](#) [SFM-107-L3-L-D-A](#) [SFM-130-T2-L-D-K](#) [SFM-145-02-L-D-K](#) [SFM-135-02-L-D-P](#) [SFM-105-L2-L-D-K](#) [SFM-104-T1-L-D](#) [SFM-140-T2-L-D-A](#) [SFM-105-T1-L-D-LC](#) [SFM-130-L1-L-D-A](#) [SFM-125-T2-L-D-P](#) [SFM-107-L2-L-D-LC](#) [SFM-107-T2-L-D-K](#) [SFM-106-T1-L-D-A](#) [SFM-103-T2-L-D-LC](#) [SFM-135-T2-L-D](#) [SFM-103-T2-L-D](#) [SFM-106-02-L-D-DS](#) [SFM-106-02-L-S-K](#) [SFM-104-L2-L-D-LC](#) [SFML-135-T2-L-D](#) [SFM-104-T1-L-S](#) [SFM-145-02-L-S-A](#) [SFM-150-02-L-S-A](#) [SFML-135-L2-L-D-A](#) [SFM-110-L2-L-S](#) [SFM-145-01-L-S](#) [SFM-108-02-L-S-K](#) [SFM-103-T1-L-S](#) [SFM-103-L2-L-S](#)