



(0.80 mm) .0315" PITCH • DISCRETE WIRE CABLE ASSEMBLY/COMPONENTS

SESDT	POSITIONS PER ROW	32	PLATING OPTION	ASSEMBLED LENGTH	OPTIONS
-------	-------------------	----	----------------	------------------	---------

= Double Row
Blue *Teflon®
Cable
(32 AWG)

-05, -10, -15, -20
(Standard sizes)

-G
= 10 μ" (0.25 μm)
Gold on contact area,
3 μ" (0.08 μm) Gold on tail

-"XX.X"
= Assembled
Length in Inches
(76.2 mm) 03.0" min.

Double Ended Assemblies

-L1
= Pin 1 to Pin 1
-L2
= Pin 1 to Pin 2
-L3
= Pin 1 to Pin N-1
-L4
= Pin 1 to Pin N

SESDT

Board Mates:

TEM-L1

SPECIFICATIONS

Insulator Material:

Natural Nylon

Contact Material:

BeCu

Plating:

Au over 50 μ" (1.27 μm) Ni

Wire:

Tinned Copper

Wire Insulation:

FEP

Operating Temp Range:

-55 °C to +125 °C

Current Rating:

1.9 A per pin

(2 pins powered)


Voltage Rating:

200 VAC/280 VDC


*DuPont™ Teflon® is a registered trademark of the E.I. du Pont de Nemours and Company or its affiliates.

Note:

Teflon® cable is intended for crimp only. Contact Samtec for solderable cable applications.

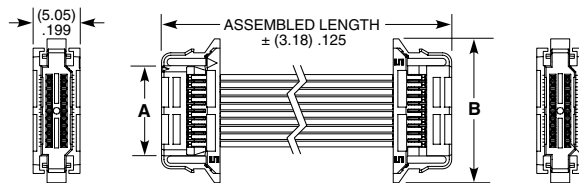

DOUBLE ENDED

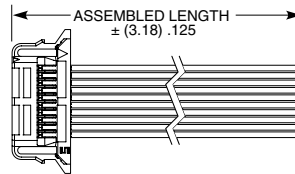

SINGLE ENDED

Single Ended Assembly

-L
= Latching

NO. OF POSITIONS	A	B
-05	(5.70) .224	(11.50) .453
-10	(9.70) .382	(15.50) .610
-15	(13.70) .539	(19.50) .768
-20	(27.70) .697	(23.50) .925

View complete specifications at: samtec.com?SESDT

ISDE	POSITIONS PER ROW	D	L	SERIES	WIRE GAUGE	PLATING	REEL OPTIONS
------	-------------------	---	---	--------	------------	---------	--------------

-05, -10, -15, -20
(Standard sizes)

-D
= Dual Row

-L
= Latch

CC396
= Contact

-3234
= 32 to 34 AWG




-G
= 10 μ" (0.25 μm)
Gold on contact area,
3 μ" (0.08 μm)
Gold on tail

-U
= Micro Reel
(4K Contacts)

-M
= Mini Reel
(15K Contacts)

-R
= Reel
(50K Contacts)

POSITIONS PER ROW	A	B
-05	(9.50) .374	(11.50) .453
-10	(13.50) .531	(15.50) .610
-15	(17.50) .689	(19.50) .768
-20	(21.50) .846	(23.50) .925

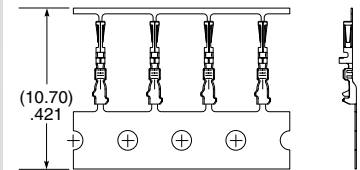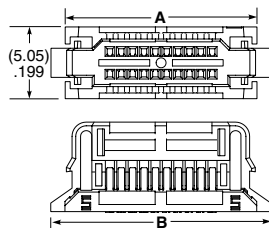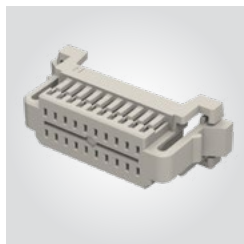

TOOLING

Hand Tool: CAT-HT-396-3232-12

Mini Applicator: CAT-MC-396-3232-XX-03

Note:

Some lengths, styles and options are non-standard, non-returnable

View complete specifications at: samtec.com?ISDE & samtec.com?CC396

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Samtec:

[SESDT-10-32-G-03.0-L1](#) [SESDT-15-32-G-09.0-L1](#) [SESDT-05-32-G-03.0-L1](#) [SESDT-05-32-G-05.0-L](#) [SESDT-05-32-G-05.9-L1](#) [SESDT-05-32-G-06.0-L1](#) [SESDT-10-32-G-20.0-L1](#) [SESDT-10-32-G-30.0-L1](#) [SESDT-05-32-G-03.0-L](#) [SESDT-10-32-G-05.0-L1](#) [SESDT-10-32-G-06.0-L1](#) [SESDT-20-32-G-03.0-L](#) [SESDT-05-32-G-06.0-L](#) [SESDT-20-32-G-06.0-L](#) [SESDT-10-32-G-10.0-L1](#) [SESDT-20-32-G-10.0-L1](#) [SESDT-05-32-G-08.0-L](#) [SESDT-05-32-G-12.0-L](#) [SESDT-10-32-G-06.0-L](#) [SESDT-15-32-G-03.0-L1](#) [SESDT-15-32-G-04.0-L1](#) [SESDT-15-32-G-06.0-L](#) [SESDT-15-32-G-12.0-L](#) [SESDT-20-32-G-03.0-L1](#) [SESDT-05-32-G-12.0-L1](#) [SESDT-15-32-G-05.0-L1](#) [SESDT-20-32-G-05.0-L1](#) [SESDT-20-32-G-12.0-L](#) [SESDT-20-32-G-16.0-L1](#) [SESDT-10-32-G-03.0-L](#) [SESDT-20-32-G-12.0-L1](#) [SESDT-10-32-G-12.0-L](#) [SESDT-15-32-G-03.0-L](#) [SESDT-20-32-G-06.0-L1](#) [SESDT-20-32-G-11.8-L1](#) [SESDT-05-32-G-08.0-L1](#) [SESDT-15-32-G-03.2-L1](#) [SESDT-05-32-G-15.0-L1](#) [SESDT-05-32-G-16.0-L1](#) [SESDT-10-32-G-08.0-L1](#) [SESDT-10-32-G-36.0-L1](#) [SESDT-10-32-G-40.0-L1](#) [SESDT-15-32-G-11.8-L](#) [SESDT-15-32-G-15.0-L](#) [SESDT-20-32-G-05.0-L](#) [SESDT-20-32-G-07.8-L1](#) [SESDT-20-32-G-40.0-L1](#) [SESDT-20-32-G-40.0-L](#) [SESDT-10-32-G-03.0-L2](#) [SESDT-10-32-G-04.0-L1](#) [SESDT-15-32-G-06.0-L1](#) [SESDT-15-32-G-08.0-L](#) [SESDT-15-32-G-08.0-L1](#) [SESDT-10-32-G-04.5-L1](#) [SESDT-10-32-G-05.0-L3](#) [SESDT-10-32-G-18.0-L](#) [SESDT-10-32-G-18.0-L3](#) [SESDT-10-32-G-50.0-L1](#) [SESDT-15-32-G-10.0-L1](#) [SESDT-15-32-G-15.0-L1](#) [SESDT-15-32-G-20.0-L](#) [SESDT-20-32-G-03.5-L3](#) [SESDT-20-32-G-14.0-L1](#) [SESDT-05-32-G-03.2-L](#) [SESDT-05-32-G-03.9-L1](#) [SESDT-05-32-G-10.0-L](#) [SESDT-05-32-G-10.2-L1](#) [SESDT-05-32-G-40.0-L](#) [SESDT-10-32-G-18.0-L1](#) [SESDT-20-32-G-03.0-L4](#) [SESDT-05-32-G-03.2-L1](#) [SESDT-05-32-G-04.0-L1](#) [SESDT-05-32-G-10.0-L1](#) [SESDT-05-32-G-48.0-L1](#) [SESDT-10-32-G-08.7-L1](#) [SESDT-10-32-G-98.4-L1](#) [SESDT-15-32-G-06.3-L1](#) [SESDT-20-32-G-03.0-L3](#) [SESDT-20-32-G-15.0-L](#) [SESDT-20-32-G-20.0-L1](#) [SESDT-20-32-G-21.0-L1](#) [SESDT-05-32-G-08.7-L1](#) [SESDT-05-32-G-31.5-L1](#) [SESDT-10-32-G-09.0-L2](#) [SESDT-15-32-G-07.8-L1](#) [SESDT-20-32-G-04.0-L1](#) [SESDT-20-32-G-08.0-L1](#) [SESDT-20-32-G-21.3-L1](#) [SESDT-20-32-G-30.0-L](#) [SESDT-05-32-G-03.0-L2](#) [SESDT-05-32-G-03.1-L1](#) [SESDT-05-32-G-12.0-L2](#) [SESDT-10-32-G-24.0-L1](#) [SESDT-10-32-G-29.4-L1](#) [SESDT-15-32-G-12.0-L1](#) [SESDT-20-32-G-04.8-L1](#) [SESDT-20-32-G-05.9-L](#) [SESDT-20-32-G-05.9-L1](#) [SESDT-20-32-G-98.4-L](#) [SESDT-10-32-G-03.0-L3](#)