



(0.80 mm) .0315" PITCH • DISCRETE WIRE CABLE ASSEMBLY/COMPONENTS

SESDT	POSITIONS PER ROW	32	PLATING OPTION	ASSEMBLED LENGTH	OPTIONS
-------	-------------------	----	----------------	------------------	---------

= Double Row
Blue *Teflon™
Fluoropolymer Cable
(32 AWG)

-05, -10, -15, -20
(Standard sizes)

-G
= 10 μ" (0.25 μm)
Gold on contact area,
3 μ" (0.08 μm) Gold on tail

-"XX.X"
= Assembled
Length in Inches
(76.2 mm) 03.0" min.

Double Ended Assemblies

-L1
= Pin 1 to Pin 1

-L2
= Pin 1 to Pin 2

-L3
= Pin 1 to Pin N-1

-L4
= Pin 1 to Pin N

Single Ended Assembly

-L
= Latching


SESDT
Board Mates:
TEM-L1

SPECIFICATIONS


Insulator Material:
Natural Nylon
Contact Material:
BeCu
Plating:
Au over 50 μ" (1.27 μm) Ni
Wire:
Tinned Copper
Wire Insulation:
FEP
Operating Temp Range:
-55 °C to +125 °C
Current Rating:
1.9 A per pin
(2 pins powered)
Voltage Rating:
200 VAC/280 VDC

*Teflon™ is a trademark of The
Chemours Company FC, LLC used
under license by Samtec.

Note:
Teflon™ Fluoropolymer cable is intended
for crimp only. Contact Samtec for
solderable cable applications.

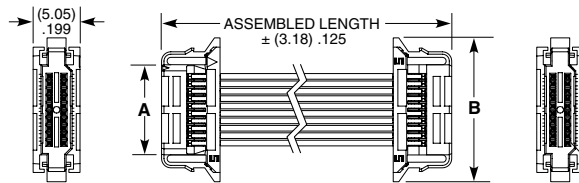

DOUBLE ENDED

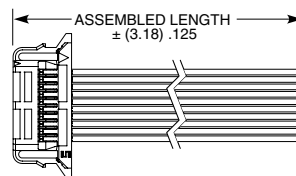

SINGLE ENDED

NO. OF POSITIONS	A	B
-05	(5.70) .224	(11.50) .453
-10	(9.70) .382	(15.50) .610
-15	(13.70) .539	(19.50) .768
-20	(17.70) .697	(23.50) .925

View complete specifications at: samtec.com?SESDT

ISDE	POSITIONS PER ROW	D	L	SERIES	WIRE GAUGE	PLATING	REEL OPTIONS
------	-------------------	---	---	--------	------------	---------	--------------

-05, -10, -15, -20
(Standard sizes)

-D
= Dual Row

-L
= Latch

CC396
= Contact

-3234
= 32 to 34 AWG



-G
= 10 μ" (0.25 μm)
Gold on
contact
area,
3 μ" (0.08 μm)
Gold on
tail

-U
= Micro Reel
(4K Contacts)

-M
= Mini Reel
(15K Contacts)

-R
= Reel
(50K Contacts)

POSITIONS PER ROW	A	B
-05	(9.50) .374	(11.50) .453
-10	(13.50) .531	(15.50) .610
-15	(17.50) .689	(19.50) .768
-20	(21.50) .846	(23.50) .925

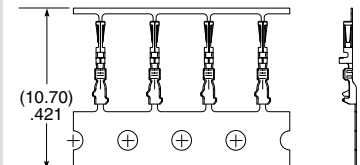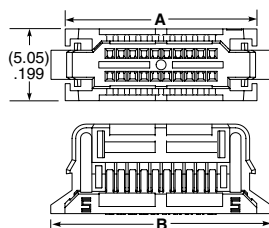

TOOLING

Hand Tool: CAT-HT-396-3232-12

Mini Applicator: CAT-MC-396-3232-XX-03

Note:
Some lengths, styles and
options are non-standard,
non-returnable

View complete specifications at: samtec.com?ISDE & samtec.com?CC396

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[SESDT-05-32-G-03.0-L-L1](#) [SESDT-05-32-G-18.0-L1](#)