

MICRO BLADE & BEAM SOCKET & HEADER

(0.40 mm) .0158" PITCH • SS4/ST4 SERIES

28
Gbps



SS4
Mates:
ST4

ST4
Mates:
SS4

SPECIFICATIONS

Insulator Material:

Black LCP

Contact Material:

Phosphor Bronze

Plating:

Au or Sn over

50 μ" (1.27 μm) Ni

Operating Temp Range:

-55 °C to +125 °C

Current Rating:

1.6 A per pin

(2 pins powered)

PROCESSING


 

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0.10 mm) .004" max

SS4	POSITIONS PER ROW	LEAD STYLE	PLATING OPTION	D	K	"X"R
	-10, -20, -30, -40, -50	-3.00 = 3.00 mm -3.50 = 3.50 mm	-L = 10 μ" (0.25 μm) Gold on contact, Matte Tin on tail		(Required in callout) -K = (3.50 mm) .138" DIA Polyimide Film Pick & Place Pad	(Required in callout) -TR = Tape & Reel -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

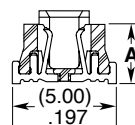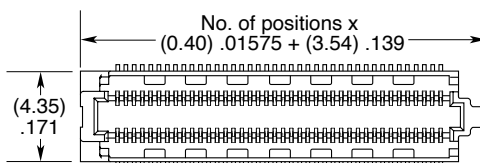




LEAD STYLE	A	B
-3.00	(2.85) .112	(3.50) .138
-3.50	(3.35) .132	(4.00) .157

ST4	POSITIONS PER ROW	LEAD STYLE	PLATING OPTION	D	P	"X"R
	-10, -20, -30, -40, -50	-1.00 = 1.00 mm -1.50 = 1.50 mm -2.50 = 2.50 mm	-L = 10 μ" (0.25 μm) Gold on contact, Matte Tin on tail		(Required in callout) -P = Pick & Place Pad	(Required in callout) -TR = Tape & Reel -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks)

MATED HEIGHT *

ST4 LEAD STYLE	SS4 LEAD STYLE	
	-3.00	-3.50
-1.00	(4.00 mm) .157"	(4.50 mm) .177"
-1.50	(4.50 mm) .177"	(5.00 mm) .197"
-2.50	(5.50 mm) .217"	(6.00 mm) .236"

  *Processing conditions will affect mated height.

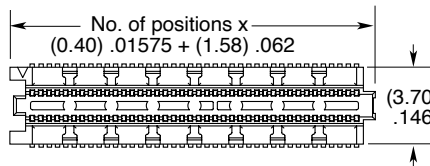

LEAD STYLE	A	B
-1.00	(1.00) .039	(3.08) .121
-1.50	(1.50) .059	(3.58) .141
-2.50	(2.50) .098	(4.58) .180

Note:
Some lengths, styles and options are non-standard, non-returnable.

samtec.com?SS4 or samtec.com?ST4

F-224

Unless otherwise approved in writing by Samtec, all parts and components are designed and built according to Samtec's specifications which are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[ST4-40-1.00-L-D-P-TR](#) [ST4-50-1.00-L-D-P-TR](#) [ST4-20-1.00-L-D-P-TR](#) [ST4-30-1.00-L-D-P-TR](#) [ST4-40-1.50-L-D-P-TR](#) [ST4-15-1.50-L-D-P-TR](#) [ST4-30-1.50-L-D-P-TR](#) [ST4-15-1.00-L-D-P-TR](#) [ST4-30-2.50-L-D-P-TR](#) [ST4-40-2.50-L-D-P-TR](#) [ST4-10-2.50-L-D-P-TR](#) [ST4-10-1.00-L-D-P-TR](#) [ST4-20-2.50-L-D-P-TR](#) [ST4-50-2.50-L-D-P-TR](#) [ST4-20-1.50-L-D-P-TR](#) [ST4-10-1.50-L-D-P-TR](#) [ST4-50-1.50-L-D-P-TR](#) [ST4-30-1.00-L-D-P-FR](#) [ST4-15-1.50-L-D-P-FR](#) [ST4-20-1.50-L-D-P-FR](#) [ST4-30-2.50-L-D-P-FR](#) [ST4-40-2.50-L-D-P-FR](#) [ST4-50-1.50-L-D-P-FR](#) [ST4-15-1.00-L-D-P-FR](#) [ST4-10-1.50-L-D-P-FR](#) [ST4-10-2.50-L-D-P-FR](#) [ST4-50-2.50-L-D-P-FR](#) [ST4-20-1.00-L-D-P-FR](#) [ST4-40-1.50-L-D-P-FR](#) [ST4-40-1.00-L-D-P-FR](#) [ST4-30-1.50-L-D-P-FR](#) [ST4-20-2.50-L-D-P-FR](#) [ST4-50-1.00-L-D-P-FR](#) [ST4-10-1.00-L-D-P-FR](#)