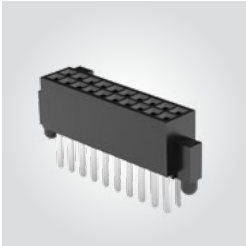
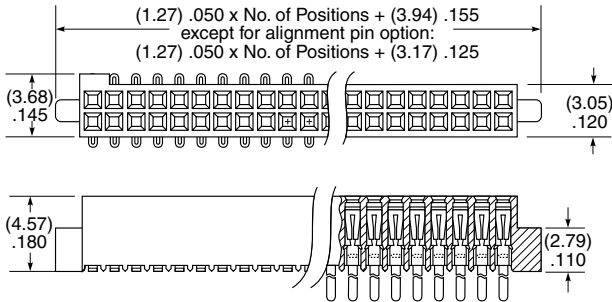
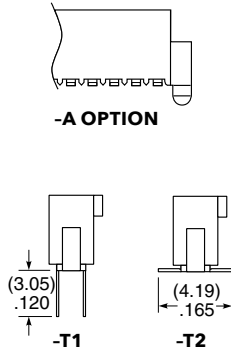
 
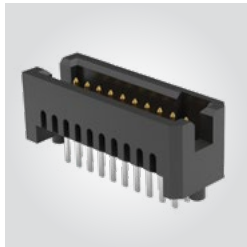
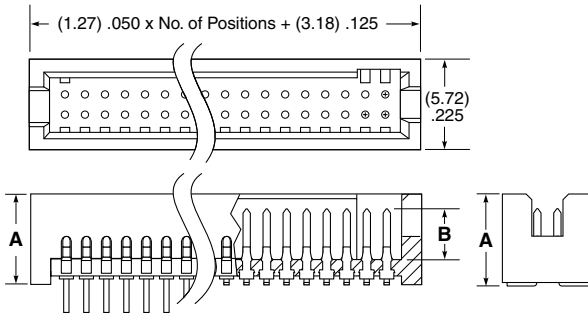


(1.27 mm) .050" PITCH • COST-EFFECTIVE HEADER/SOCKET

SFC	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	D	OPTIONS
		04, 05, 10, 15, 20, 25, 30, 35, 40, 45, 50 (Standard sizes)	-T1 = Through-hole Tiger Eye™ LITE -T2 = Surface Mount Tiger Eye™ LITE	-F = Gold flash on contact, Matte Tin on tail -L = 10 μ" (0.25 μm) Gold on contact, Matte Tin on tail		-A = Alignment Pin -K = (4.00 mm) .157" DIA Polyimide film Pick & Place Pad -TR = Tape & Reel (-T2 only) -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks) (-T2 only)
SFC Board Mates: TFC Cable Mates: TFSD, TFSDT						 -A OPTION  -T1 -T2

SFC
Board Mates:
TFC
Cable Mates:
TFSD, TFSdT

View complete specifications at: samtec.com?SFC

TFC	1	NO. PINS PER ROW	LEAD STYLE	PLATING OPTION	D	OPTIONS																													
		03, 04, 06, 08 (Lead Style -01 & -02 only) 05, 07, 10, 15, 20, 25, 30, 35, 40, 45, 50 (Standard sizes)	-X1 = Through-hole -X2 = Surface Mount	-F = Gold flash on post, Matte Tin on tail -L = 15 μ" (0.38 μm) Gold on post, Matte Tin on tail		-RA = Right-angle (-01 only) -A = Alignment Pin -LC = Locking Clip (Manual Placement required) (not available with -RA) -K = (6.75 mm) .266" DIA Polyimide film Pick & Place Pad (not available with -RA) -P = Plastic Pick & Place Pad (5 positions min.) (not available with -RA) -TR = Tape & Reel (-X2 only) (not available with -RA) -FR = Full Reel Tape & Reel (must order max. quantity per reel; contact Samtec for quantity breaks) (-X2 only) (not available with -RA)																													
																																			
			<table><tr><th>SMT LEAD STYLE</th><th>A</th><th>B</th><th>TH LEAD STYLE</th><th>A</th><th>B</th></tr><tr><td>-02</td><td>(5.72) .225</td><td>(3.38) .133</td><td>-01</td><td>(5.59) .220</td><td>(3.38) .133</td></tr><tr><td>-12</td><td>(7.49) .295</td><td></td><td>-11</td><td>(7.37) .290</td><td></td></tr><tr><td>-22</td><td>(9.27) .365</td><td>(3.30) .130</td><td>-21</td><td>(9.14) .360</td><td>(3.30) .130</td></tr><tr><td>-32</td><td>(11.18) .440</td><td></td><td>-31</td><td>(11.05) .435</td><td></td></tr></table>				SMT LEAD STYLE	A	B	TH LEAD STYLE	A	B	-02	(5.72) .225	(3.38) .133	-01	(5.59) .220	(3.38) .133	-12	(7.49) .295		-11	(7.37) .290		-22	(9.27) .365	(3.30) .130	-21	(9.14) .360	(3.30) .130	-32	(11.18) .440		-31	(11.05) .435
SMT LEAD STYLE	A	B	TH LEAD STYLE	A	B																														
-02	(5.72) .225	(3.38) .133	-01	(5.59) .220	(3.38) .133																														
-12	(7.49) .295		-11	(7.37) .290																															
-22	(9.27) .365	(3.30) .130	-21	(9.14) .360	(3.30) .130																														
-32	(11.18) .440		-31	(11.05) .435																															

TFC
Board Mates:
SFC

Cable Mates:
SFSD, SFSDT

Note:

Note:
Some lengths, styles and
options are non-standard,
non-returnable.

View complete specifications at: samtec.com?TFC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[TFC-105-12-LM-D-A](#)