



YMQ-110-01-L-5

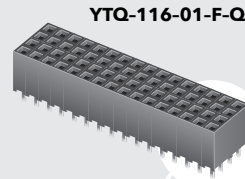

YMQ-116-01-F-Q

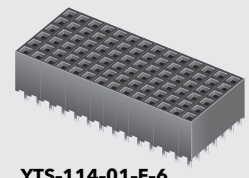

YTS-114-01-F-6

(2.00 mm) .0787"

YTS, YMQ SERIES

HIGH-DENSITY SOCKET STRIP

SPECIFICATIONS

For complete specifications see www.samtec.com?YTS or www.samtec.com?YMQ

Insulator Material:

Black Liquid Crystal Polymer

Contact Material:

Phosphor Bronze

Operating Temp Range:

-55 °C to +125 °C

Plating:

Sn or Au over 50 μ" (1.27 μm) Ni

Insertion Depth:

(2.62 mm) .103" to (5.03 mm) .198"

Max Cycles:

100 with 10 μ" (0.25 μm) Au

RoHS Compliant:

Yes

Mates with:

YTT, YTW, YTE, TMMS



Choice of four, five or six row

(2.00 mm) .0787" pitch

(6.35 mm) .250"

(2.00 mm) .0787" TYP

PROCESSING

YTS Lead-Free Solderable:


Wave Only

YMQ Lead-Free Solderable:

Wave or reflow with Matte Sn plating

RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality

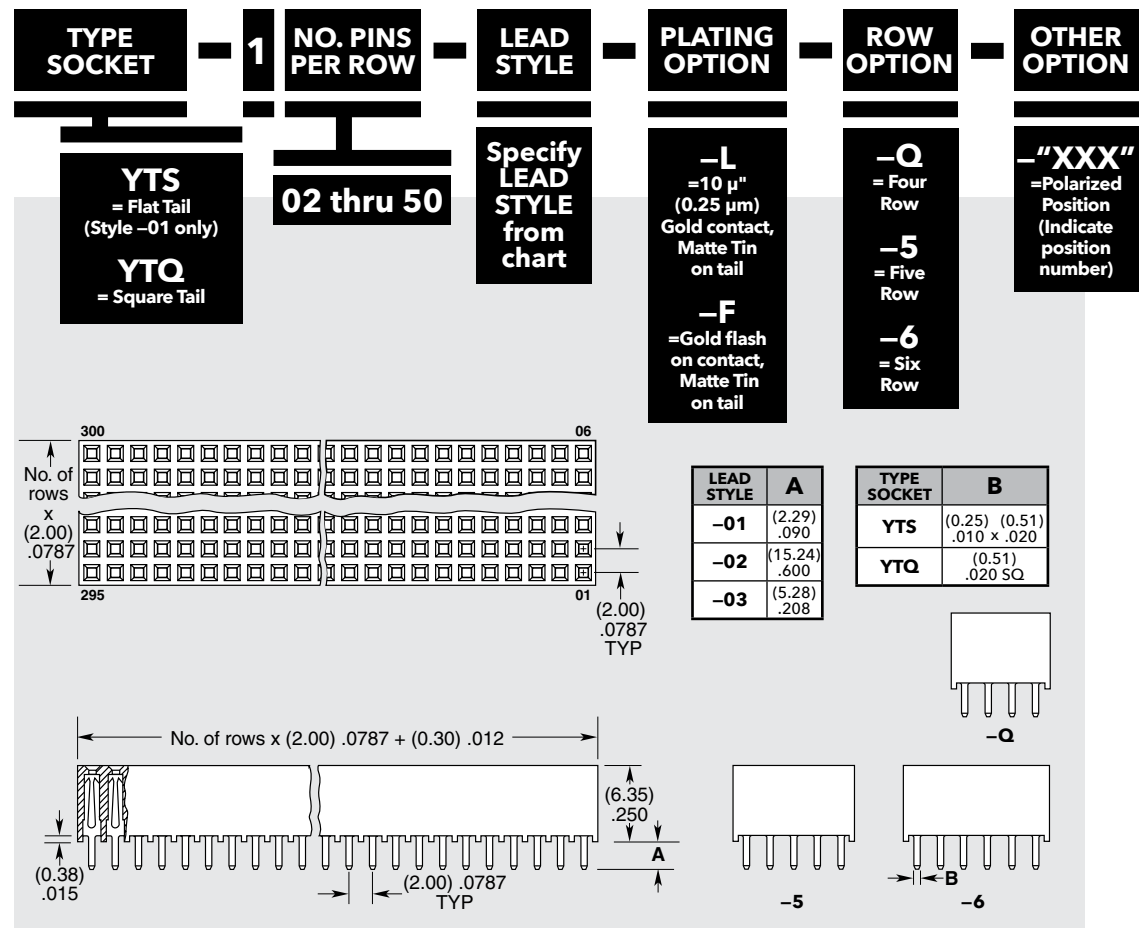

Note:
Some lengths, styles and options are non-standard, non-returnable.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Samtec:](#)

[YTQ-144-02-L-Q](#) [YTQ-145-03-L-Q](#) [YTQ-140-03-F-Q](#) [YTQ-140-03-L-5](#) [YTQ-119-01-L-5](#) [YTQ-120-01-F-5](#) [YTQ-122-03-H-Q-050](#) [YTQ-122-03-L-5](#) [YTQ-126-01-L-Q](#) [YTQ-130-02-L-Q-117](#) [YTQ-130-03-F-Q](#) [YTQ-136-03-L-Q](#) [YTQ-138-02-L-Q](#) [YTQ-139-01-F-5](#) [YTQ-145-01-L-Q](#) [YTQ-118-03-F-Q](#) [YTQ-118-03-S-Q](#) [YTQ-123-03-L-5](#) [YTQ-127-03-L-Q](#) [YTQ-130-02-L-Q](#) [YTQ-120-03-L-5](#) [YTQ-130-03-L-Q](#) [YTQ-132-01-L-Q](#) [YTQ-140-01-L-6](#) [YTQ-140-03-S-Q](#) [YTQ-150-03-L-5](#) [YTQ-119-03-L-5](#) [YTQ-121-01-S-Q](#) [YTQ-121-03-S-Q](#) [YTQ-125-03-S-Q](#) [YTQ-126-03-H-Q-050](#) [YTQ-130-03-G-Q](#) [YTQ-150-01-F-Q](#) [YTQ-140-02-L-Q](#) [YTQ-150-02-S-Q](#) [YTQ-150-03-F-5](#) [YTQ-150-03-F-Q](#) [YTQ-117-03-L-Q](#) [YTQ-118-01-L-5](#) [YTQ-120-02-L-Q](#) [YTQ-125-01-L-5](#) [YTQ-125-01-L-6](#) [YTQ-132-03-L-Q](#) [YTQ-134-01-S-6](#) [YTQ-134-02-L-Q](#) [YTQ-150-02-S-5](#) [YTQ-105-01-L-Q](#) [YTQ-105-03-L-Q](#) [YTQ-115-03-L-Q](#) [YTQ-120-01-F-Q](#) [YTQ-120-01-L-5](#) [YTQ-120-03-G-Q-MW](#) [YTQ-120-03-L-Q](#) [YTQ-124-01-L-Q](#) [YTQ-125-03-F-5](#) [YTQ-130-03-L-5](#) [YTQ-130-03-S-Q](#) [YTQ-135-03-S-Q](#) [YTQ-140-01-L-Q](#) [YTQ-140-03-L-Q](#) [YTQ-150-01-L-6](#) [YTQ-150-03-L-Q](#) [YTQ-110-01-L-Q](#) [YTQ-111-01-S-Q](#) [YTQ-111-03-L-5](#) [YTQ-112-01-L-Q](#) [YTQ-115-01-L-5](#) [YTQ-125-01-L-Q](#) [YTQ-130-01-F-5](#) [YTQ-130-02-G-Q](#) [YTQ-134-03-L-Q](#) [YTQ-140-01-F-Q](#) [YTQ-144-01-L-5](#) [YTQ-150-02-F-Q](#) [YTQ-115-01-F-Q](#) [YTQ-115-01-L-5-038](#) [YTQ-118-01-S-Q](#) [YTQ-120-01-G-Q](#) [YTQ-123-01-L-Q](#) [YTQ-124-01-L-5](#) [YTQ-125-02-L-Q](#) [YTQ-125-03-L-6](#) [YTQ-128-03-L-Q](#) [YTQ-130-01-F-Q](#) [YTQ-130-02-G-Q-117](#) [YTQ-134-03-L-5](#) [YTQ-150-01-L-5](#) [YTQ-150-01-L-Q](#) [YTQ-118-02-F-Q](#) [YTQ-122-03-H-Q](#) [YTQ-130-01-LM-Q](#) [YTQ-130-03-L-Q-001](#) [YTQ-150-02-L-5](#) [YTQ-150-03-L-6](#) [YTQ-103-01-L-Q](#) [YTQ-110-01-F-Q](#) [YTQ-114-02-F-Q](#) [YTQ-116-01-L-6](#) [YTQ-104-01-F-Q](#) [YTQ-111-01-L-5](#)