


PN-A SERIES PC NEMA 6P/IP68 RATED

Ordering Information

Part Number Opaque Cover	Part Number Clear Cover	External Length (in)	External Width (in)	External Depth (in)	Internal Length (in)	Internal Width (in)	Internal Depth (in)	Weight (Lb)
PN-1320-A	PN-1320-AC	2.52	2.28	1.38	2.28	2.04	1.14	0.03
PN-1321-A	PN-1321-AC	4.53	2.56	1.58	4.29	2.32	1.34	0.05
PN-1322-A	PN-1322-AC	4.53	2.56	2.17	4.29	2.32	1.93	0.06
PN-1323-A	PN-1323-AC	4.53	3.54	2.17	4.29	3.30	1.93	0.08
PN-1324-A	PN-1324-AC	6.73	4.76	2.17	6.49	4.52	1.93	0.13
PN-1325-A	PN-1325-AC	8.74	5.75	2.17	8.50	5.51	1.93	0.18
PN-1326-A	PN-1326-AC	7.68	3.15	2.17	7.44	2.91	1.93	0.10
PN-1327-A	PN-1327-AC	6.73	4.76	3.15	6.49	4.52	2.91	0.15
PN-1328-A	PN-1328-AC	4.53	3.54	3.15	4.29	3.30	2.91	0.09
PN-1329-A	PN-1329-AC	8.74	5.75	2.95	8.50	5.51	2.71	0.21
PN-1330-A	PN-1330-AC	2.05	1.97	1.38	1.81	1.73	1.14	0.02
PN-1331-A	PN-1331-AC	3.23	3.15	2.17	2.99	2.91	1.93	0.06
PN-1332-A	PN-1332-AC	6.30	3.15	2.17	6.06	2.91	1.93	0.09
PN-1333-A	PN-1333-AC	6.30	3.15	3.35	6.06	2.91	3.11	0.11
PN-1334-A	PN-1334-AC	7.87	4.72	2.95	7.63	4.48	2.71	0.17
PN-1335-A	PN-1335-AC	10.43	7.28	3.74	10.19	7.04	3.50	0.35
PN-1336-A	PN-1336-AC	4.72	4.72	2.36	4.48	4.48	2.12	0.10
PN-1337-A	PN-1337-AC	4.72	4.72	3.54	4.48	4.48	3.30	0.11
PN-1338-A	PN-1338-AC	6.30	6.30	2.36	6.06	6.06	2.12	0.15
PN-1339-A	PN-1339-AC	6.26	6.26	3.54	6.02	6.02	3.30	0.19
PN-1340-A	PN-1340-AC	9.45	6.30	3.54	9.21	6.06	3.30	0.28
PN-1341-A	PN-1341-AC	9.45	6.24	4.72	9.21	6.00	4.48	0.35
PN-1342-A	PN-1342-AC	11.81	9.06	3.41	11.57	8.82	3.17	0.45
PN-1343-A	PN-1343-AC	11.81	9.06	4.39	11.57	8.82	4.15	0.51
PN-1344-A	PN-1344-AC	14.17	7.87	5.91	13.93	7.63	5.67	0.74

Priced, sold and packaged in quantities of one

BUD PN-A Series PC NEMA

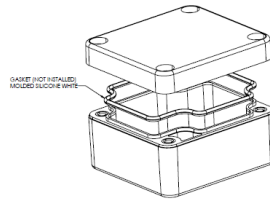

Benefits and Features

- UL508A & NEMA 1, 2, 3, 4, 4x,6,6P 12, and 13 enclosure specifications
- Designed to IP68 of IEC 529
- UL Listed (E194432 Vol 1)
- Wall mounting holes and cover attaching screws are outside the sealing area thus preventing ingress of moisture and dust
- Most models have internal guide slots for mounting PCB assemblies vertically
- Internal bosses allow mounting of PCBs horizontally or for connection of terminals etc
- Cover screws are stainless steel, non-magnetic and fasten into threaded brass inserts
- **Gasket Material:** molded Silicon (not installed)
- **Color:** Light Gray body / Gray or Clear cover
- RoHS Certified: Compliant
- **Indoor / Outdoor:** Outdoor (UV Stabilized)
- Flammability Rating: UL94-HB
- Type of Plastic: Polycarbonate
- Service Temperature Min: -40°C
- Service Temperature Max: 120°C

Accessories


- Aluminum Internal Panel PNX series
- External mounting Brackets

Competitive Advantages

- Non-metallic IP68 / NEMA 6P enclosures
- UV resistant for outdoor applications

Availability

January 2021

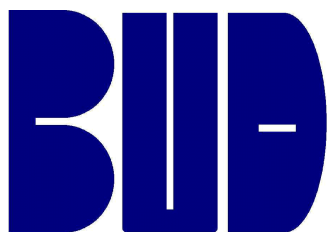

Bud Industries, Inc.
4605 E. 355th Street
Willoughby, Ohio 44094

saleseast@budind.com
saleswest@budind.com

www.budind.com

BUD PN-A Series PC NEMA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[PN-1322-A](#) [PN-1325-AC](#) [PN-1326-AC](#) [PN-1329-A](#) [PN-1332-AC](#) [PN-1322-AC](#) [PN-1325-A](#) [PN-1326-A](#) [PN-1327-AC](#) [PN-1335-A](#) [PN-1336-A](#) [PN-1337-AC](#) [PN-1338-A](#) [PN-1340-AC](#) [PN-1329-AC](#) [PN-1341-AC](#) [PN-1327-A](#) [PN-1340-A](#) [PN-1332-A](#) [PN-1333-A](#) [PN-1341-A](#) [PN-1324-AC](#) [PN-1330-A](#) [PN-1331-AC](#) [PN-1333-AC](#) [PN-1334-A](#) [PN-1335-AC](#) [PN-1338-AC](#) [PN-1339-A](#) [PN-1324-A](#) [PN-1328-AC](#) [PN-1334-AC](#) [PN-1337-A](#) [PN-1339-AC](#) [PN-1328-A](#) [PN-1330-AC](#) [PN-1331-A](#) [PN-1336-AC](#)