

PN-A SERIES WITH MOLDED MOUNTING BRACKET


PC NEMA 6P/IP68 RATED

Ordering Information*

Part Number Opaque Cover	Part Number Clear Cover	External Length (in)	External Width (in)	External Depth (in)	Internal Length (in)	Internal Width (in)	Internal Height (in)	Weight (Lb)
PN-1320-AMB	PN-132 0-ACMB	2.52	2.28	1.38	2.28	2.04	1.14	0.03
PN-1321-AMB	PN-132 1-ACMB	4.53	2.56	1.57	4.29	2.32	1.33	0.05
PN-1322-AMB	PN-132 2-ACMB	4.53	2.56	2.17	4.29	2.32	1.93	0.06
PN-1323-AMB	PN-132 3-ACMB	4.53	3.54	2.17	4.29	3.30	1.93	0.08
PN-1324-AMB	PN-132 4-ACMB	6.73	4.76	2.17	6.49	4.52	1.93	0.13
PN-1325-AMB	PN-132 5-ACMB	8.74	5.75	2.17	8.50	5.51	1.93	0.18
PN-1327-AMB	PN-132 7-ACMB	6.73	4.76	3.15	6.49	4.52	2.91	0.15
PN-1328-AMB	PN-132 8-ACMB	4.53	3.54	3.15	4.29	3.30	2.91	0.09
PN-1329-AMB	PN-132 9-ACMB	8.74	5.75	2.95	8.50	5.51	2.71	0.21
PN-1330-AMB	PN-133 0-ACMB	2.05	1.97	1.38	1.81	1.73	1.14	0.02
PN-1331-AMB	PN-133 1-ACMB	3.23	3.15	2.17	2.99	2.91	1.93	0.06
PN-1332-AMB	PN-133 2-ACMB	6.30	3.15	2.17	6.06	2.91	1.93	0.09
PN-1333-AMB	PN-133 3-ACMB	6.30	3.15	3.35	6.06	2.91	3.11	0.11
PN-1335-AMB	PN-133 5-ACMB	10.43	7.28	3.74	10.19	7.04	3.50	0.35
PN-1336-AMB	PN-133 6-ACMB	4.72	4.72	2.36	4.48	4.48	2.12	0.10
PN-1337-AMB	PN-133 7-ACMB	4.72	4.72	3.54	4.48	4.48	3.30	0.11

Priced, sold and packaged in quantities of one

**size information related to body, mounting brackets are excluded.*

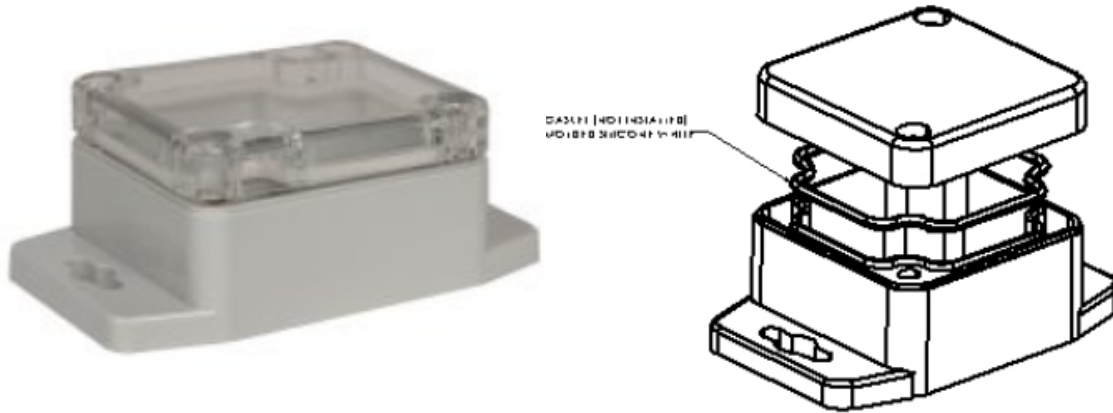

Benefits and Features

- UL508A & NEMA 1, 2, 3, 4, 4x,6,6P 12, and 13 enclosure specifications
- Designed to IP68 of IEC 529
- UL Listed (E194432 Vol 1)
- Wall mounting holes and cover attaching screws are outside the sealing area thus preventing ingress of moisture and dust
- Most models have internal guide slots for mounting PCB assemblies vertically
- Internal bosses allow mounting of PCBs horizontally or for connection of terminals etc
- Cover screws are stainless steel, non-magnetic and fasten into threaded brass inserts
- **Gasket Material:** molded Silicon (not installed)
Color: Light Gray body / Gray or Clear cover
- RoHS Certified: Compliant
- **Indoor / Outdoor:** Outdoor (UV Stabilized)
- Flammability Rating: UL94-HB
- Type of Plastic: Polycarbonate
- Service Temperature Min: -40°C
- Service Temperature Max: 120°C

Accessories

- Aluminum Internal Panel PNX series
- External mounting Brackets

BUD Molded Mounting Bracket NEMA

Applications


- Automation & controls
- General purpose outdoor application
- Multiple internal equipment mounting surfaces
- WIFI and internet

Competitive Advantages

- Non-metallic IP68 / NEMA 6P enclosures
- UV resistant for outdoor applications

Availability

January 2021

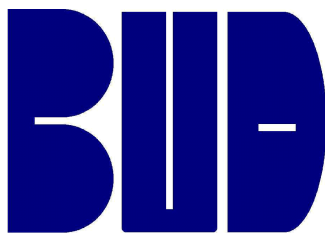

Bud Industries, Inc.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[PN-1324-AMB](#) [PN-1329-AMB](#) [PN-1322-AMB](#) [PN-1332-AMB](#) [PN-1331-AMB](#) [PN-1325-AMB](#) [PN-1328-ACMB](#) [PN-1329-ACMB](#) [PN-1336-ACMB](#) [PN-1337-AMB](#) [PN-1325-ACMB](#) [PN-1328-AMB](#) [PN-1332-ACMB](#) [PN-1330-AMB](#) [PN-1333-AMB](#) [PN-1336-AMB](#) [PN-1337-ACMB](#) [PN-1330-ACMB](#) [PN-1331-ACMB](#) [PN-1324-ACMB](#) [PN-1327-ACMB](#) [PN-1322-ACMB](#) [PN-1323-AMB](#) [PN-1323-ACMB](#) [PN-1327-AMB](#) [PN-1333-ACMB](#)