

PU Series NEMA 6P/IP68 PC Enclosure



Ordering Information

Part Number	Part Number	External Length (in)	External Width (in)	External Depth (in)	Internal Length (in)	Internal Width (in)	Internal Depth (in)	Weight (Lb)
PU-16532	PU-16532-C	2.63	2.63	1.63	2.38	2.38	1.38	0.30
PU-16533	PU-16533-C	4.50	2.63	2.05	4.25	2.38	1.80	0.40
PU-16534	PU-16534-C	4.53	3.56	2.25	4.28	3.31	2.00	0.50
PU-16535	PU-16535-C	4.50	4.50	2.44	4.25	4.25	2.19	0.60
PU-16536	PU-16536-C	5.50	4.13	2.44	5.25	3.88	2.19	0.60
PU-16537		6.13	4.63	2.44	5.88	4.38	2.19	0.70
PU-16538		7.63	4.63	3.09	7.38	4.38	2.84	0.80
PU-16539		8.75	5.25	3.30	8.50	5.00	3.05	1.14
PU-16540		10.00	7.00	4.06	9.75	6.75	3.81	1.75

Priced, sold and packaged in quantities of one

BUD PU SERIES

Benefits and Features

- Modern streamlined design with multiple sizes to choose from
- Rated to NEMA 4X & 6P and Meets IP66 & IP68 requirements
- UL Listed to UL 508A, Type 1, 2, 4, 4X, 6, 6P, 12 & 13
- Designed and tested for a wide variety of outdoor applications and adverse conditions
- Molded from durable, UV stabilized polycarbonate UL94 V0 rated
- Continuous silicone rubber gasket is pre-installed to ensure watertight seal
- Stainless steel screws and brass inserts for cover assembling
- Mounting bosses in base
- All sizes include molded flanges for enclosure mounting

Accessories

- 0.060" Aluminum internal mounting panel (PUX prefix)

Applications


- Wi-Fi applications
- battery charging
- monitoring systems
- waste water
- agriculture
- GPS tracking
- automation & controls

Competition and Competitive Advantages

- Non-metallic IP68 / NEMA 6P enclosures
- UL94 V0 rating
- UV resistant for outdoor applications

Availability

- In Stock

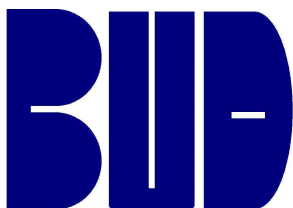

Bud Industries, Inc.

4605 E. 355th Street
Willoughby, Ohio 44094

saleseast@budind.com
saleswest@budind.com

www.budind.com

BUD PU SERIES

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[PU-16533](#) [PU-16533-C](#) [PU-16535](#) [PU-16535-C](#) [PU-16537](#) [PU-16532](#) [PU-16532-C](#) [PU-16536](#) [PU-16536-C](#) [PU-16540](#) [PU-16539](#) [PU-16534](#) [PU-16534-C](#) [PU-16538](#)