
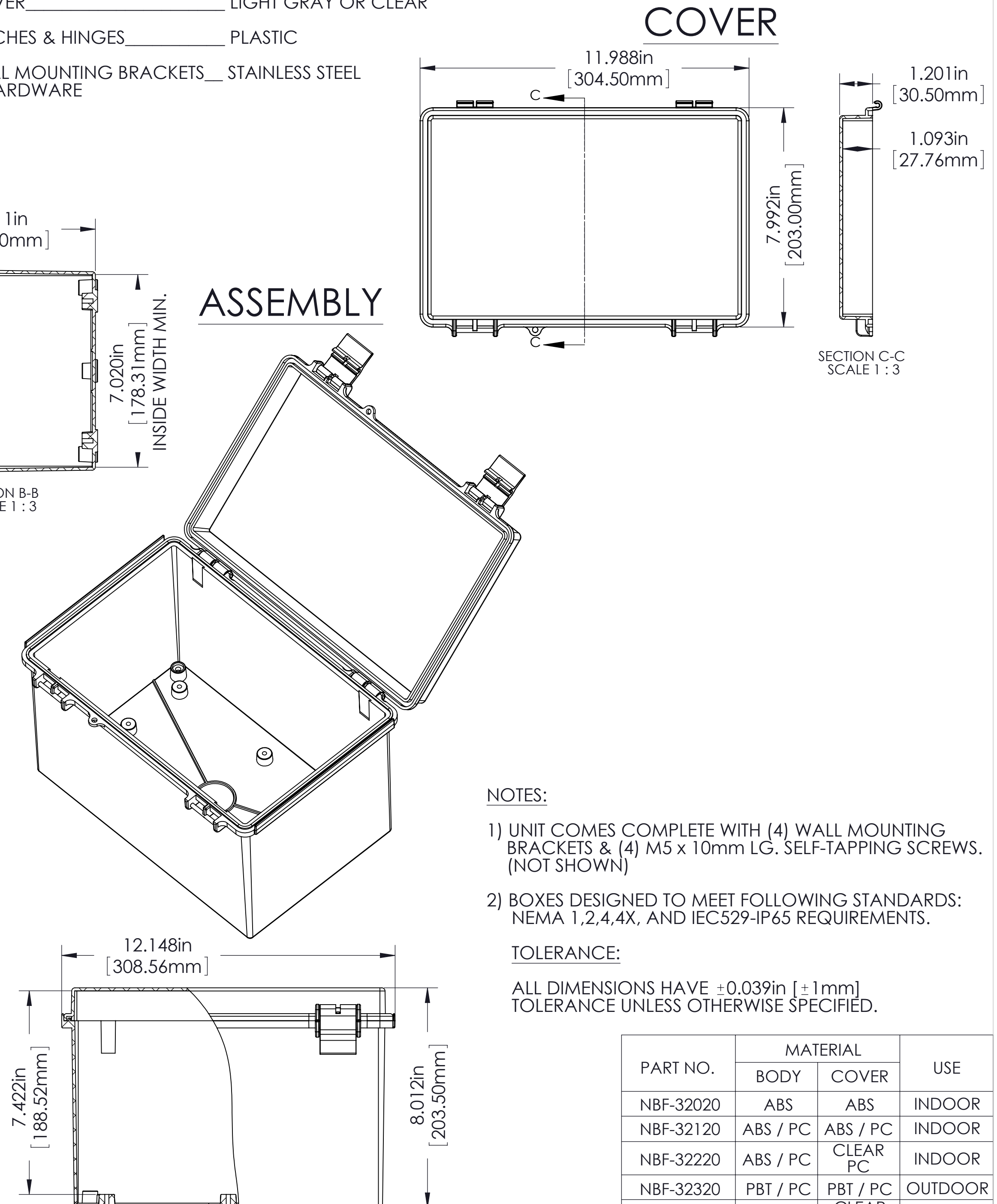


PART NAME	NBF SERIES PLASTIC NEMA BOX			PART No.	NBF-32020 & NBF-32120 & NBF-32220 & NBF-32320 & NBF-32420			REVISION DATE	6/25/2010	
MATERIAL	FLAMMABILITY RATING	CONTINUOUS OPERATING TEMP.		FINISH: BODY_____ LIGHT GRAY COVER_____ LIGHT GRAY OR CLEAR LATCHES & HINGES_____ PLASTIC WALL MOUNTING BRACKETS__ STAINLESS STEEL & HARDWARE COVER 11.98in [304.50mm] C 1.201in [30.50mm]						
ABS	UL94-HB	-40°C ~ +60°C / -40°F ~ 140°F								
CLEAR PC	UL94-V0 UV STABILIZED	-40°C ~ +130°C / -40°F ~ 266°F								
ABS / PC BLEND	UL94-5VA	-40°C ~ +85°C / -40°F ~ 185°F								
PBT / PC BLEND	UL94-5VA + UV (f1)	-40°C ~ +75°C / -40°F ~ 167°F								

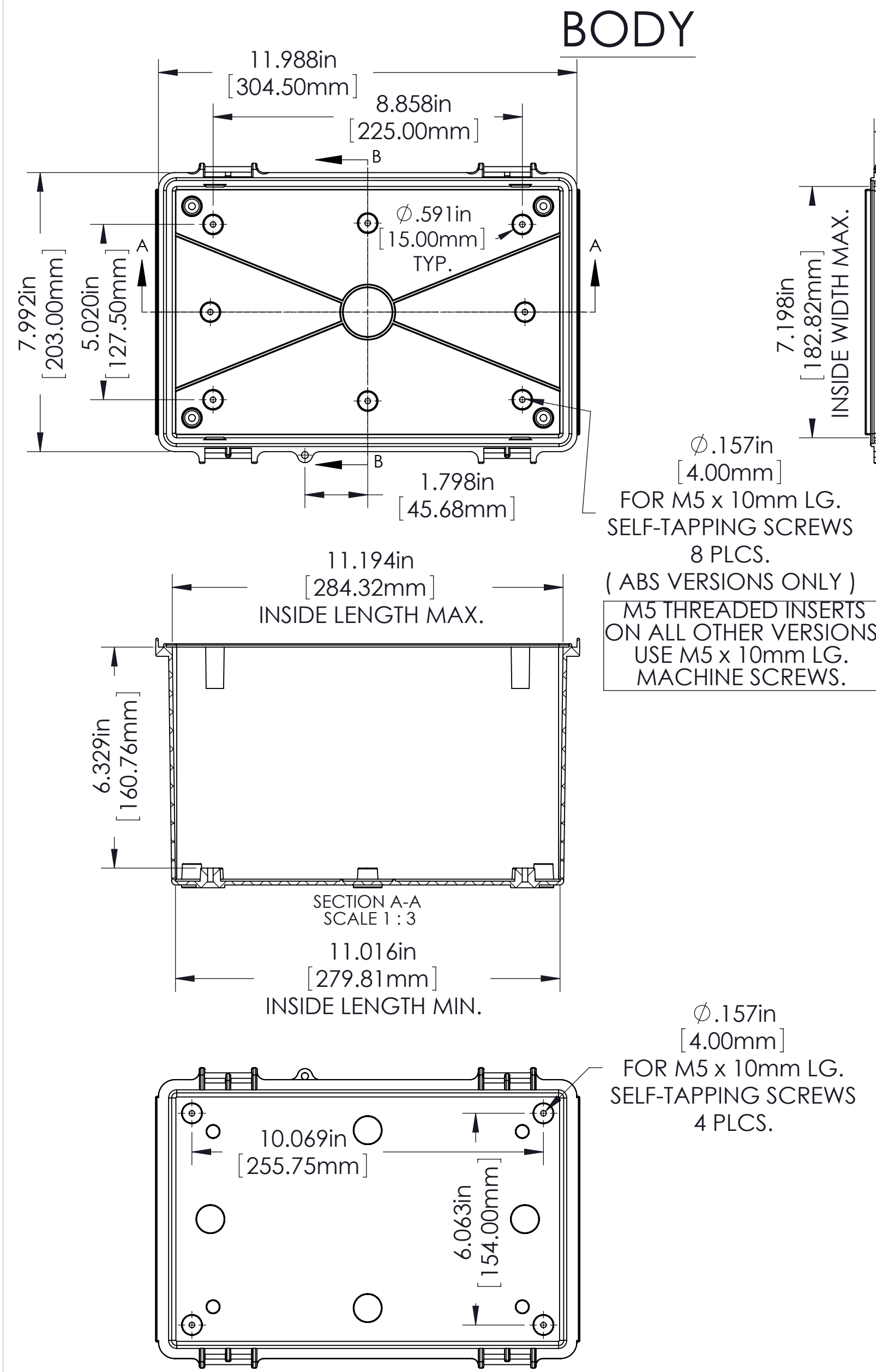

NOTES:

1) UNIT COMES COMPLETE WITH (4) WALL MOUNTING BRACKETS & (4) M5 x 10mm LG. SELF-TAPPING SCREWS. (NOT SHOWN)

2) BOXES DESIGNED TO MEET FOLLOWING STANDARDS: NEMA 1,2,4,4X, AND IEC529-IP65 REQUIREMENTS.

TOLERANCE:

ALL DIMENSIONS HAVE ± 0.039 in [+1mm] TOLERANCE UNLESS OTHERWISE SPECIFIED.

PART NO.	MATERIAL		USE
	BODY	COVER	
NBF-32020	ABS	ABS	INDOOR
NBF-32120	ABS / PC	ABS / PC	INDOOR
NBF-32220	ABS / PC	CLEAR PC	INDOOR
NBF-32320	PBT / PC	PBT / PC	OUTDOOR
NBF-32420	PBT / PC	CLEAR PC	OUTDOOR

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[NBF-32120](#) [NBF-32420](#) [NBF-32020](#) [NBF-32320](#) [NBF-32220](#)