

PART
NAME

CLASSIC II RACK

PART
No.

 
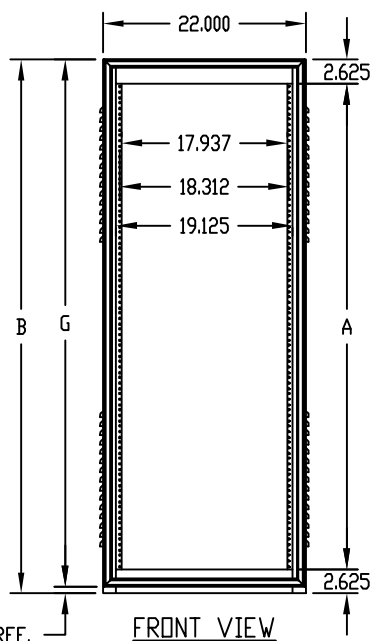
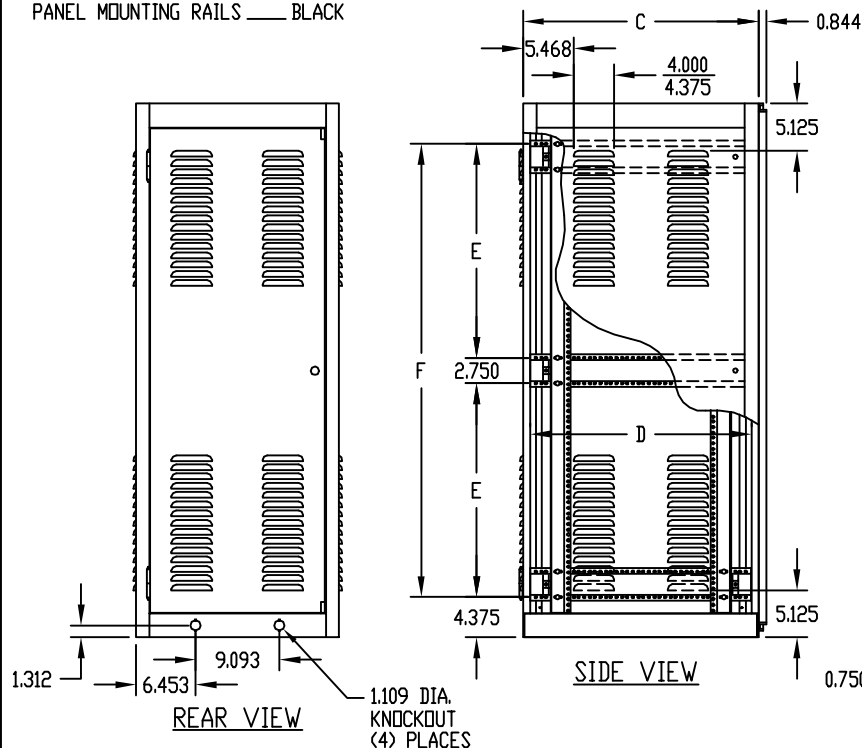
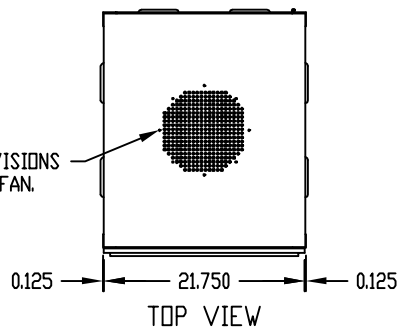
AGR-9572 TO AGR-9596

MATERIAL

PANEL MOUNTING RAILS _____ 12 GA. C.R.S.
 VERTICAL RAILS & FILLERS _____ 14 GA. STEEL
 TOP, BOTTOM, & RAIL SUPPORTS _____ 16 GA. STEEL
 DOOR STIFFENER _____ 18 GA. STEEL
 SIDES & DOOR _____ 20 GA. STEEL
 TRIM EXTRUSIONS _____ ALUMINUM

FINISH

FRAME ASSEMBLY, SIDES
 & DOOR ASSEMBLY _____ GRAY TEXTURE
 _____ ROYAL BLUE TEXTURE
 TRIM EXTRUSIONS _____ CAUSTIC ETCHED & CLEAR ANODIZED
 WITH BLACK INSERT
 PANEL MOUNTING RAILS _____ BLACK

MOUNTING PROVISIONS
FOR OPTIONAL FAN.

PANEL MOUNTING RAILS ARE TAPPED #10-32 ON E.I.A.
 UNIVERSAL SPACING AND ARE FULLY ADJUSTABLE.

BOTTOM PIERCED FOR RC-7758 CASTERS.

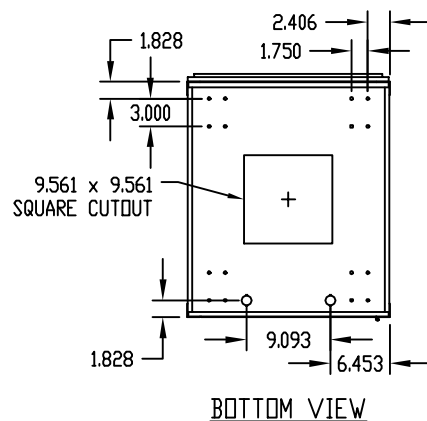
LOAD RATING: 1200 LBS. MAX.

☒-(2) SETS OF (10) HOODED LOUVERS
 CENTERED ON EACH SIDE.

○-(2) SETS OF (15) HOODED LOUVERS
 CENTERED ON EACH SIDE.

□-(4) SETS OF (10) HOODED LOUVERS ON EACH SIDE.

△-(4) SETS OF (15) HOODED LOUVERS ON EACH SIDE.



OPTIONAL ACCESSORY

PART NO.	PANEL SPACE A	B	C	D	E	F	G	STEEL FRONT DOORS PART NO.
AGR-9572 ☒	42.000	47.312	18.500	17.000	—	38.562	46.562	AGD-932
AGR-9573 ○	52.500	57.812			—	49.062	57.062	AGD-933
AGR-9574 ○	61.250	66.562			27.531	57.812	65.812	AGD-934
AGR-9575 ○	70.000	75.312			31.906	66.562	74.562	AGD-935
AGR-9576 ○	78.750	84.062	18.500	17.000	36.281	75.312	83.312	AGD-937
AGR-9582 □	42.000	47.312	25.500	24.000	—	38.562	46.562	AGD-932
AGR-9583 △	52.500	57.812			—	49.062	57.062	AGD-933
AGR-9584 △	61.250	66.562			27.531	57.812	65.812	AGD-934
AGR-9585 △	70.000	75.312			31.906	66.562	74.562	AGD-935
AGR-9586 △	78.750	84.062	25.500	24.000	36.281	75.312	83.312	AGD-937
AGR-9592 □	42.000	47.312	30.750	29.250	—	38.562	46.562	AGD-932
AGR-9593 △	52.500	57.812			—	49.062	57.062	AGD-933
AGR-9594 △	61.250	66.562			27.531	57.812	65.812	AGD-934
AGR-9595 △	70.000	75.312			31.906	66.562	74.562	AGD-935
AGR-9596 △	78.750	84.062	30.750	29.250	36.281	75.312	83.312	AGD-937

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[AGR-9586-RB](#) [AGR-9586-GT](#) [AGR-9585-RB](#) [AGR-9573-GT](#) [AGR-9573-RB](#) [AGR-9575-RB](#) [AGR-9584-GT](#) [AGR-9584-RB](#) [AGR-9582-GT](#) [AGR-9582-RB](#) [AGR-9583-GT](#) [AGR-9593-GT](#) [AGR-9593-RB](#) [AGR-9574-GT](#) [AGR-9574-RB](#) [AGR-9585-GT](#) [AGR-9576-GT](#) [AGR-9592-RB](#) [AGR-9592-GT](#) [AGR-9596-RB](#) [AGR-9583-RB](#) [AGR-9594-GT](#) [AGR-9594-RB](#) [AGR-9576-RB](#) [AGR-9575-GT](#) [AGR-9572-GT](#) [AGR-9572-RB](#) [AGR-9595-RB](#)