



PART NAME	UTILIBOX (STYLE A)	PART No.	CU-3281-MB to CU-3287-MB CUR-3281-MB to CUR-3287-MB CUR-3281-CMB to CUR-3287-CMB	REV. DATE	9-2-10
-----------	--------------------	----------	--	-----------	--------

MATERIAL:
 BODY AND STANDARD COVERS
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94V-A)
 RECESSED COVERS (CUR-)
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94V-0)
 CLEAR COVERS (-C)
 ABS THERMOPLASTIC (FLAMMABILITY RATING UL94V-2)
 FINISH
 BODY AND STANDARD COVERS ARE BLACK TEXTURED
 RECESSED (CUR-) AND CLEAR COVERS (-C) ARE SMOOTH FINISH

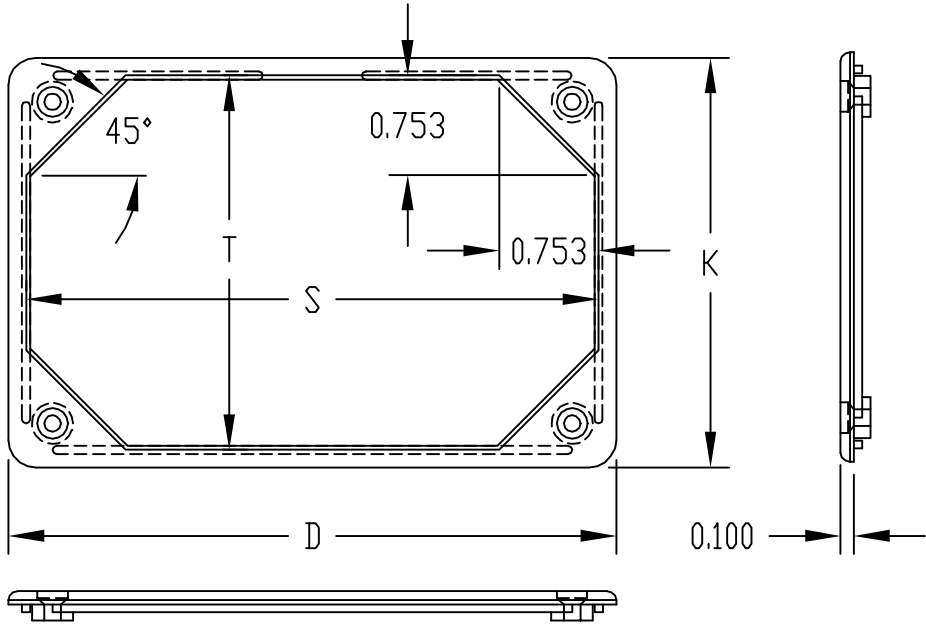


FOUR (4) #4-40 x 0.375" LG. SCREWS
 SUPPLIED FOR ASSEMBLING COVER
 TO BODY

MOUNTING BOSSES USE EITHER M2.5
 METRIC OR #4 STD. SHEET METAL
 SCREWS x 0.250" LG.
 (NOT SUPPLIED)

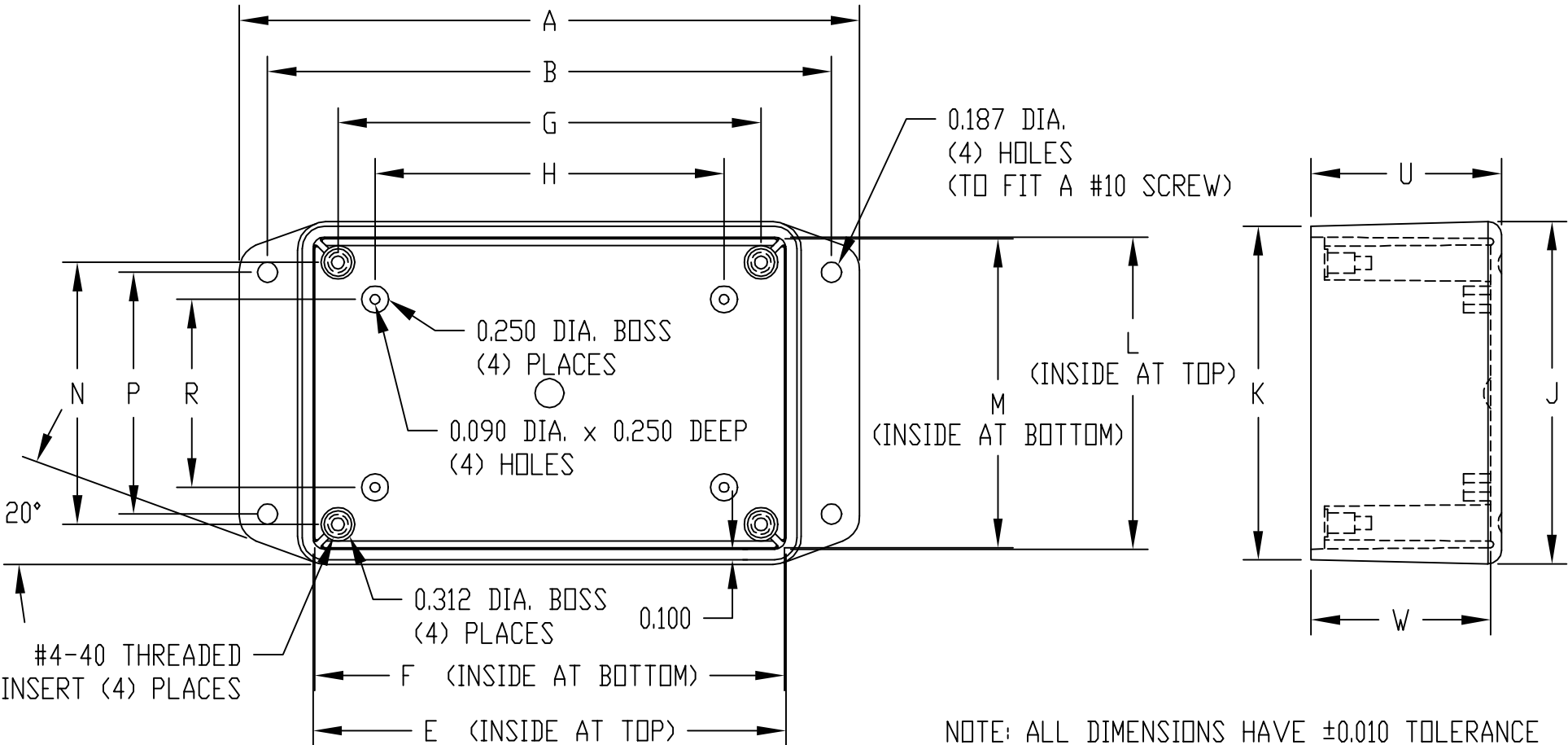

NOTE: ALL DIMENSIONS HAVE ±0.010 TOLERANCE
 UNLESS OTHERWISE SPECIFIED

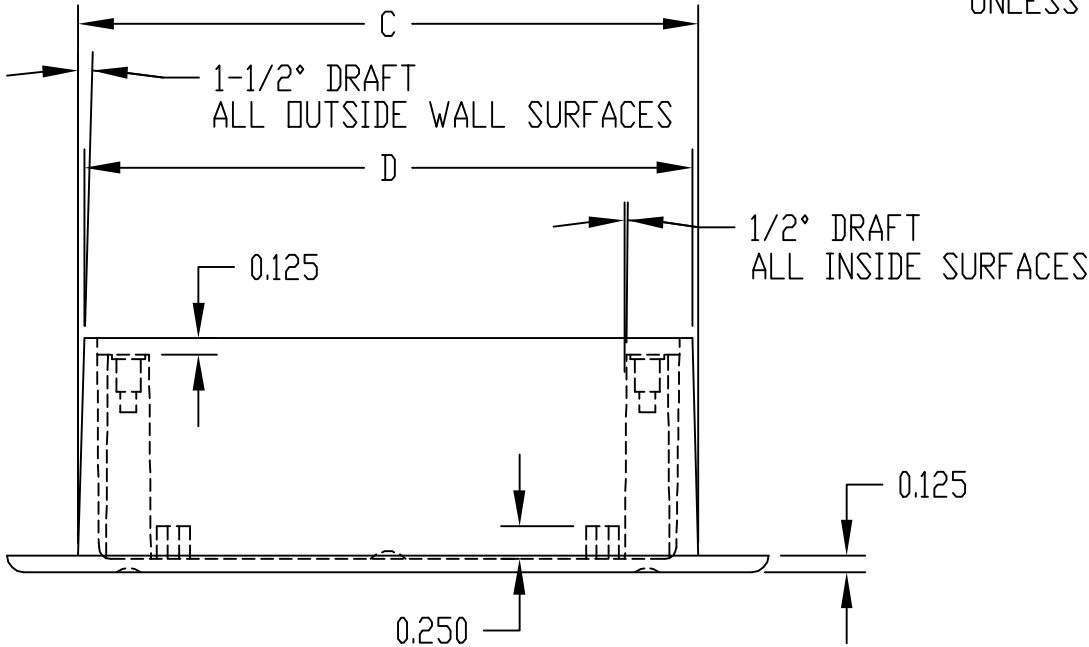

PART No.	A	B	C	D	E	F	G	H	J	K	L	M	N	P	R	S	T	U	W
CU-3281-MB	5.776	5.250	4.690	4.604	4.404	4.375	3.938	3.250	3.190	3.104	2.904	2.875	2.438	2.250	1.750	4.337	2.837	1.772	1.672
CU-3282-MB	5.776	5.250	4.724	4.612	4.412	4.375	3.938	3.250	4.724	4.612	4.412	4.375	3.938	3.500	3.250	4.345	4.345	2.256	2.156
CU-3283-MB	7.276	6.750	6.224	6.112	5.912	5.875	5.438	4.750	4.724	4.612	4.412	4.375	3.938	3.500	3.250	5.845	4.345	2.256	2.156
CU-3284-MB	8.776	8.250	7.724	7.612	7.412	7.375	6.938	6.250	4.724	4.612	4.412	4.375	3.938	3.500	3.250	7.345	4.345	2.256	2.156
CU-3287-MB	7.276	6.750	6.224	6.112	5.912	5.875	5.438	4.750	4.724	4.612	4.412	4.375	3.938	3.500	3.250	5.845	4.345	1.250	1.156

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Bud Industries:

[CU-3282-MB](#) [CUR-3281-MB](#) [CUR-3283-MB](#) [CUR-3284-MB](#) [CU-3281-MB](#) [CUR-3282-MB](#) [CU-3284-MB](#) [CU-3283-MB](#) [CU-3287-MB](#)