


NOTES:

1. MATERIAL: PLASTIC, E-PTFE,SILICON
COLOR: -B(BLACK) -W(WHITE)
2. ALL DIMENSIONS HAVE ±.03[.76] TOLERANCE UNLESS OTHERWISE SPECIFIED
3. DIMENSIONS ARE INCH [MM]

4. TECHNICAL DATA:

ART NO.: CF100(1 packing unit = 1 pieces,with 4 tapping screw)
MOUNTING: SCREW MOUNTING
MAXIMUM SIZE AND AREA: RECTANGULAR,100mm²
DIMENSIONS: 135×135×8mm
WEIGHT: APPROXIMATELY 98g
FITTING POSITION: VARIABLE
OPERATING TEMPERATURE: -40 to +100α
IP RATING: IP 65
AIR PERM: 3m³/m².min
COLLECTION EFFICIENCY: 95%-99.9995%
INITIAL RESISTANCE: <86Pa

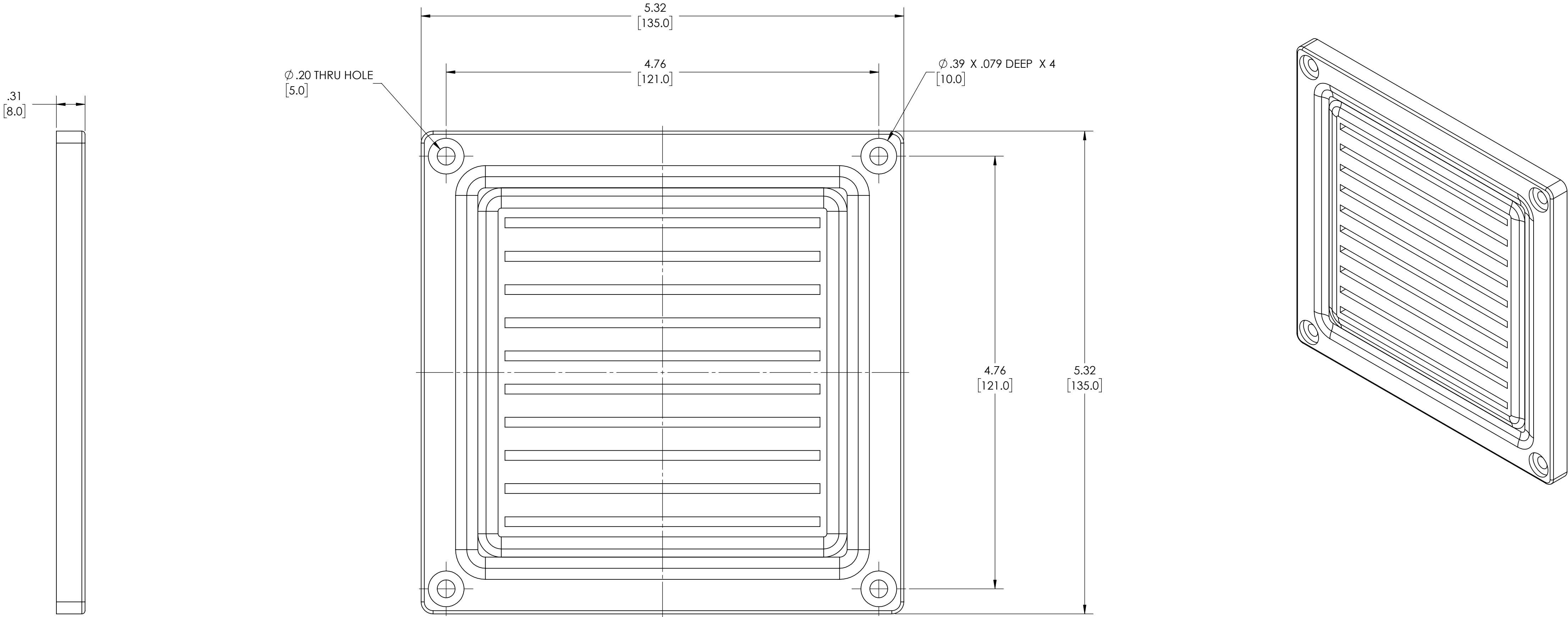

DRAWING FOR REFERENCE
WE RESERVE THE RIGHT TO MAKE CHANGES TO OUR
STANDARD PRODUCTS. PLEASE CONSULT WITH BUD INDUSTRIES
PRIOR TO USING THIS DRAWING FOR DESIGN PURPOSE.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Bud Industries:](#)

[IPV-65100-B](#) [IPV-65100-W](#)